

Professionally approved products.


Datasheet

RPSMA-UFL RF coax cable assembly

RS Stock number 794-2908



Dimensions: (mm)

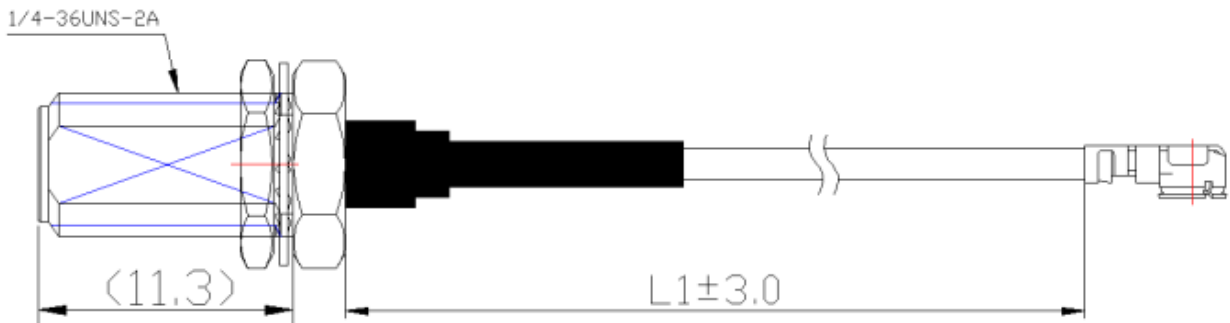

Specification

PRODUCT MATERIAL

1. RP-SMA B/H JACK CRIMP TYPE FOR $\varnothing 1.37\text{mm}$ CABLE NUT x 1, WASHER x 1
2. U.FL-LP-088 Halogen Free For $\varnothing 1.37\text{mm}$ Cable
3. U.FL-088 CONTACT For $\varnothing 1.37\text{mm}$ Cable
4. 1.37mm CABLE TIN PLATED COLOR:BLACK
5. HEAT SHRINK TUBE F32 $\varnothing 2.5\text{mm}$ L=15.0mm COLOR:BLACK.

ELECTRICAL PERFORMANCE:

1. IMPEDANCE: 50 OHMS
2. FREQUENCY RANGE: DC~3GHz
3. WORKING VOLTAGE: 250Vrms MAXIMUM
4. DIELECTRIC WITHSTANDING VOLTAGE: 750Vrms min.