


Professionally approved products.

Datasheet

Male SMA to Female SMA Coaxial Cable Assembly

RS Stock number [794-2920](#)

Dimensions: (mm)

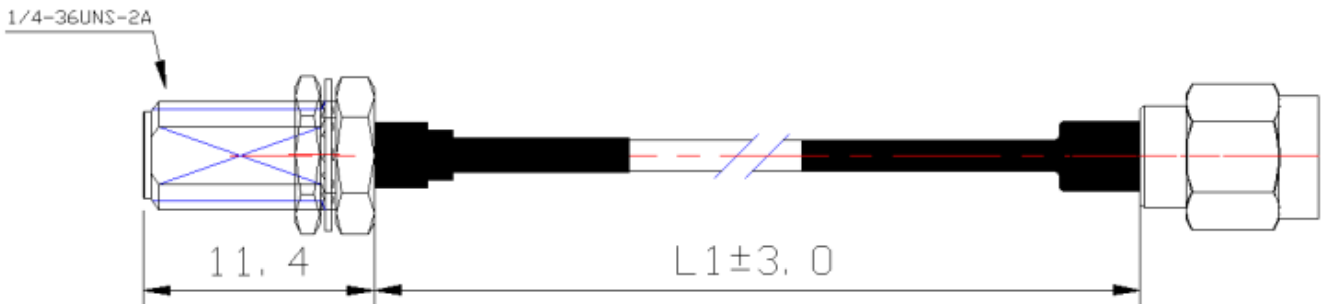

Specifications

PRODUCT MATERIAL

- 1. SMA B/H JACK CRIMP TYPE FOR Ø1.37mm CABLE NUT x WASHER x 1
- U.FL-LP-088 Halogen Free For Ø1.37mm Cable
- U.FL-088 CONTACT For Ø1.37mm Cable
- 1.37mm CABLE TIN PLATED COLOR:BLACK
- HEAT SHRINK TUBE F32 Ø2.5mm L=15.0mm COLOR:BLACK

ELECTRICAL PERFORMANCE

- IMPEDANCE:50 OHMS
- FREQUENCY RANGE:DC~3GHz
- WORKING VOLTAGE:250Vrms MAXIMUM 4.DIELECTRIC WITHSTANDING VOLTAGE:750Vrms min