

# Data sheet

## Thick Film Chip Resistor - RS Series

### 0201/0402/0603/0805/1206

#### ■Scope

- This specification applies to all sizes of rectangular-type fixed chip resistors with Ruthenium-base as material.

#### ■Features


- Small size and light weight
- Highly reliable multilayer electrode construction
- Compatible with all soldering process



#### ■Applications

- Telecommunication Equipments
- Radio and Tape Recorders, TV Tuners
- Video Cameras, Watches, Pocket Calculators
- Automotive Industry
- Computers, Instruments
- Medical and Military Equipment

#### ■Construction

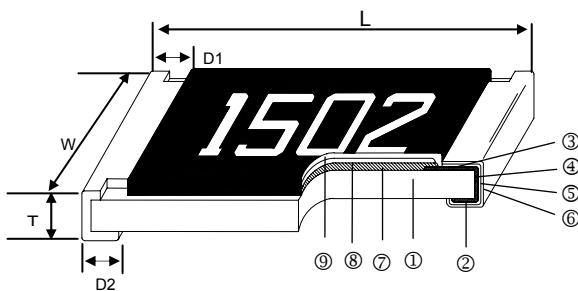

① Alumina Substrate	④ Edge Electrode (NiCr)	⑦ Resistor Layer (RuO <sub>2</sub> /Ag)
② Bottom Electrode (Ag)	⑤ Barrier Layer (Ni)	⑧ Primary Overcoat (Glass)
③ Top Electrode (Ag-Pd)	⑥ External Electrode (Sn)	⑨ Secondary Overcoat (Epoxy)

#### ■Dimensions

Unit: mm


Type	Size (Inch)	L	W	T	D1	D2	Weight (g) (1000pcs)
RS-0201	0201	0.60±0.03	0.30±0.03	0.23±0.03	0.15±0.05	0.15±0.05	0.150
RS-0402	0402	1.00±0.05	0.50±0.05	0.35±0.05	0.20±0.10	0.20±0.10	0.620
RS-0603	0603	1.60±0.10	0.80±0.10	0.45±0.10	0.30±0.20	0.30±0.20	2.042
RS-0805	0805	2.00±0.10	1.25±0.10	0.50±0.10	0.35±0.20	0.40±0.20	4.368
RS-1206	1206	3.10±0.10	1.55±0.10	0.55±0.10	0.50±0.25	0.50±0.20	8.947



### Part Numbering

RS-	0402-	10R-	1%-	0.0625W
	Dimensions	Resistance	Tolerance	Power Rating @ 70 °C
	0201 0402 0603 0805 1206	10R: 10Ω 100R: 100Ω 10K: 10KΩ 100K: 100KΩ	1%	0.0625W 0.1W 0.125W 0.25W



### Derating Curve

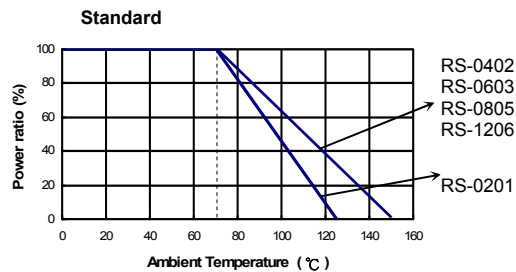

### Standard Electrical Specifications

Item Type	Power Rating at 70°C Jumper Rated Current	Operating Temp. Range	Max. Operating Voltage	Max. Overload Voltage	Resistance Range	TCR (PPM/°C)
					±1%	
RS-0201	1/20W	-55 ~ +155°C	25V	50V	10Ω – 910KΩ	±200
RS-0402	1/16W	-55 ~ +155°C	50V	100V	10Ω – 910KΩ	±100
RS-0603	1/10W	-55 ~ +155°C	75V	150V	10Ω – 910KΩ	±100
RS-0805	1/8W	-55 ~ +155°C	150V	300V	10Ω – 910KΩ	±100
RS-1206	1/4W	-55 ~ +155°C	200V	400V	10Ω – 910KΩ	±100

### Soldering Condition

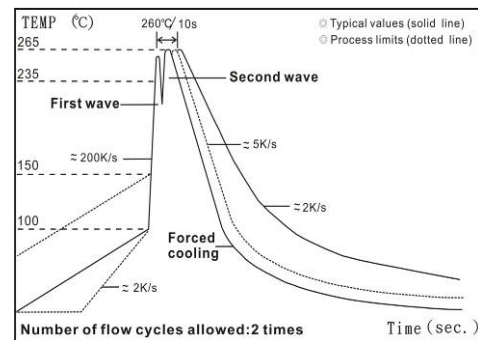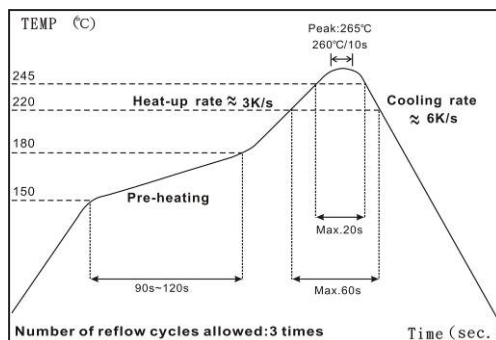

#### IR Reflow Soldering

- (1) Time of IR reflow soldering at maximum temperature point 260°C: 10s
- (2) Time of wave soldering at maximum temperature point 260°C: 10s
- (3) Time of soldering iron at maximum temperature point 410°C: 5s

#### Wave Soldering (Flow Soldering)


**■ Environmental Characteristics**

Item	Requirement	Test Method
	±1%	
Temperature Coefficient of Resistance (T.C.R.)	As Spec.	<b>JIS-C-5201-1 4.8</b> <b>IEC-60115-1 4.8</b> -55°C~+125/+155°C, 25°C is the reference temperature
Short Time Overload	±(1.0%+0.05Ω)	<b>JIS-C-5201-1 4.13</b> <b>IEC-60115-1 4.13</b> RCWV*2.5 or Max. overload voltage for 5 seconds, 2 seconds for high power series
Insulation Resistance	≥10G	<b>JIS-C-5201-1 4.6</b> <b>IEC-60115-1 4.6</b> Max. overload voltage for 1 minute
Endurance	±(2.0%+0.10Ω)	<b>JIS-C-5201-1 4.25</b> <b>IEC-60115-1 4.25.1</b> 70±2°C, Max. working voltage for 1000 hrs with 1.5 hrs "ON" and 0.5 hrs "OFF"
Damp Heat with Load	±(2.0%+0.10Ω)	<b>JIS-C-5201-1 4.24</b> 40±2°C, 90~95% R.H. Max. working voltage for 1000 hrs with 1.5 hrs "ON" and 0.5 hrs "OFF"
Dry Heat	±(1.0%+0.05Ω)	<b>JIS-C-5201-1 4.23</b> <b>IEC-60115-1 2.23.2</b> at +125/+155°C for 1000 hrs
Bending Strength	±(1.0%+0.05Ω)	<b>JIS-C-5201-1 4.33</b> <b>IEC-60115-1 4.33</b> Bending once for 5 seconds 2010, 2512 sizes: 2mm Other sizes: 3mm
Solderability	95% min. coverage	<b>JIS-C-5201-1 4.17</b> <b>IEC-60115-1 4.17</b> 245±5°C for 3 seconds
Resistance to Soldering Heat	±(0.5%+0.05Ω)	<b>JIS-C-5201-1 4.18</b> <b>IEC-60115-1 4.18</b> 260±5°C for 10 seconds
Voltage Proof	No breakdown or flashover	<b>JIS-C-5201-1 4.7</b> <b>IEC-60115-1 4.7</b> 1.42 times RCWV (RMS) for 1 minute
Leaching	Individual leaching area □ 5% Total leaching area □ 10%	<b>JIS-C-5201-1 4.18</b> <b>IEC-60068-2-58 8.2.1</b> 260±5°C for 30 seconds
Rapid Change of Temperature	±(0.5%+0.05Ω)	<b>JIS-C-5201-1 4.18</b> <b>IEC-60115-1 4.18</b> -55°C to +125/+155°C, 5 cycles

**■ Storage Temperature: 25±3°C; Humidity < 80%RH**

## ■Packaging


### Reel Specifications & Packaging Quantity

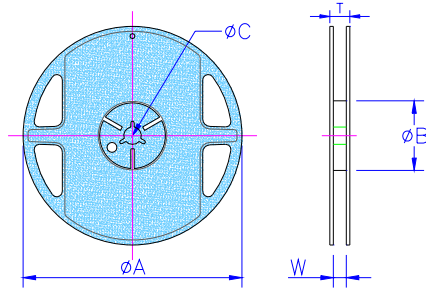

Unit: mm

Type	Packaging Quantity	Tape Width	Reel Diameter	ΦA	ΦB	ΦC	W	T
RS-0201 RS-0402	Paper	8mm	7 inch	178.5±1.5	60 <sup>+1/-0</sup>	13.0±0.2	9.0±0.5	12.5±0.5
			10 inch	254±1	100±0.5	13.0±0.2	9.5±0.5	13.5±0.5
RS-0603 RS-0805 RS-1206			13 inch	330±1	100±0.5	13.0±0.2	9.5±0.5	13.5±0.5

### Paper Tape Specifications

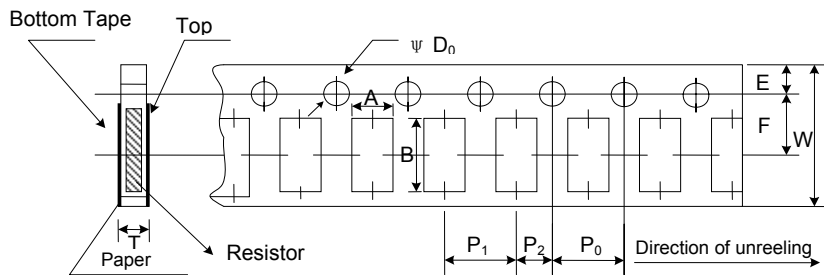

Unit: mm

Type	A	B	W	E	F	P <sub>0</sub>	P <sub>1</sub>	P <sub>2</sub>	ΦD <sub>0</sub>	T
RS-0201	0.38±0.05	0.68±0.05	8.0±0.2	1.75±0.1	3.50±0.05	4.00±0.10	2.00±0.05	2.00±0.05	1.50+0.1,-0	0.42±0.1
RS-0402	0.65±0.10	1.15±0.1	8.0±0.2	1.75±0.1	3.50±0.05	4.00±0.10	2.00±0.05	2.00±0.05	1.50+0.1,-0	0.45±0.1
RS-0603	1.10±0.10	1.90±0.1	8.0±0.2	1.75±0.1	3.50±0.05	4.00±0.10	4.00±0.05	2.00±0.05	1.50+0.1,-0	0.70±0.1
RS-0805	1.60±0.10	2.40±0.2	8.0±0.2	1.75±0.1	3.50±0.05	4.00±0.10	4.00±0.05	2.00±0.05	1.50+0.1,-0	0.85±0.1
RS-1206	1.90±0.10	3.50±0.2	8.0±0.2	1.75±0.1	3.50±0.05	4.00±0.10	4.00±0.05	2.00±0.05	1.50+0.1,-0	0.85±0.1



**■Marking**

No Marking for 0402

1% for 0805/1206: 4 digits marking

Example:

Resistance	100Ω	2.2KΩ	10KΩ	49.9KΩ	100KΩ
Marking	1000	2201	1002	4992	1003

1% for 0603: 3 digits marking in E96



3 digits marking for Example: 14C=13K7Ω 13C=13K3Ω  
68B=4K99Ω 68X=49.9Ω


**Marking Table**

Code	E96	Code	E96	Code	E96	Code	E96
01	100	25	178	49	316	73	562
02	102	26	182	50	324	74	576
03	105	27	187	51	332	75	590
04	107	28	191	52	340	76	604
05	110	29	196	53	348	77	619
06	113	30	200	54	357	78	634
07	115	31	205	55	365	79	649
08	118	32	210	56	374	80	665
09	121	33	215	57	383	81	681
10	124	34	221	58	392	82	698
11	127	35	226	59	402	83	715
12	130	36	232	60	412	84	732
13	133	37	237	61	422	85	750
14	137	38	243	62	432	86	768
15	140	39	249	63	442	87	787
16	143	40	255	64	453	88	806
17	147	41	261	65	464	89	825
18	150	42	267	66	475	90	845
19	154	43	274	67	487	91	866
20	158	44	280	68	499	92	887
21	162	45	287	69	511	93	909
22	165	46	294	70	523	94	931
23	169	47	301	71	536	95	953
24	174	48	309	72	549	96	976

Code	A	B	C	D	E	F	G	X	Y
Multiplier	10 <sup>0</sup>	10 <sup>1</sup>	10 <sup>2</sup>	10 <sup>3</sup>	10 <sup>4</sup>	10 <sup>5</sup>	10 <sup>6</sup>	10 <sup>-1</sup>	10 <sup>-2</sup>

**■Recommend Land Pattern**

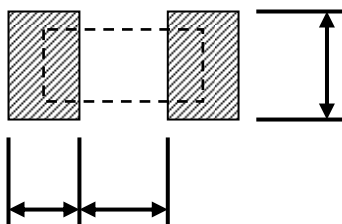

Unit: mm

Type	A	B	C
RS-0402	0.50	0.45	0.60
RS-0603	0.90	0.60	0.90
RS-0805	1.20	0.70	1.30
RS-1206	2.00	0.90	1.60

**RS Stock number reference table****RS 0201 Series**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0201-1R-1%-0.05W	7167447
RS-0201-1R1-1%-0.05W	7167440
RS-0201-1R2-1%-0.05W	7167444
RS-0201-1R3-1%-0.05W	7167453
RS-0201-1R5-1%-0.05W	7167456
RS-0201-1R6-1%-0.05W	7167450
RS-0201-1R8-1%-0.05W	7167469
RS-0201-2R-1%-0.05W	7167462
RS-0201-2R2-1%-0.05W	7167466
RS-0201-2R4-1%-0.05W	7167475
RS-0201-2R7-1%-0.05W	7167478
RS-0201-3R-1%-0.05W	7167472
RS-0201-3R3-1%-0.05W	7167481
RS-0201-3R6-1%-0.05W	7167484
RS-0201-3R9-1%-0.05W	7167488
RS-0201-4R3-1%-0.05W	7167497
RS-0201-4R7-1%-0.05W	7167490
RS-0201-5R1-1%-0.05W	7167494
RS-0201-5R6-1%-0.05W	7167504
RS-0201-6R2-1%-0.05W	7167507
RS-0201-6R8-1%-0.05W	7167501
RS-0201-7R5-1%-0.05W	7167510
RS-0201-8R2-1%-0.05W	7167513
RS-0201-9R1-1%-0.05W	7167517
RS-0201-10R-1%-0.05W	7167526
RS-0201-11R-1%-0.05W	7167529
RS-0201-12R-1%-0.05W	7167523
RS-0201-13R-1%-0.05W	7167532
RS-0201-15R-1%-0.05W	7167535
RS-0201-16R-1%-0.05W	7167539
RS-0201-18R-1%-0.05W	7167548
RS-0201-20R-1%-0.05W	7167541
RS-0201-22R-1%-0.05W	7167545
RS-0201-24R-1%-0.05W	7167554
RS-0201-27R-1%-0.05W	7167557
RS-0201-30R-1%-0.05W	7167551
RS-0201-33R-1%-0.05W	7167560
RS-0201-36R-1%-0.05W	7167563
RS-0201-39R-1%-0.05W	7167567
RS-0201-43R-1%-0.05W	7167576
RS-0201-47R-1%-0.05W	7167579
RS-0201-51R-1%-0.05W	7167573
RS-0201-56R-1%-0.05W	7167582
RS-0201-62R-1%-0.05W	7167585
RS-0201-68R-1%-0.05W	7167589
RS-0201-75R-1%-0.05W	7167598

**RS 0201 Series continued**



<b>Part Number</b>	<b>RS Stock Number</b>
RS-0201-82R-1%-0.05W	7167591
RS-0201-91R-1%-0.05W	7167595
RS-0201-100R-1%-0.05W	7167605
RS-0201-110R-1%-0.05W	7167608
RS-0201-120R-1%-0.05W	7167602
RS-0201-130R-1%-0.05W	7167611
RS-0201-150R-1%-0.05W	7167614
RS-0201-160R-1%-0.05W	7167618
RS-0201-180R-1%-0.05W	7167627
RS-0201-200R-1%-0.05W	7167620
RS-0201-220R-1%-0.05W	7167624
RS-0201-240R-1%-0.05W	7167633
RS-0201-270R-1%-0.05W	7167636
RS-0201-300R-1%-0.05W	7167630
RS-0201-330R-1%-0.05W	7167649
RS-0201-360R-1%-0.05W	7167642
RS-0201-390R-1%-0.05W	7167646
RS-0201-430R-1%-0.05W	7167655
RS-0201-470R-1%-0.05W	7167658
RS-0201-510R-1%-0.05W	7167652
RS-0201-560R-1%-0.05W	7167661
RS-0201-620R-1%-0.05W	7167664
RS-0201-680R-1%-0.05W	7167668
RS-0201-750R-1%-0.05W	7167677
RS-0201-820R-1%-0.05W	7167670
RS-0201-910R-1%-0.05W	7167674
RS-0201-1k-1%-0.05W	7167683
RS-0201-1k1-1%-0.05W	7167686
RS-0201-1k2-1%-0.05W	7167680
RS-0201-1k3-1%-0.05W	7167699
RS-0201-1k5-1%-0.05W	7167692
RS-0201-1k6-1%-0.05W	7167696
RS-0201-1k8-1%-0.05W	7167706
RS-0201-2k-1%-0.05W	7167709
RS-0201-2k2-1%-0.05W	7167703
RS-0201-2k4-1%-0.05W	7167712
RS-0201-2k7-1%-0.05W	7167715
RS-0201-3k-1%-0.05W	7167719
RS-0201-3k3-1%-0.05W	7167728
RS-0201-3k6-1%-0.05W	7167721
RS-0201-3k9-1%-0.05W	7167725
RS-0201-4k3-1%-0.05W	7167734
RS-0201-4k7-1%-0.05W	7167737
RS-0201-5k1-1%-0.05W	7167731
RS-0201-5k6-1%-0.05W	7167740
RS-0201-6k2-1%-0.05W	7167743
RS-0201-6k8-1%-0.05W	7167747
RS-0201-7k5-1%-0.05W	7167756
RS-0201-8k2-1%-0.05W	7167759

**RS 0201 Series continued**



---

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0201-9k1-1%-0.05W	7167753
RS-0201-10k-1%-0.05W	7167762
RS-0201-11k-1%-0.05W	7167765
RS-0201-12k-1%-0.05W	7167769
RS-0201-13k-1%-0.05W	7167778
RS-0201-15k-1%-0.05W	7167771
RS-0201-16k-1%-0.05W	7167775
RS-0201-18k-1%-0.05W	7167784
RS-0201-20k-1%-0.05W	7167787
RS-0201-22k-1%-0.05W	7167781
RS-0201-24k-1%-0.05W	7167790
RS-0201-27k-1%-0.05W	7167793
RS-0201-30k-1%-0.05W	7167797
RS-0201-33k-1%-0.05W	7167807
RS-0201-36k-1%-0.05W	7167800
RS-0201-39k-1%-0.05W	7167804
RS-0201-43k-1%-0.05W	7167813
RS-0201-47k-1%-0.05W	7167816
RS-0201-51k-1%-0.05W	7167810
RS-0201-56k-1%-0.05W	7167829
RS-0201-62k-1%-0.05W	7167822
RS-0201-68k-1%-0.05W	7167826
RS-0201-75k-1%-0.05W	7167835
RS-0201-82k-1%-0.05W	7167838
RS-0201-91k-1%-0.05W	7167832
RS-0201-100k-1%-0.05W	7167841
RS-0201-110k-1%-0.05W	7167844
RS-0201-120k-1%-0.05W	7167848
RS-0201-130k-1%-0.05W	7167857
RS-0201-150k-1%-0.05W	7167850
RS-0201-160k-1%-0.05W	7167854
RS-0201-180k-1%-0.05W	7167863
RS-0201-200k-1%-0.05W	7167866
RS-0201-220k-1%-0.05W	7167860
RS-0201-240k-1%-0.05W	7167879
RS-0201-270k-1%-0.05W	7167872
RS-0201-300k-1%-0.05W	7167876
RS-0201-330k-1%-0.05W	7167885
RS-0201-360k-1%-0.05W	7167888
RS-0201-390k-1%-0.05W	7167882
RS-0201-430k-1%-0.05W	7167891
RS-0201-470k-1%-0.05W	7167894
RS-0201-510k-1%-0.05W	7167898
RS-0201-560k-1%-0.05W	7167908
RS-0201-620k-1%-0.05W	7167901
RS-0201-680k-1%-0.05W	7167905
RS-0201-750k-1%-0.05W	7167914
RS-0201-820k-1%-0.05W	7167917
RS-0201-910k-1%-0.05W	7167911



**RS 0402 Series**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-1R-1%-0.0625W	7167923
RS-0402-1R02-1%-0.0625W	7167927
RS-0402-1R05-1%-0.0625W	7167936
RS-0402-1R07-1%-0.0625W	7167939
RS-0402-1R1-1%-0.0625W	7167933
RS-0402-1R13-1%-0.0625W	7167942
RS-0402-1R15-1%-0.0625W	7167945
RS-0402-1R18-1%-0.0625W	7167949
RS-0402-1R21-1%-0.0625W	7167958
RS-0402-1R24-1%-0.0625W	7167951
RS-0402-1R27-1%-0.0625W	7167955
RS-0402-1R3-1%-0.0625W	7167964
RS-0402-1R33-1%-0.0625W	7167967
RS-0402-1R37-1%-0.0625W	7167961
RS-0402-1R4-1%-0.0625W	7167970
RS-0402-1R43-1%-0.0625W	7167973
RS-0402-1R47-1%-0.0625W	7167977
RS-0402-1R5-1%-0.0625W	7167986
RS-0402-1R54-1%-0.0625W	7167989
RS-0402-1R58-1%-0.0625W	7167983
RS-0402-1R62-1%-0.0625W	7167992
RS-0402-1R65-1%-0.0625W	7167995
RS-0402-1R69-1%-0.0625W	7167999
RS-0402-1R74-1%-0.0625W	7168002
RS-0402-1R78-1%-0.0625W	7168005
RS-0402-1R82-1%-0.0625W	7168009
RS-0402-1R87-1%-0.0625W	7168018
RS-0402-1R91-1%-0.0625W	7168011
RS-0402-1R96-1%-0.0625W	7168015
RS-0402-2R-1%-0.0625W	7168024
RS-0402-2R05-1%-0.0625W	7168027
RS-0402-2R1-1%-0.0625W	7168021
RS-0402-2R16-1%-0.0625W	7168030
RS-0402-2R21-1%-0.0625W	7168033
RS-0402-2R36-1%-0.0625W	7168037
RS-0402-2R32-1%-0.0625W	7168046
RS-0402-2R37-1%-0.0625W	7168049
RS-0402-2R43-1%-0.0625W	7168043
RS-0402-2R49-1%-0.0625W	7168052
RS-0402-2R55-1%-0.0625W	7168055
RS-0402-2R61-1%-0.0625W	7168059
RS-0402-2R67-1%-0.0625W	7168068
RS-0402-2R74-1%-0.0625W	7168061
RS-0402-2R8-1%-0.0625W	7168065
RS-0402-2R87-1%-0.0625W	7168074
RS-0402-2R94-1%-0.0625W	7168077
RS-0402-3R01-1%-0.0625W	7168071
RS-0402-3R09-1%-0.0625W	7168080
RS-0402-3R16-1%-0.0625W	7168083
RS-0402-3R24-1%-0.0625W	7168087
RS-0402-3R32-1%-0.0625W	7168096
RS-0402-3R4-1%-0.0625W	7168099
RS-0402-3R48-1%-0.0625W	7168093

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-3R57-1%-0.0625W	7168103
RS-0402-3R65-1%-0.0625W	7168106
RS-0402-3R74-1%-0.0625W	7168100
RS-0402-3R83-1%-0.0625W	7168119
RS-0402-3R92-1%-0.0625W	7168112
RS-0402-4R02-1%-0.0625W	7168116
RS-0402-4R12-1%-0.0625W	7168125
RS-0402-4R22-1%-0.0625W	7168128
RS-0402-4R32-1%-0.0625W	7168122
RS-0402-4R42-1%-0.0625W	7168131
RS-0402-4R53-1%-0.0625W	7168134
RS-0402-4R64-1%-0.0625W	7168138
RS-0402-4R75-1%-0.0625W	7168147
RS-0402-4R87-1%-0.0625W	7168140
RS-0402-4R91-1%-0.0625W	7168144
RS-0402-5R11-1%-0.0625W	7168153
RS-0402-5R23-1%-0.0625W	7168156
RS-0402-5R36-1%-0.0625W	7168150
RS-0402-5R49-1%-0.0625W	7168169
RS-0402-5R62-1%-0.0625W	7168162
RS-0402-5R76-1%-0.0625W	7168166
RS-0402-5R9-1%-0.0625W	7168175
RS-0402-6R04-1%-0.0625W	7168178
RS-0402-6R19-1%-0.0625W	7168172
RS-0402-6R34-1%-0.0625W	7168181
RS-0402-6R49-1%-0.0625W	7168184
RS-0402-6R65-1%-0.0625W	7168188
RS-0402-6R81-1%-0.0625W	7168197
RS-0402-6R98-1%-0.0625W	7168190
RS-0402-7R15-1%-0.0625W	7168194
RS-0402-7R32-1%-0.0625W	7168204
RS-0402-7R5-1%-0.0625W	7168207
RS-0402-7R68-1%-0.0625W	7168201
RS-0402-7R87-1%-0.0625W	7168210
RS-0402-8R06-1%-0.0625W	7168213
RS-0402-8R25-1%-0.0625W	7168217
RS-0402-8R45-1%-0.0625W	7168226
RS-0402-8R66-1%-0.0625W	7168229
RS-0402-8R87-1%-0.0625W	7168223
RS-0402-9R09-1%-0.0625W	7168232
RS-0402-9R31-1%-0.0625W	7168235
RS-0402-9R59-1%-0.0625W	7168239
RS-0402-9R76-1%-0.0625W	7168248
RS-0402-10R2-1%-0.0625W	7168241
RS-0402-10R5-1%-0.0625W	7168245
RS-0402-10R7-1%-0.0625W	7168254
RS-0402-11R3-1%-0.0625W	7168257
RS-0402-11R5-1%-0.0625W	7168251
RS-0402-11R8-1%-0.0625W	7168260
RS-0402-12R1-1%-0.0625W	7168263
RS-0402-12R4-1%-0.0625W	7168267
RS-0402-12R7-1%-0.0625W	7168276
RS-0402-13R3-1%-0.0625W	7168279
RS-0402-13R7-1%-0.0625W	7168273

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-14R-1%-0.0625W	7168282
RS-0402-14R3-1%-0.0625W	7168285
RS-0402-14R7-1%-0.0625W	7168289
RS-0402-15R4-1%-0.0625W	7168298
RS-0402-15R8-1%-0.0625W	7168291
RS-0402-16R2-1%-0.0625W	7168295
RS-0402-16R5-1%-0.0625W	7168305
RS-0402-16R9-1%-0.0625W	7168308
RS-0402-17R4-1%-0.0625W	7168302
RS-0402-17R8-1%-0.0625W	7168311
RS-0402-18R2-1%-0.0625W	7168314
RS-0402-18R7-1%-0.0625W	7168318
RS-0402-19R1-1%-0.0625W	7168327
RS-0402-19R6-1%-0.0625W	7168320
RS-0402-20R5-1%-0.0625W	7168324
RS-0402-21R-1%-0.0625W	7168333
RS-0402-21R6-1%-0.0625W	7168336
RS-0402-22R1-1%-0.0625W	7168330
RS-0402-23R6-1%-0.0625W	7168349
RS-0402-23R2-1%-0.0625W	7168342
RS-0402-23R7-1%-0.0625W	7168346
RS-0402-24R3-1%-0.0625W	7168355
RS-0402-24R9-1%-0.0625W	7168358
RS-0402-25R5-1%-0.0625W	7168352
RS-0402-26R1-1%-0.0625W	7168361
RS-0402-26R7-1%-0.0625W	7168364
RS-0402-27R4-1%-0.0625W	7168368
RS-0402-28R-1%-0.0625W	7168377
RS-0402-28R7-1%-0.0625W	7168370
RS-0402-29R4-1%-0.0625W	7168374
RS-0402-30R1-1%-0.0625W	7168383
RS-0402-30R9-1%-0.0625W	7168386
RS-0402-31R6-1%-0.0625W	7168380
RS-0402-32R4-1%-0.0625W	7168399
RS-0402-33R2-1%-0.0625W	7168392
RS-0402-34R-1%-0.0625W	7168396
RS-0402-34R8-1%-0.0625W	7168406
RS-0402-35R7-1%-0.0625W	7168409
RS-0402-36R5-1%-0.0625W	7168403
RS-0402-37R4-1%-0.0625W	7168412
RS-0402-38R3-1%-0.0625W	7168415
RS-0402-39R2-1%-0.0625W	7168419
RS-0402-40R2-1%-0.0625W	7168428
RS-0402-41R2-1%-0.0625W	7168421
RS-0402-42R2-1%-0.0625W	7168425
RS-0402-43R2-1%-0.0625W	7168434
RS-0402-44R2-1%-0.0625W	7168437
RS-0402-45R3-1%-0.0625W	7168431
RS-0402-46R4-1%-0.0625W	7168440
RS-0402-47R5-1%-0.0625W	7168443
RS-0402-48R7-1%-0.0625W	7168447
RS-0402-49R1-1%-0.0625W	7168456
RS-0402-51R1-1%-0.0625W	7168459
RS-0402-52R3-1%-0.0625W	7168453

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-53R6-1%-0.0625W	7168462
RS-0402-54R9-1%-0.0625W	7168465
RS-0402-56R2-1%-0.0625W	7168469
RS-0402-57R6-1%-0.0625W	7168478
RS-0402-59R-1%-0.0625W	7168471
RS-0402-60R4-1%-0.0625W	7168475
RS-0402-61R9-1%-0.0625W	7168484
RS-0402-63R4-1%-0.0625W	7168487
RS-0402-64R9-1%-0.0625W	7168481
RS-0402-66R5-1%-0.0625W	7168490
RS-0402-68R1-1%-0.0625W	7168493
RS-0402-69R8-1%-0.0625W	7168497
RS-0402-71R5-1%-0.0625W	7168507
RS-0402-73R2-1%-0.0625W	7168500
RS-0402-76R8-1%-0.0625W	7168504
RS-0402-78R7-1%-0.0625W	7168513
RS-0402-80R6-1%-0.0625W	7168516
RS-0402-82R5-1%-0.0625W	7168510
RS-0402-84R5-1%-0.0625W	7168529
RS-0402-86R6-1%-0.0625W	7168522
RS-0402-88R7-1%-0.0625W	7168526
RS-0402-90R9-1%-0.0625W	7168535
RS-0402-93R1-1%-0.0625W	7168538
RS-0402-95R9-1%-0.0625W	7168532
RS-0402-97R6-1%-0.0625W	7168541
RS-0402-102R-1%-0.0625W	7168544
RS-0402-105R-1%-0.0625W	7168548
RS-0402-107R-1%-0.0625W	7168557
RS-0402-113R-1%-0.0625W	7168550
RS-0402-115R-1%-0.0625W	7168554
RS-0402-118R-1%-0.0625W	7168563
RS-0402-121R-1%-0.0625W	7168566
RS-0402-124R-1%-0.0625W	7168560
RS-0402-127R-1%-0.0625W	7168579
RS-0402-133R-1%-0.0625W	7168572
RS-0402-137R-1%-0.0625W	7168576
RS-0402-140R-1%-0.0625W	7168585
RS-0402-143R-1%-0.0625W	7168588
RS-0402-147R-1%-0.0625W	7168582
RS-0402-154R-1%-0.0625W	7168591
RS-0402-158R-1%-0.0625W	7168594
RS-0402-162R-1%-0.0625W	7168598
RS-0402-165R-1%-0.0625W	7168608
RS-0402-169R-1%-0.0625W	7168601
RS-0402-174R-1%-0.0625W	7168605
RS-0402-178R-1%-0.0625W	7168614
RS-0402-182R-1%-0.0625W	7168617
RS-0402-187R-1%-0.0625W	7168611
RS-0402-191R-1%-0.0625W	7168620
RS-0402-196R-1%-0.0625W	7168623
RS-0402-205R-1%-0.0625W	7168627
RS-0402-210R-1%-0.0625W	7168636
RS-0402-216R-1%-0.0625W	7168639
RS-0402-221R-1%-0.0625W	7168633

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-236R-1%-0.0625W	7168642
RS-0402-232R-1%-0.0625W	7168645
RS-0402-237R-1%-0.0625W	7168649
RS-0402-243R-1%-0.0625W	7168658
RS-0402-249R-1%-0.0625W	7168651
RS-0402-255R-1%-0.0625W	7168655
RS-0402-261R-1%-0.0625W	7168664
RS-0402-267R-1%-0.0625W	7168667
RS-0402-274R-1%-0.0625W	7168661
RS-0402-280R-1%-0.0625W	7168670
RS-0402-287R-1%-0.0625W	7168673
RS-0402-294R-1%-0.0625W	7168677
RS-0402-301R-1%-0.0625W	7168686
RS-0402-309R-1%-0.0625W	7168689
RS-0402-316R-1%-0.0625W	7168683
RS-0402-324R-1%-0.0625W	7168692
RS-0402-332R-1%-0.0625W	7168695
RS-0402-340R-1%-0.0625W	7168699
RS-0402-348R-1%-0.0625W	7168709
RS-0402-357R-1%-0.0625W	7168702
RS-0402-365R-1%-0.0625W	7168706
RS-0402-374R-1%-0.0625W	7168715
RS-0402-383R-1%-0.0625W	7168718
RS-0402-392R-1%-0.0625W	7168712
RS-0402-402R-1%-0.0625W	7168721
RS-0402-412R-1%-0.0625W	7168724
RS-0402-422R-1%-0.0625W	7168728
RS-0402-432R-1%-0.0625W	7168737
RS-0402-442R-1%-0.0625W	7168730
RS-0402-453R-1%-0.0625W	7168734
RS-0402-464R-1%-0.0625W	7168743
RS-0402-475R-1%-0.0625W	7168746
RS-0402-487R-1%-0.0625W	7168740
RS-0402-491R-1%-0.0625W	7168759
RS-0402-511R-1%-0.0625W	7168752
RS-0402-523R-1%-0.0625W	7168756
RS-0402-536R-1%-0.0625W	7168765
RS-0402-549R-1%-0.0625W	7168768
RS-0402-562R-1%-0.0625W	7168762
RS-0402-576R-1%-0.0625W	7168771
RS-0402-590R-1%-0.0625W	7168774
RS-0402-604R-1%-0.0625W	7168778
RS-0402-619R-1%-0.0625W	7168787
RS-0402-634R-1%-0.0625W	7168780
RS-0402-649R-1%-0.0625W	7168784
RS-0402-665R-1%-0.0625W	7168793
RS-0402-681R-1%-0.0625W	7168796
RS-0402-698R-1%-0.0625W	7168790
RS-0402-715R-1%-0.0625W	7168800
RS-0402-732R-1%-0.0625W	7168803
RS-0402-768R-1%-0.0625W	7168807
RS-0402-787R-1%-0.0625W	7168816
RS-0402-806R-1%-0.0625W	7168819
RS-0402-825R-1%-0.0625W	7168813

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-845R-1%-0.0625W	7168822
RS-0402-866R-1%-0.0625W	7168825
RS-0402-887R-1%-0.0625W	7168829
RS-0402-909R-1%-0.0625W	7168838
RS-0402-931R-1%-0.0625W	7168831
RS-0402-959R-1%-0.0625W	7168835
RS-0402-976R-1%-0.0625W	7168844
RS-0402-1k02-1%-0.0625W	7168847
RS-0402-1k05-1%-0.0625W	7168841
RS-0402-1k07-1%-0.0625W	7168850
RS-0402-1k13-1%-0.0625W	7168853
RS-0402-1k15-1%-0.0625W	7168857
RS-0402-1k18-1%-0.0625W	7168866
RS-0402-1k21-1%-0.0625W	7168869
RS-0402-1k24-1%-0.0625W	7168863
RS-0402-1k27-1%-0.0625W	7168872
RS-0402-1k30-1%-0.0625W	7168875
RS-0402-1k33-1%-0.0625W	7168879
RS-0402-1k37-1%-0.0625W	7168888
RS-0402-1k40-1%-0.0625W	7168881
RS-0402-1k43-1%-0.0625W	7168885
RS-0402-1k47-1%-0.0625W	7168894
RS-0402-1k54-1%-0.0625W	7168897
RS-0402-1k58-1%-0.0625W	7168891
RS-0402-1k62-1%-0.0625W	7168901
RS-0402-1k65-1%-0.0625W	7168904
RS-0402-1k69-1%-0.0625W	7168908
RS-0402-1k74-1%-0.0625W	7168917
RS-0402-1k78-1%-0.0625W	7168910
RS-0402-1k82-1%-0.0625W	7168914
RS-0402-1k87-1%-0.0625W	7168923
RS-0402-1k91-1%-0.0625W	7168926
RS-0402-1k96-1%-0.0625W	7168920
RS-0402-2k05-1%-0.0625W	7168939
RS-0402-2k10-1%-0.0625W	7168932
RS-0402-2k16-1%-0.0625W	7168936
RS-0402-2k21-1%-0.0625W	7168945
RS-0402-2k36-1%-0.0625W	7168948
RS-0402-2k32-1%-0.0625W	7168942
RS-0402-2k37-1%-0.0625W	7168951
RS-0402-2k43-1%-0.0625W	7168954
RS-0402-2k49-1%-0.0625W	7168958
RS-0402-2k55-1%-0.0625W	7168967
RS-0402-2k61-1%-0.0625W	7168960
RS-0402-2k67-1%-0.0625W	7168964
RS-0402-2k74-1%-0.0625W	7168973
RS-0402-2k80-1%-0.0625W	7168976
RS-0402-2k87-1%-0.0625W	7168970
RS-0402-2k94-1%-0.0625W	7168989
RS-0402-3k01-1%-0.0625W	7168982
RS-0402-3k09-1%-0.0625W	7168986
RS-0402-3k16-1%-0.0625W	7168995
RS-0402-3k24-1%-0.0625W	7168998
RS-0402-3k32-1%-0.0625W	7168992

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-3k40-1%-0.0625W	7169005
RS-0402-3k48-1%-0.0625W	7169008
RS-0402-3k57-1%-0.0625W	7169002
RS-0402-3k65-1%-0.0625W	7169011
RS-0402-3k74-1%-0.0625W	7169014
RS-0402-3k83-1%-0.0625W	7169018
RS-0402-3k92-1%-0.0625W	7169027
RS-0402-4k02-1%-0.0625W	7169020
RS-0402-4k12-1%-0.0625W	7169024
RS-0402-4k22-1%-0.0625W	7169033
RS-0402-4k32-1%-0.0625W	7169036
RS-0402-4k42-1%-0.0625W	7169030
RS-0402-4k53-1%-0.0625W	7169049
RS-0402-4k64-1%-0.0625W	7169042
RS-0402-4k75-1%-0.0625W	7169046
RS-0402-4k87-1%-0.0625W	7169055
RS-0402-4k91-1%-0.0625W	7169058
RS-0402-5k11-1%-0.0625W	7169052
RS-0402-5k23-1%-0.0625W	7169061
RS-0402-5k36-1%-0.0625W	7169064
RS-0402-5k49-1%-0.0625W	7169068
RS-0402-5k62-1%-0.0625W	7169077
RS-0402-5k76-1%-0.0625W	7169070
RS-0402-5k90-1%-0.0625W	7169074
RS-0402-6k04-1%-0.0625W	7169083
RS-0402-6k19-1%-0.0625W	7169086
RS-0402-6k34-1%-0.0625W	7169080
RS-0402-6k49-1%-0.0625W	7169099
RS-0402-6k65-1%-0.0625W	7169092
RS-0402-6k81-1%-0.0625W	7169096
RS-0402-6k98-1%-0.0625W	7169106
RS-0402-7k15-1%-0.0625W	7169109
RS-0402-7k32-1%-0.0625W	7169103
RS-0402-7k68-1%-0.0625W	7169112
RS-0402-7k87-1%-0.0625W	7169115
RS-0402-8k06-1%-0.0625W	7169119
RS-0402-8k25-1%-0.0625W	7169128
RS-0402-8k45-1%-0.0625W	7169121
RS-0402-8k66-1%-0.0625W	7169125
RS-0402-8k87-1%-0.0625W	7169134
RS-0402-9k09-1%-0.0625W	7169137
RS-0402-9k31-1%-0.0625W	7169131
RS-0402-9k59-1%-0.0625W	7169140
RS-0402-9k76-1%-0.0625W	7169143
RS-0402-10k2-1%-0.0625W	7169147
RS-0402-10k5-1%-0.0625W	7169156
RS-0402-10k7-1%-0.0625W	7169159
RS-0402-11k3-1%-0.0625W	7169153
RS-0402-11k5-1%-0.0625W	7169162
RS-0402-11k8-1%-0.0625W	7169165
RS-0402-12k1-1%-0.0625W	7169169
RS-0402-12k4-1%-0.0625W	7169178
RS-0402-12k7-1%-0.0625W	7169171
RS-0402-13k3-1%-0.0625W	7169175

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-13k7-1%-0.0625W	7169184
RS-0402-14K-1%-0.0625W	7169187
RS-0402-14k3-1%-0.0625W	7169181
RS-0402-14k7-1%-0.0625W	7169190
RS-0402-15k4-1%-0.0625W	7169193
RS-0402-15k8-1%-0.0625W	7169197
RS-0402-16k2-1%-0.0625W	7169207
RS-0402-16k5-1%-0.0625W	7169200
RS-0402-16k9-1%-0.0625W	7169204
RS-0402-17k4-1%-0.0625W	7169213
RS-0402-17k8-1%-0.0625W	7169216
RS-0402-18k2-1%-0.0625W	7169210
RS-0402-18k7-1%-0.0625W	7169229
RS-0402-19k1-1%-0.0625W	7169222
RS-0402-19k6-1%-0.0625W	7169226
RS-0402-20k5-1%-0.0625W	7169235
RS-0402-21K-1%-0.0625W	7169238
RS-0402-21k6-1%-0.0625W	7169232
RS-0402-22k1-1%-0.0625W	7169241
RS-0402-23k6-1%-0.0625W	7169244
RS-0402-23k2-1%-0.0625W	7169248
RS-0402-23k7-1%-0.0625W	7169257
RS-0402-24k3-1%-0.0625W	7169250
RS-0402-24k9-1%-0.0625W	7169254
RS-0402-25k5-1%-0.0625W	7169263
RS-0402-26k1-1%-0.0625W	7169266
RS-0402-26k7-1%-0.0625W	7169260
RS-0402-27k4-1%-0.0625W	7169279
RS-0402-28K-1%-0.0625W	7169272
RS-0402-28k7-1%-0.0625W	7169276
RS-0402-29k4-1%-0.0625W	7169285
RS-0402-30k1-1%-0.0625W	7169288
RS-0402-30k9-1%-0.0625W	7169282
RS-0402-31k6-1%-0.0625W	7169291
RS-0402-32k4-1%-0.0625W	7169294
RS-0402-33k2-1%-0.0625W	7169298
RS-0402-34K-1%-0.0625W	7169308
RS-0402-34k8-1%-0.0625W	7169301
RS-0402-35k7-1%-0.0625W	7169305
RS-0402-36k5-1%-0.0625W	7169314
RS-0402-37k4-1%-0.0625W	7169317
RS-0402-38k3-1%-0.0625W	7169311
RS-0402-39k2-1%-0.0625W	7169320
RS-0402-40k2-1%-0.0625W	7169323
RS-0402-41k2-1%-0.0625W	7169327
RS-0402-42k2-1%-0.0625W	7169336
RS-0402-43k2-1%-0.0625W	7169339
RS-0402-44k2-1%-0.0625W	7169333
RS-0402-45k3-1%-0.0625W	7169342
RS-0402-46k4-1%-0.0625W	7169345
RS-0402-47k5-1%-0.0625W	7169349
RS-0402-48k7-1%-0.0625W	7169358
RS-0402-49k1-1%-0.0625W	7169351
RS-0402-51k1-1%-0.0625W	7169355



**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-52k3-1%-0.0625W	7169364
RS-0402-53k6-1%-0.0625W	7169367
RS-0402-54k9-1%-0.0625W	7169361
RS-0402-56k2-1%-0.0625W	7169370
RS-0402-57k6-1%-0.0625W	7169373
RS-0402-59K-1%-0.0625W	7169377
RS-0402-60k4-1%-0.0625W	7169386
RS-0402-61k9-1%-0.0625W	7169389
RS-0402-63k4-1%-0.0625W	7169383
RS-0402-64k9-1%-0.0625W	7169392
RS-0402-66k5-1%-0.0625W	7169395
RS-0402-68k1-1%-0.0625W	7169399
RS-0402-69k8-1%-0.0625W	7169409
RS-0402-71k5-1%-0.0625W	7169402
RS-0402-73k2-1%-0.0625W	7169406
RS-0402-76k8-1%-0.0625W	7169415
RS-0402-78k7-1%-0.0625W	7169418
RS-0402-80k6-1%-0.0625W	7169412
RS-0402-82k5-1%-0.0625W	7169421
RS-0402-84k5-1%-0.0625W	7169424
RS-0402-86k6-1%-0.0625W	7169428
RS-0402-88k7-1%-0.0625W	7169437
RS-0402-90k9-1%-0.0625W	7169430
RS-0402-93k1-1%-0.0625W	7169434
RS-0402-95k9-1%-0.0625W	7169443
RS-0402-97K6-1%-0.0625W	7169446
RS-0402-102K-1%-0.0625W	7169440
RS-0402-105K-1%-0.0625W	7169459
RS-0402-107K-1%-0.0625W	7169452
RS-0402-113K-1%-0.0625W	7169456
RS-0402-115K-1%-0.0625W	7169465
RS-0402-118K-1%-0.0625W	7169468
RS-0402-121K-1%-0.0625W	7169462
RS-0402-124K-1%-0.0625W	7169471
RS-0402-127K-1%-0.0625W	7169474
RS-0402-133K-1%-0.0625W	7169478
RS-0402-137K-1%-0.0625W	7169487
RS-0402-140K-1%-0.0625W	7169480
RS-0402-143K-1%-0.0625W	7169484
RS-0402-147K-1%-0.0625W	7169493
RS-0402-154K-1%-0.0625W	7169496
RS-0402-158K-1%-0.0625W	7169490
RS-0402-162K-1%-0.0625W	7169500
RS-0402-165K-1%-0.0625W	7169503
RS-0402-169K-1%-0.0625W	7169507
RS-0402-174K-1%-0.0625W	7169516
RS-0402-178K-1%-0.0625W	7169519
RS-0402-182K-1%-0.0625W	7169513
RS-0402-187K-1%-0.0625W	7169522
RS-0402-191K-1%-0.0625W	7169525
RS-0402-196K-1%-0.0625W	7169529
RS-0402-205K-1%-0.0625W	7169538
RS-0402-210K-1%-0.0625W	7169531
RS-0402-216K-1%-0.0625W	7169535

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-221K-1%-0.0625W	7169544
RS-0402-236K-1%-0.0625W	7169547
RS-0402-232K-1%-0.0625W	7169541
RS-0402-237K-1%-0.0625W	7169550
RS-0402-243K-1%-0.0625W	7169553
RS-0402-249K-1%-0.0625W	7169557
RS-0402-255K-1%-0.0625W	7169566
RS-0402-261K-1%-0.0625W	7169569
RS-0402-267K-1%-0.0625W	7169563
RS-0402-274K-1%-0.0625W	7169572
RS-0402-280K-1%-0.0625W	7169575
RS-0402-287K-1%-0.0625W	7169579
RS-0402-294K-1%-0.0625W	7169588
RS-0402-301K-1%-0.0625W	7169581
RS-0402-309K-1%-0.0625W	7169585
RS-0402-316K-1%-0.0625W	7169594
RS-0402-324K-1%-0.0625W	7169597
RS-0402-332K-1%-0.0625W	7169591
RS-0402-340K-1%-0.0625W	7169601
RS-0402-348K-1%-0.0625W	7169604
RS-0402-357K-1%-0.0625W	7169608
RS-0402-365K-1%-0.0625W	7169617
RS-0402-374K-1%-0.0625W	7169610
RS-0402-383K-1%-0.0625W	7169614
RS-0402-392K-1%-0.0625W	7169623
RS-0402-402K-1%-0.0625W	7169626
RS-0402-412K-1%-0.0625W	7169620
RS-0402-422K-1%-0.0625W	7169639
RS-0402-432K-1%-0.0625W	7169632
RS-0402-442K-1%-0.0625W	7169636
RS-0402-453K-1%-0.0625W	7169645
RS-0402-464K-1%-0.0625W	7169648
RS-0402-475K-1%-0.0625W	7169642
RS-0402-487K-1%-0.0625W	7169651
RS-0402-491K-1%-0.0625W	7169654
RS-0402-511K-1%-0.0625W	7169658
RS-0402-523K-1%-0.0625W	7169667
RS-0402-536K-1%-0.0625W	7169660
RS-0402-549K-1%-0.0625W	7169664
RS-0402-562K-1%-0.0625W	7169673
RS-0402-576K-1%-0.0625W	7169676
RS-0402-590K-1%-0.0625W	7169670
RS-0402-604K-1%-0.0625W	7169689
RS-0402-619K-1%-0.0625W	7169682
RS-0402-634K-1%-0.0625W	7169686
RS-0402-649K-1%-0.0625W	7169695
RS-0402-665K-1%-0.0625W	7169698
RS-0402-681K-1%-0.0625W	7169692
RS-0402-698K-1%-0.0625W	7169702
RS-0402-715K-1%-0.0625W	7169705
RS-0402-732K-1%-0.0625W	7169709
RS-0402-768K-1%-0.0625W	7169718
RS-0402-787K-1%-0.0625W	7169711
RS-0402-806K-1%-0.0625W	7169715

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-825K-1%-0.0625W	7169724
RS-0402-845K-1%-0.0625W	7169727
RS-0402-866K-1%-0.0625W	7169721
RS-0402-887K-1%-0.0625W	7169730
RS-0402-909K-1%-0.0625W	7169733
RS-0402-931K-1%-0.0625W	7169737
RS-0402-959K-1%-0.0625W	7169746
RS-0402-976K-1%-0.0625W	7169749
RS-0402-10R-1%-0.0625W	6980463
RS-0402-11R-1%-0.0625W	6980466
RS-0402-12R-1%-0.0625W	6980460
RS-0402-13R-1%-0.0625W	6980479
RS-0402-15R-1%-0.0625W	6980472
RS-0402-16R-1%-0.0625W	6980476
RS-0402-18R-1%-0.0625W	6980485
RS-0402-20R-1%-0.0625W	6980488
RS-0402-22R-1%-0.0625W	6980482
RS-0402-24R-1%-0.0625W	6980491
RS-0402-27R-1%-0.0625W	6980494
RS-0402-30R-1%-0.0625W	6980498
RS-0402-33R-1%-0.0625W	6980508
RS-0402-36R-1%-0.0625W	6980501
RS-0402-39R-1%-0.0625W	6980505
RS-0402-43R-1%-0.0625W	6980514
RS-0402-47R-1%-0.0625W	6980517
RS-0402-51R-1%-0.0625W	6980511
RS-0402-56R-1%-0.0625W	6980520
RS-0402-62R-1%-0.0625W	6980523
RS-0402-68R-1%-0.0625W	6980527
RS-0402-75R-1%-0.0625W	6980536
RS-0402-82R-1%-0.0625W	6980539
RS-0402-91R-1%-0.0625W	6980533
RS-0402-100R-1%-0.0625W	6980542
RS-0402-110R-1%-0.0625W	6980545
RS-0402-120R-1%-0.0625W	6980549
RS-0402-130R-1%-0.0625W	6980558
RS-0402-150R-1%-0.0625W	6980551
RS-0402-160R-1%-0.0625W	6980555
RS-0402-180R-1%-0.0625W	6980564
RS-0402-200R-1%-0.0625W	6980567
RS-0402-220R-1%-0.0625W	6980561
RS-0402-240R-1%-0.0625W	6980570
RS-0402-270R-1%-0.0625W	6980573
RS-0402-300R-1%-0.0625W	6980577
RS-0402-330R-1%-0.0625W	6980586
RS-0402-360R-1%-0.0625W	6980589
RS-0402-390R-1%-0.0625W	6980583
RS-0402-430R-1%-0.0625W	6980592
RS-0402-470R-1%-0.0625W	6980595
RS-0402-510R-1%-0.0625W	6980599
RS-0402-560R-1%-0.0625W	6980609
RS-0402-620R-1%-0.0625W	6980602
RS-0402-680R-1%-0.0625W	6980606
RS-0402-750R-1%-0.0625W	6980615

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-820R-1%-0.0625W	6980618
RS-0402-910R-1%-0.0625W	6980612
RS-0402-1k-1%-0.0625W	6980621
RS-0402-1k-1%-0.0625W	6980624
RS-0402-1k1-1%-0.0625W	6980628
RS-0402-1k2-1%-0.0625W	6980637
RS-0402-1k3-1%-0.0625W	6980630
RS-0402-1k5-1%-0.0625W	6980634
RS-0402-1k6-1%-0.0625W	6980643
RS-0402-1k8-1%-0.0625W	6980646
RS-0402-2k-1%-0.0625W	6980640
RS-0402-2k-1%-0.0625W	6980659
RS-0402-2k2-1%-0.0625W	6980652
RS-0402-2k4-1%-0.0625W	6980656
RS-0402-2k7-1%-0.0625W	6980665
RS-0402-3k-1%-0.0625W	6980668
RS-0402-3k-1%-0.0625W	6980662
RS-0402-3k3-1%-0.0625W	6980671
RS-0402-3k6-1%-0.0625W	6980674
RS-0402-3k9-1%-0.0625W	6980678
RS-0402-4k3-1%-0.0625W	6980687
RS-0402-4k7-1%-0.0625W	6980680
RS-0402-5k1-1%-0.0625W	6980684
RS-0402-5k6-1%-0.0625W	6980693
RS-0402-6k2-1%-0.0625W	6986708
RS-0402-6k8-1%-0.0625W	6986701
RS-0402-7k5-1%-0.0625W	6986705
RS-0402-8k2-1%-0.0625W	6986714
RS-0402-9k1-1%-0.0625W	6986717
RS-0402-11k-1%-0.0625W	6986711
RS-0402-12k-1%-0.0625W	6986720
RS-0402-13k-1%-0.0625W	6986723
RS-0402-15k-1%-0.0625W	6986727
RS-0402-16k-1%-0.0625W	6986736
RS-0402-18k-1%-0.0625W	6986739
RS-0402-22k-1%-0.0625W	6986733
RS-0402-24k-1%-0.0625W	6986742
RS-0402-27k-1%-0.0625W	6986745
RS-0402-33k-1%-0.0625W	6986749
RS-0402-36k-1%-0.0625W	6986758
RS-0402-39k-1%-0.0625W	6986751
RS-0402-43k-1%-0.0625W	6986755
RS-0402-47k-1%-0.0625W	6986764
RS-0402-51k-1%-0.0625W	6986767
RS-0402-56k-1%-0.0625W	6986761
RS-0402-62k-1%-0.0625W	6986770
RS-0402-68k-1%-0.0625W	6986773
RS-0402-75k-1%-0.0625W	6986777
RS-0402-82k-1%-0.0625W	6986786
RS-0402-91k-1%-0.0625W	6986789
RS-0402-100k-1%-0.0625W	6986783
RS-0402-110k-1%-0.0625W	6986792
RS-0402-120k-1%-0.0625W	6986795
RS-0402-130k-1%-0.0625W	6986799

**RS 0402 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0402-150k-1%-0.0625W	6986809
RS-0402-160k-1%-0.0625W	6986802
RS-0402-180k-1%-0.0625W	6986806
RS-0402-200k-1%-0.0625W	6986815
RS-0402-220k-1%-0.0625W	6986818
RS-0402-240k-1%-0.0625W	6986812
RS-0402-270k-1%-0.0625W	6986821
RS-0402-300k-1%-0.0625W	6986824
RS-0402-330k-1%-0.0625W	6986828
RS-0402-360k-1%-0.0625W	6986837
RS-0402-390k-1%-0.0625W	6986830
RS-0402-430k-1%-0.0625W	6986834
RS-0402-470k-1%-0.0625W	6986843
RS-0402-510k-1%-0.0625W	6986846
RS-0402-560k-1%-0.0625W	6986840
RS-0402-620k-1%-0.0625W	6986859
RS-0402-680k-1%-0.0625W	6986852
RS-0402-750k-1%-0.0625W	6986856
RS-0402-820k-1%-0.0625W	6986865
RS-0402-910k-1%-0.0625W	6986868

**RS 0603 Series**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-1R-1%-0.1W	7169752
RS-0603-1R02-1%-0.1W	7169755
RS-0603-1R05-1%-0.1W	7169759
RS-0603-1R07-1%-0.1W	7169768
RS-0603-1R1-1%-0.1W	7169761
RS-0603-1R13-1%-0.1W	7169765
RS-0603-1R15-1%-0.1W	7169774
RS-0603-1R18-1%-0.1W	7169777
RS-0603-1R21-1%-0.1W	7169771
RS-0603-1R24-1%-0.1W	7169780
RS-0603-1R27-1%-0.1W	7169783
RS-0603-1R3-1%-0.1W	7169787
RS-0603-1R33-1%-0.1W	7169796
RS-0603-1R37-1%-0.1W	7169799
RS-0603-1R4-1%-0.1W	7169793
RS-0603-1R43-1%-0.1W	7169803
RS-0603-1R47-1%-0.1W	7169806
RS-0603-1R5-1%-0.1W	7169800
RS-0603-1R54-1%-0.1W	7169819
RS-0603-1R58-1%-0.1W	7169812
RS-0603-1R62-1%-0.1W	7169816
RS-0603-1R65-1%-0.1W	7169825
RS-0603-1R69-1%-0.1W	7169828
RS-0603-1R74-1%-0.1W	7169822
RS-0603-1R78-1%-0.1W	7169831
RS-0603-1R82-1%-0.1W	7169834
RS-0603-1R87-1%-0.1W	7169838
RS-0603-1R91-1%-0.1W	7169847

**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-1R96-1%-0.1W	7169840
RS-0603-2R-1%-0.1W	7169844
RS-0603-2R05-1%-0.1W	7169853
RS-0603-2R1-1%-0.1W	7169856
RS-0603-2R21-1%-0.1W	7169869
RS-0603-2R32-1%-0.1W	7169866
RS-0603-2R37-1%-0.1W	7169875
RS-0603-2R43-1%-0.1W	7169878
RS-0603-2R49-1%-0.1W	7169872
RS-0603-2R55-1%-0.1W	7169881
RS-0603-2R61-1%-0.1W	7169884
RS-0603-2R67-1%-0.1W	7169888
RS-0603-2R74-1%-0.1W	7169897
RS-0603-2R8-1%-0.1W	7169890
RS-0603-2R87-1%-0.1W	7169894
RS-0603-2R94-1%-0.1W	7169904
RS-0603-3R01-1%-0.1W	7169907
RS-0603-3R09-1%-0.1W	7169901
RS-0603-3R16-1%-0.1W	7169910
RS-0603-3R24-1%-0.1W	7169913
RS-0603-3R32-1%-0.1W	7169917
RS-0603-3R4-1%-0.1W	7169926
RS-0603-3R48-1%-0.1W	7169929
RS-0603-3R57-1%-0.1W	7169923
RS-0603-3R65-1%-0.1W	7169932
RS-0603-3R74-1%-0.1W	7169935
RS-0603-3R83-1%-0.1W	7169939
RS-0603-3R92-1%-0.1W	7169948
RS-0603-4R02-1%-0.1W	7169941
RS-0603-4R12-1%-0.1W	7169945
RS-0603-4R22-1%-0.1W	7169954
RS-0603-4R32-1%-0.1W	7169957
RS-0603-4R42-1%-0.1W	7169951
RS-0603-4R53-1%-0.1W	7169960
RS-0603-4R64-1%-0.1W	7169963
RS-0603-4R75-1%-0.1W	7169967
RS-0603-4R87-1%-0.1W	7169976
RS-0603-5R11-1%-0.1W	7169973
RS-0603-5R23-1%-0.1W	7169982
RS-0603-5R36-1%-0.1W	7169985
RS-0603-5R49-1%-0.1W	7169989
RS-0603-5R62-1%-0.1W	7169998
RS-0603-5R76-1%-0.1W	7169991
RS-0603-5R9-1%-0.1W	7169995
RS-0603-6R04-1%-0.1W	7170005
RS-0603-6R19-1%-0.1W	7170008
RS-0603-6R34-1%-0.1W	7170002
RS-0603-6R49-1%-0.1W	7170011
RS-0603-6R65-1%-0.1W	7170014
RS-0603-6R81-1%-0.1W	7170018
RS-0603-6R98-1%-0.1W	7170027
RS-0603-7R15-1%-0.1W	7170020
RS-0603-7R32-1%-0.1W	7170024
RS-0603-7R5-1%-0.1W	7170033

**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-7R68-1%-0.1W	7170036
RS-0603-7R87-1%-0.1W	7170030
RS-0603-8R06-1%-0.1W	7170049
RS-0603-8R25-1%-0.1W	7170042
RS-0603-8R45-1%-0.1W	7170046
RS-0603-8R66-1%-0.1W	7170055
RS-0603-8R87-1%-0.1W	7170058
RS-0603-9R09-1%-0.1W	7170052
RS-0603-9R31-1%-0.1W	7170061
RS-0603-9R76-1%-0.1W	7170068
RS-0603-10R2-1%-0.1W	7170077
RS-0603-10R5-1%-0.1W	7170070
RS-0603-10R7-1%-0.1W	7170074
RS-0603-11R3-1%-0.1W	7170083
RS-0603-11R5-1%-0.1W	7170086
RS-0603-11R8-1%-0.1W	7170080
RS-0603-12R1-1%-0.1W	7170099
RS-0603-12R4-1%-0.1W	7170092
RS-0603-12R7-1%-0.1W	7170096
RS-0603-13R3-1%-0.1W	7170106
RS-0603-13R7-1%-0.1W	7170109
RS-0603-14R-1%-0.1W	7170103
RS-0603-14R3-1%-0.1W	7170112
RS-0603-14R7-1%-0.1W	7170115
RS-0603-15R4-1%-0.1W	7170119
RS-0603-15R8-1%-0.1W	7170128
RS-0603-16R2-1%-0.1W	7170121
RS-0603-16R5-1%-0.1W	7170125
RS-0603-16R9-1%-0.1W	7170134
RS-0603-17R4-1%-0.1W	7170137
RS-0603-17R8-1%-0.1W	7170131
RS-0603-18R2-1%-0.1W	7170140
RS-0603-18R7-1%-0.1W	7170143
RS-0603-19R1-1%-0.1W	7170147
RS-0603-19R6-1%-0.1W	7170156
RS-0603-20R5-1%-0.1W	7170159
RS-0603-21R-1%-0.1W	7170153
RS-0603-22R1-1%-0.1W	7170165
RS-0603-23R2-1%-0.1W	7170178
RS-0603-23R7-1%-0.1W	7170171
RS-0603-24R3-1%-0.1W	7170175
RS-0603-24R9-1%-0.1W	7170184
RS-0603-25R5-1%-0.1W	7170187
RS-0603-26R1-1%-0.1W	7170181
RS-0603-26R7-1%-0.1W	7170190
RS-0603-27R4-1%-0.1W	7170193
RS-0603-28R-1%-0.1W	7170197
RS-0603-28R7-1%-0.1W	7170207
RS-0603-29R4-1%-0.1W	7170200
RS-0603-30R1-1%-0.1W	7170204
RS-0603-30R9-1%-0.1W	7170213
RS-0603-31R6-1%-0.1W	7170216
RS-0603-32R4-1%-0.1W	7170210
RS-0603-33R2-1%-0.1W	7170229

**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-34R-1%-0.1W	7170222
RS-0603-34R8-1%-0.1W	7170226
RS-0603-35R7-1%-0.1W	7170235
RS-0603-36R5-1%-0.1W	7170238
RS-0603-37R4-1%-0.1W	7170232
RS-0603-38R3-1%-0.1W	7170241
RS-0603-39R2-1%-0.1W	7170244
RS-0603-40R2-1%-0.1W	7170248
RS-0603-41R2-1%-0.1W	7170257
RS-0603-42R2-1%-0.1W	7170250
RS-0603-43R2-1%-0.1W	7170254
RS-0603-44R2-1%-0.1W	7170263
RS-0603-45R3-1%-0.1W	7170266
RS-0603-46R4-1%-0.1W	7170260
RS-0603-47R5-1%-0.1W	7170279
RS-0603-48R7-1%-0.1W	7170272
RS-0603-51R1-1%-0.1W	7170285
RS-0603-52R3-1%-0.1W	7170288
RS-0603-53R6-1%-0.1W	7170282
RS-0603-54R9-1%-0.1W	7170291
RS-0603-56R2-1%-0.1W	7170294
RS-0603-57R6-1%-0.1W	7170298
RS-0603-59R-1%-0.1W	7170308
RS-0603-60R4-1%-0.1W	7170301
RS-0603-61R9-1%-0.1W	7170305
RS-0603-63R4-1%-0.1W	7170314
RS-0603-64R9-1%-0.1W	7170317
RS-0603-66R5-1%-0.1W	7170311
RS-0603-68R1-1%-0.1W	7170320
RS-0603-69R8-1%-0.1W	7170323
RS-0603-71R5-1%-0.1W	7170327
RS-0603-73R2-1%-0.1W	7170336
RS-0603-76R8-1%-0.1W	7170339
RS-0603-78R7-1%-0.1W	7170333
RS-0603-80R6-1%-0.1W	7170342
RS-0603-82R5-1%-0.1W	7170345
RS-0603-84R5-1%-0.1W	7170349
RS-0603-86R6-1%-0.1W	7170358
RS-0603-88R7-1%-0.1W	7170351
RS-0603-90R9-1%-0.1W	7170355
RS-0603-93R1-1%-0.1W	7170364
RS-0603-97R6-1%-0.1W	7170361
RS-0603-102R-1%-0.1W	7170370
RS-0603-105R-1%-0.1W	7170373
RS-0603-107R-1%-0.1W	7170377
RS-0603-113R-1%-0.1W	7170386
RS-0603-115R-1%-0.1W	7170389
RS-0603-118R-1%-0.1W	7170383
RS-0603-121R-1%-0.1W	7170392
RS-0603-124R-1%-0.1W	7170395
RS-0603-127R-1%-0.1W	7170399
RS-0603-133R-1%-0.1W	7170409
RS-0603-137R-1%-0.1W	7170402
RS-0603-140R-1%-0.1W	7170406



**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-143R-1%-0.1W	7170415
RS-0603-147R-1%-0.1W	7170418
RS-0603-154R-1%-0.1W	7170412
RS-0603-158R-1%-0.1W	7170421
RS-0603-162R-1%-0.1W	7170424
RS-0603-165R-1%-0.1W	7170428
RS-0603-169R-1%-0.1W	7170437
RS-0603-174R-1%-0.1W	7170430
RS-0603-178R-1%-0.1W	7170434
RS-0603-182R-1%-0.1W	7170443
RS-0603-187R-1%-0.1W	7170446
RS-0603-191R-1%-0.1W	7170440
RS-0603-196R-1%-0.1W	7170459
RS-0603-205R-1%-0.1W	7170452
RS-0603-210R-1%-0.1W	7170456
RS-0603-221R-1%-0.1W	7170468
RS-0603-232R-1%-0.1W	7170471
RS-0603-237R-1%-0.1W	7170474
RS-0603-243R-1%-0.1W	7170478
RS-0603-249R-1%-0.1W	7170487
RS-0603-255R-1%-0.1W	7170480
RS-0603-261R-1%-0.1W	7170484
RS-0603-267R-1%-0.1W	7170493
RS-0603-274R-1%-0.1W	7170496
RS-0603-280R-1%-0.1W	7170490
RS-0603-287R-1%-0.1W	7170500
RS-0603-294R-1%-0.1W	7170503
RS-0603-301R-1%-0.1W	7170507
RS-0603-309R-1%-0.1W	7170516
RS-0603-316R-1%-0.1W	7170519
RS-0603-324R-1%-0.1W	7170513
RS-0603-332R-1%-0.1W	7170522
RS-0603-340R-1%-0.1W	7170525
RS-0603-348R-1%-0.1W	7170529
RS-0603-357R-1%-0.1W	7170538
RS-0603-365R-1%-0.1W	7170531
RS-0603-374R-1%-0.1W	7170535
RS-0603-383R-1%-0.1W	7170544
RS-0603-392R-1%-0.1W	7170547
RS-0603-402R-1%-0.1W	7170541
RS-0603-412R-1%-0.1W	7170550
RS-0603-422R-1%-0.1W	7170553
RS-0603-432R-1%-0.1W	7170557
RS-0603-442R-1%-0.1W	7170566
RS-0603-453R-1%-0.1W	7170569
RS-0603-464R-1%-0.1W	7170563
RS-0603-475R-1%-0.1W	7170572
RS-0603-487R-1%-0.1W	7170575
RS-0603-511R-1%-0.1W	7170588
RS-0603-523R-1%-0.1W	7170581
RS-0603-536R-1%-0.1W	7170585
RS-0603-549R-1%-0.1W	7170594
RS-0603-562R-1%-0.1W	7170597
RS-0603-576R-1%-0.1W	7170591

**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-590R-1%-0.1W	7170601
RS-0603-604R-1%-0.1W	7170604
RS-0603-619R-1%-0.1W	7170608
RS-0603-634R-1%-0.1W	7170617
RS-0603-649R-1%-0.1W	7170610
RS-0603-665R-1%-0.1W	7170614
RS-0603-681R-1%-0.1W	7170623
RS-0603-698R-1%-0.1W	7170626
RS-0603-715R-1%-0.1W	7170620
RS-0603-732R-1%-0.1W	7170639
RS-0603-768R-1%-0.1W	7170632
RS-0603-787R-1%-0.1W	7170636
RS-0603-806R-1%-0.1W	7170645
RS-0603-825R-1%-0.1W	7170648
RS-0603-845R-1%-0.1W	7170642
RS-0603-866R-1%-0.1W	7170651
RS-0603-887R-1%-0.1W	7170654
RS-0603-909R-1%-0.1W	7170658
RS-0603-931R-1%-0.1W	7170667
RS-0603-976R-1%-0.1W	7170664
RS-0603-1k02-1%-0.1W	7170673
RS-0603-1k05-1%-0.1W	7170676
RS-0603-1k07-1%-0.1W	7170670
RS-0603-1k13-1%-0.1W	7170689
RS-0603-1k15-1%-0.1W	7170682
RS-0603-1k18-1%-0.1W	7170686
RS-0603-1k21-1%-0.1W	7170695
RS-0603-1k24-1%-0.1W	7170698
RS-0603-1k27-1%-0.1W	7170692
RS-0603-1k30-1%-0.1W	7170702
RS-0603-1k33-1%-0.1W	7170705
RS-0603-1k37-1%-0.1W	7170709
RS-0603-1k40-1%-0.1W	7170718
RS-0603-1k43-1%-0.1W	7170711
RS-0603-1k47-1%-0.1W	7170715
RS-0603-1k54-1%-0.1W	7170724
RS-0603-1k58-1%-0.1W	7170727
RS-0603-1k62-1%-0.1W	7170721
RS-0603-1k65-1%-0.1W	7170730
RS-0603-1k69-1%-0.1W	7170733
RS-0603-1k74-1%-0.1W	7170737
RS-0603-1k78-1%-0.1W	7170746
RS-0603-1k82-1%-0.1W	7170749
RS-0603-1k87-1%-0.1W	7170743
RS-0603-1k91-1%-0.1W	7170752
RS-0603-1k96-1%-0.1W	7170755
RS-0603-2k05-1%-0.1W	7170759
RS-0603-2k10-1%-0.1W	7170768
RS-0603-2k21-1%-0.1W	7170765
RS-0603-2k32-1%-0.1W	7170777
RS-0603-2k37-1%-0.1W	7170771
RS-0603-2k43-1%-0.1W	7170780
RS-0603-2k49-1%-0.1W	7170783
RS-0603-2k55-1%-0.1W	7170787

**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-2k61-1%-0.1W	7170796
RS-0603-2k67-1%-0.1W	7170799
RS-0603-2k74-1%-0.1W	7170793
RS-0603-2k80-1%-0.1W	7170803
RS-0603-2k87-1%-0.1W	7170806
RS-0603-2k94-1%-0.1W	7170800
RS-0603-3k01-1%-0.1W	7170819
RS-0603-3k09-1%-0.1W	7170812
RS-0603-3k16-1%-0.1W	7170816
RS-0603-3k24-1%-0.1W	7170825
RS-0603-3k32-1%-0.1W	7170828
RS-0603-3k40-1%-0.1W	7170822
RS-0603-3k48-1%-0.1W	7170831
RS-0603-3k57-1%-0.1W	7170834
RS-0603-3k65-1%-0.1W	7170838
RS-0603-3k74-1%-0.1W	7170847
RS-0603-3k83-1%-0.1W	7170840
RS-0603-3k92-1%-0.1W	7170844
RS-0603-4k02-1%-0.1W	7170853
RS-0603-4k12-1%-0.1W	7170856
RS-0603-4k22-1%-0.1W	7170850
RS-0603-4k32-1%-0.1W	7170869
RS-0603-4k42-1%-0.1W	7170862
RS-0603-4k53-1%-0.1W	7170866
RS-0603-4k64-1%-0.1W	7170875
RS-0603-4k75-1%-0.1W	7170878
RS-0603-4k87-1%-0.1W	7170872
RS-0603-5k11-1%-0.1W	7170884
RS-0603-5k23-1%-0.1W	7170888
RS-0603-5k36-1%-0.1W	7170897
RS-0603-5k49-1%-0.1W	7170890
RS-0603-5k62-1%-0.1W	7170894
RS-0603-5k76-1%-0.1W	7170904
RS-0603-5k90-1%-0.1W	7170907
RS-0603-6k04-1%-0.1W	7170901
RS-0603-6k19-1%-0.1W	7170910
RS-0603-6k34-1%-0.1W	7170913
RS-0603-6k49-1%-0.1W	7170917
RS-0603-6k65-1%-0.1W	7170926
RS-0603-6k81-1%-0.1W	7170929
RS-0603-6k98-1%-0.1W	7170923
RS-0603-7k15-1%-0.1W	7170932
RS-0603-7k32-1%-0.1W	7170935
RS-0603-7k68-1%-0.1W	7170939
RS-0603-7k87-1%-0.1W	7170948
RS-0603-8k06-1%-0.1W	7170941
RS-0603-8k25-1%-0.1W	7170945
RS-0603-8k45-1%-0.1W	7170954
RS-0603-8k66-1%-0.1W	7170957
RS-0603-8k87-1%-0.1W	7170951
RS-0603-9k09-1%-0.1W	7170960
RS-0603-9k31-1%-0.1W	7170963
RS-0603-9k76-1%-0.1W	7170976
RS-0603-10k2-1%-0.1W	7170979

**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-10k5-1%-0.1W	7170973
RS-0603-10k7-1%-0.1W	7170982
RS-0603-11k3-1%-0.1W	7170985
RS-0603-11k5-1%-0.1W	7170989
RS-0603-11k8-1%-0.1W	7170998
RS-0603-12k1-1%-0.1W	7170991
RS-0603-12k4-1%-0.1W	7170995
RS-0603-12k7-1%-0.1W	7171008
RS-0603-13k3-1%-0.1W	7171001
RS-0603-13k7-1%-0.1W	7171005
RS-0603-14K-1%-0.1W	7171014
RS-0603-14k3-1%-0.1W	7171017
RS-0603-14k7-1%-0.1W	7171011
RS-0603-15k4-1%-0.1W	7171020
RS-0603-15k8-1%-0.1W	7171023
RS-0603-16k2-1%-0.1W	7171027
RS-0603-16k5-1%-0.1W	7171036
RS-0603-16k9-1%-0.1W	7171039
RS-0603-17k4-1%-0.1W	7171033
RS-0603-17k8-1%-0.1W	7171042
RS-0603-18k2-1%-0.1W	7171045
RS-0603-18k7-1%-0.1W	7171049
RS-0603-19k1-1%-0.1W	7171058
RS-0603-19k6-1%-0.1W	7171051
RS-0603-20k5-1%-0.1W	7171055
RS-0603-21K-1%-0.1W	7171064
RS-0603-22k1-1%-0.1W	7171061
RS-0603-23k2-1%-0.1W	7171073
RS-0603-23k7-1%-0.1W	7171077
RS-0603-24k3-1%-0.1W	7171086
RS-0603-24k9-1%-0.1W	7171089
RS-0603-25k5-1%-0.1W	7171083
RS-0603-26k1-1%-0.1W	7171092
RS-0603-26k7-1%-0.1W	7171095
RS-0603-27k4-1%-0.1W	7171099
RS-0603-28K-1%-0.1W	7171109
RS-0603-28k7-1%-0.1W	7171102
RS-0603-29k4-1%-0.1W	7171106
RS-0603-30k1-1%-0.1W	7171115
RS-0603-30k9-1%-0.1W	7171118
RS-0603-31k6-1%-0.1W	7171112
RS-0603-32k4-1%-0.1W	7171121
RS-0603-33k2-1%-0.1W	7171124
RS-0603-34K-1%-0.1W	7171128
RS-0603-34k8-1%-0.1W	7171137
RS-0603-35k7-1%-0.1W	7171130
RS-0603-36k5-1%-0.1W	7171134
RS-0603-37k4-1%-0.1W	7171143
RS-0603-38k3-1%-0.1W	7171146
RS-0603-39k2-1%-0.1W	7171140
RS-0603-40k2-1%-0.1W	7171159
RS-0603-41k2-1%-0.1W	7171152
RS-0603-42k2-1%-0.1W	7171156
RS-0603-43k2-1%-0.1W	7171165

**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-44k2-1%-0.1W	7171168
RS-0603-45k3-1%-0.1W	7171162
RS-0603-46k4-1%-0.1W	7171171
RS-0603-47k5-1%-0.1W	7171174
RS-0603-48k7-1%-0.1W	7171178
RS-0603-51k1-1%-0.1W	7171180
RS-0603-52k3-1%-0.1W	7171184
RS-0603-53k6-1%-0.1W	7171193
RS-0603-54k9-1%-0.1W	7171196
RS-0603-56k2-1%-0.1W	7171190
RS-0603-57k6-1%-0.1W	7171200
RS-0603-59K-1%-0.1W	7171203
RS-0603-60k4-1%-0.1W	7171207
RS-0603-61k9-1%-0.1W	7171216
RS-0603-63k4-1%-0.1W	7171219
RS-0603-64k9-1%-0.1W	7171213
RS-0603-66k5-1%-0.1W	7171222
RS-0603-68k1-1%-0.1W	7171225
RS-0603-69k8-1%-0.1W	7171229
RS-0603-71k5-1%-0.1W	7171238
RS-0603-73k2-1%-0.1W	7171231
RS-0603-76k8-1%-0.1W	7171235
RS-0603-78k7-1%-0.1W	7171244
RS-0603-80k6-1%-0.1W	7171247
RS-0603-82k5-1%-0.1W	7171241
RS-0603-84k5-1%-0.1W	7171250
RS-0603-86k6-1%-0.1W	7171253
RS-0603-88k7-1%-0.1W	7171257
RS-0603-90k9-1%-0.1W	7171266
RS-0603-93k1-1%-0.1W	7171269
RS-0603-97K6-1%-0.1W	7171272
RS-0603-102K-1%-0.1W	7171275
RS-0603-105K-1%-0.1W	7171279
RS-0603-107K-1%-0.1W	7171288
RS-0603-113K-1%-0.1W	7171281
RS-0603-115K-1%-0.1W	7171285
RS-0603-118K-1%-0.1W	7171294
RS-0603-121K-1%-0.1W	7171297
RS-0603-124K-1%-0.1W	7171291
RS-0603-127K-1%-0.1W	7171301
RS-0603-133K-1%-0.1W	7171304
RS-0603-137K-1%-0.1W	7171308
RS-0603-140K-1%-0.1W	7171317
RS-0603-143K-1%-0.1W	7171310
RS-0603-147K-1%-0.1W	7171314
RS-0603-154K-1%-0.1W	7171323
RS-0603-158K-1%-0.1W	7171326
RS-0603-162K-1%-0.1W	7171320
RS-0603-165K-1%-0.1W	7171339
RS-0603-169K-1%-0.1W	7171332
RS-0603-174K-1%-0.1W	7171336
RS-0603-178K-1%-0.1W	7171345
RS-0603-182K-1%-0.1W	7171348
RS-0603-187K-1%-0.1W	7171342

**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-191K-1%-0.1W	7171351
RS-0603-196K-1%-0.1W	7171354
RS-0603-205K-1%-0.1W	7171358
RS-0603-210K-1%-0.1W	7171367
RS-0603-221K-1%-0.1W	7171364
RS-0603-232K-1%-0.1W	7171376
RS-0603-237K-1%-0.1W	7171370
RS-0603-243K-1%-0.1W	7171389
RS-0603-249K-1%-0.1W	7171382
RS-0603-255K-1%-0.1W	7171386
RS-0603-261K-1%-0.1W	7171395
RS-0603-267K-1%-0.1W	7171398
RS-0603-274K-1%-0.1W	7171392
RS-0603-280K-1%-0.1W	7171402
RS-0603-287K-1%-0.1W	7171405
RS-0603-294K-1%-0.1W	7171409
RS-0603-301K-1%-0.1W	7171418
RS-0603-309K-1%-0.1W	7171411
RS-0603-316K-1%-0.1W	7171415
RS-0603-324K-1%-0.1W	7171424
RS-0603-332K-1%-0.1W	7171427
RS-0603-340K-1%-0.1W	7171421
RS-0603-348K-1%-0.1W	7171430
RS-0603-357K-1%-0.1W	7171433
RS-0603-365K-1%-0.1W	7171437
RS-0603-374K-1%-0.1W	7171446
RS-0603-383K-1%-0.1W	7171449
RS-0603-392K-1%-0.1W	7171443
RS-0603-402K-1%-0.1W	7171452
RS-0603-412K-1%-0.1W	7171455
RS-0603-422K-1%-0.1W	7171459
RS-0603-432K-1%-0.1W	7171468
RS-0603-442K-1%-0.1W	7171461
RS-0603-453K-1%-0.1W	7171465
RS-0603-464K-1%-0.1W	7171474
RS-0603-475K-1%-0.1W	7171477
RS-0603-487K-1%-0.1W	7171471
RS-0603-511K-1%-0.1W	7171483
RS-0603-523K-1%-0.1W	7171487
RS-0603-536K-1%-0.1W	7171496
RS-0603-549K-1%-0.1W	7171499
RS-0603-562K-1%-0.1W	7171493
RS-0603-576K-1%-0.1W	7171503
RS-0603-590K-1%-0.1W	7171506
RS-0603-604K-1%-0.1W	7171500
RS-0603-619K-1%-0.1W	7171519
RS-0603-634K-1%-0.1W	7171512
RS-0603-649K-1%-0.1W	7171516
RS-0603-665K-1%-0.1W	7171525
RS-0603-681K-1%-0.1W	7171528
RS-0603-698K-1%-0.1W	7171522
RS-0603-715K-1%-0.1W	7171531
RS-0603-732K-1%-0.1W	7171534
RS-0603-768K-1%-0.1W	7171538



---

RS-0603-787K-1%-0.1W	7171547
RS-0603-806K-1%-0.1W	7171540
RS-0603-825K-1%-0.1W	7171544
RS-0603-845K-1%-0.1W	7171553
RS-0603-866K-1%-0.1W	7171556
RS-0603-887K-1%-0.1W	7171550
RS-0603-909K-1%-0.1W	7171569
RS-0603-931K-1%-0.1W	7171562
RS-0603-976K-1%-0.1W	7171575
RS-0603-10R-1%-0.1W	697-9084
RS-0603-11R-1%-0.1W	697-9097
RS-0603-12R-1%-0.1W	697-9090
RS-0603-13R-1%-0.1W	697-9094
RS-0603-15R-1%-0.1W	697-9104
RS-0603-16R-1%-0.1W	697-9107
RS-0603-18R-1%-0.1W	697-9101
RS-0603-20R-1%-0.1W	697-9110
RS-0603-22R-1%-0.1W	697-9113
RS-0603-24R-1%-0.1W	697-9117
RS-0603-27R-1%-0.1W	697-9126
RS-0603-30R-1%-0.1W	697-9129
RS-0603-33R-1%-0.1W	697-9123
RS-0603-36R-1%-0.1W	697-9132
RS-0603-39R-1%-0.1W	697-9135
RS-0603-43R-1%-0.1W	697-9139
RS-0603-47R-1%-0.1W	697-9148
RS-0603-51R-1%-0.1W	697-9141
RS-0603-56R-1%-0.1W	697-9145
RS-0603-62R-1%-0.1W	697-9154
RS-0603-68R-1%-0.1W	697-9157
RS-0603-75R-1%-0.1W	697-9151
RS-0603-82R-1%-0.1W	697-9160
RS-0603-91R-1%-0.1W	697-9163
RS-0603-100R-1%-0.1W	697-9167
RS-0603-110R-1%-0.1W	697-9176
RS-0603-120R-1%-0.1W	697-9179
RS-0603-130R-1%-0.1W	697-9173
RS-0603-150R-1%-0.1W	697-9182
RS-0603-160R-1%-0.1W	697-9185
RS-0603-180R-1%-0.1W	697-9189
RS-0603-200R-1%-0.1W	697-9198
RS-0603-220R-1%-0.1W	697-9191
RS-0603-240R-1%-0.1W	697-9195
RS-0603-270R-1%-0.1W	697-9205
RS-0603-300R-1%-0.1W	697-9208
RS-0603-330R-1%-0.1W	697-9202
RS-0603-360R-1%-0.1W	697-9211
RS-0603-390R-1%-0.1W	697-9214
RS-0603-430R-1%-0.1W	697-9218
RS-0603-470R-1%-0.1W	697-9227
RS-0603-510R-1%-0.1W	697-9220
RS-0603-560R-1%-0.1W	697-9224
RS-0603-620R-1%-0.1W	697-9233
RS-0603-680R-1%-0.1W	697-9236
RS-0603-750R-1%-0.1W	697-9230
RS-0603-820R-1%-0.1W	697-9249

**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-910R-1%-0.1W	697-9242
RS-0603-1k-1%-0.1W	697-9246
RS-0603-1k1-1%-0.1W	697-9255
RS-0603-1k2-1%-0.1W	697-9258
RS-0603-1k3-1%-0.1W	697-9252
RS-0603-1k5-1%-0.1W	697-9261
RS-0603-1k6-1%-0.1W	697-9264
RS-0603-1k8-1%-0.1W	697-9268
RS-0603-2k-1%-0.1W	697-9277
RS-0603-2k2-1%-0.1W	697-9270
RS-0603-2k4-1%-0.1W	697-9274
RS-0603-2k7-1%-0.1W	697-9283
RS-0603-3k-1%-0.1W	697-9286
RS-0603-3k3-1%-0.1W	697-9280
RS-0603-3k6-1%-0.1W	697-9299
RS-0603-3k9-1%-0.1W	697-9292
RS-0603-4k3-1%-0.1W	697-9296
RS-0603-4k7-1%-0.1W	697-9306
RS-0603-5k1-1%-0.1W	697-9309
RS-0603-5k6-1%-0.1W	697-9303
RS-0603-6k2-1%-0.1W	697-9312
RS-0603-6k8-1%-0.1W	697-9315
RS-0603-7k5-1%-0.1W	697-9319
RS-0603-8k2-1%-0.1W	697-9328
RS-0603-9k1-1%-0.1W	697-9321
RS-0603-10k-1%-0.1W	697-9325
RS-0603-11k-1%-0.1W	697-9334
RS-0603-12k-1%-0.1W	697-9337
RS-0603-13k-1%-0.1W	697-9331
RS-0603-15k-1%-0.1W	697-9340
RS-0603-16k-1%-0.1W	697-9343
RS-0603-18k-1%-0.1W	697-9347
RS-0603-20k-1%-0.1W	697-9356
RS-0603-22k-1%-0.1W	697-9359
RS-0603-24k-1%-0.1W	697-9353
RS-0603-27k-1%-0.1W	697-9362
RS-0603-30k-1%-0.1W	697-9369
RS-0603-33k-1%-0.1W	697-9378
RS-0603-36k-1%-0.1W	697-9371
RS-0603-39k-1%-0.1W	697-9375
RS-0603-43k-1%-0.1W	697-9384
RS-0603-47k-1%-0.1W	697-9387
RS-0603-51k-1%-0.1W	697-9381
RS-0603-56k-1%-0.1W	697-9393
RS-0603-62k-1%-0.1W	697-9397
RS-0603-68k-1%-0.1W	697-9404
RS-0603-75k-1%-0.1W	697-9416
RS-0603-82k-1%-0.1W	697-9429
RS-0603-91k-1%-0.1W	697-9426
RS-0603-100k-1%-0.1W	697-9438
RS-0603-110k-1%-0.1W	697-9432
RS-0603-120k-1%-0.1W	697-9444
RS-0603-130k-1%-0.1W	697-9457
RS-0603-150k-1%-0.1W	697-9466



**RS 0603 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0603-160k-1%-0.1W	697-9485
RS-0603-180k-1%-0.1W	697-9488
RS-0603-200k-1%-0.1W	697-9494
RS-0603-220k-1%-0.1W	697-9508
RS-0603-240k-1%-0.1W	697-9505
RS-0603-270k-1%-0.1W	697-9520
RS-0603-300k-1%-0.1W	697-9527
RS-0603-330k-1%-0.1W	697-9539
RS-0603-360k-1%-0.1W	697-9542
RS-0603-390k-1%-0.1W	697-9549
RS-0603-430k-1%-0.1W	697-9551
RS-0603-470k-1%-0.1W	697-9564
RS-0603-510k-1%-0.1W	697-9561
RS-0603-560k-1%-0.1W	697-9573
RS-0603-620k-1%-0.1W	697-9586
RS-0603-680k-1%-0.1W	697-9583
RS-0603-750k-1%-0.1W	697-9595
RS-0603-820k-1%-0.1W	697-9609
RS-0603-910k-1%-0.1W	697-9606

**RS 0805 Series**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-1R-1%-0.125W	7171572
RS-0805-1R02-1%-0.125W	7171581
RS-0805-1R05-1%-0.125W	7171584
RS-0805-1R07-1%-0.125W	7171588
RS-0805-1R1-1%-0.125W	7171597
RS-0805-1R13-1%-0.125W	7171590
RS-0805-1R15-1%-0.125W	7171594
RS-0805-1R18-1%-0.125W	7171604
RS-0805-1R21-1%-0.125W	7171607
RS-0805-1R24-1%-0.125W	7171601
RS-0805-1R27-1%-0.125W	7171610
RS-0805-1R3-1%-0.125W	7171613
RS-0805-1R33-1%-0.125W	7171617
RS-0805-1R37-1%-0.125W	7171626
RS-0805-1R4-1%-0.125W	7171629
RS-0805-1R43-1%-0.125W	7171623
RS-0805-1R47-1%-0.125W	7171632
RS-0805-1R5-1%-0.125W	7171635
RS-0805-1R54-1%-0.125W	7171639
RS-0805-1R58-1%-0.125W	7171648
RS-0805-1R62-1%-0.125W	7171641
RS-0805-1R65-1%-0.125W	7171645
RS-0805-1R69-1%-0.125W	7171654
RS-0805-1R74-1%-0.125W	7171657
RS-0805-1R78-1%-0.125W	7171651
RS-0805-1R82-1%-0.125W	7171660
RS-0805-1R87-1%-0.125W	7171663
RS-0805-1R91-1%-0.125W	7171667
RS-0805-1R96-1%-0.125W	7171676
RS-0805-2R-1%-0.125W	7171679



---

RS-0805-2R05-1%-0.125W	7171673
RS-0805-2R1-1%-0.125W	7171682
RS-0805-2R21-1%-0.125W	7171689
RS-0805-2R32-1%-0.125W	7171691
RS-0805-2R37-1%-0.125W	7171695
RS-0805-2R43-1%-0.125W	7171705
RS-0805-2R49-1%-0.125W	7171708
RS-0805-2R55-1%-0.125W	7171702
RS-0805-2R61-1%-0.125W	7171711
RS-0805-2R67-1%-0.125W	7171714
RS-0805-2R74-1%-0.125W	7171718
RS-0805-2R8-1%-0.125W	7171727
RS-0805-2R87-1%-0.125W	7171720
RS-0805-2R94-1%-0.125W	7171724
RS-0805-3R01-1%-0.125W	7171733
RS-0805-3R09-1%-0.125W	7171736
RS-0805-3R16-1%-0.125W	7171730
RS-0805-3R24-1%-0.125W	7171749
RS-0805-3R32-1%-0.125W	7171742
RS-0805-3R4-1%-0.125W	7171746
RS-0805-3R48-1%-0.125W	7171755
RS-0805-3R57-1%-0.125W	7171758
RS-0805-3R65-1%-0.125W	7171752
RS-0805-3R74-1%-0.125W	7171761
RS-0805-3R83-1%-0.125W	7171764
RS-0805-3R92-1%-0.125W	7171768
RS-0805-4R02-1%-0.125W	7171777
RS-0805-4R12-1%-0.125W	7171770
RS-0805-4R22-1%-0.125W	7171774
RS-0805-4R32-1%-0.125W	7171783
RS-0805-4R42-1%-0.125W	7171786
RS-0805-4R53-1%-0.125W	7171780
RS-0805-4R64-1%-0.125W	7171799
RS-0805-4R75-1%-0.125W	7171792
RS-0805-4R87-1%-0.125W	7171796
RS-0805-5R11-1%-0.125W	7171809
RS-0805-5R23-1%-0.125W	7171803
RS-0805-5R36-1%-0.125W	7171812
RS-0805-5R49-1%-0.125W	7171815
RS-0805-5R62-1%-0.125W	7171819
RS-0805-5R76-1%-0.125W	7171828
RS-0805-5R9-1%-0.125W	7171821
RS-0805-6R04-1%-0.125W	7171825
RS-0805-6R19-1%-0.125W	7171834
RS-0805-6R34-1%-0.125W	7171837
RS-0805-6R49-1%-0.125W	7171831
RS-0805-6R65-1%-0.125W	7171840
RS-0805-6R81-1%-0.125W	7171843
RS-0805-6R98-1%-0.125W	7171847
RS-0805-7R15-1%-0.125W	7171856
RS-0805-7R32-1%-0.125W	7171859
RS-0805-7R5-1%-0.125W	7171853
RS-0805-7R68-1%-0.125W	7171862
RS-0805-7R87-1%-0.125W	7171865
RS-0805-8R06-1%-0.125W	7171869

**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-8R25-1%-0.125W	7171878
RS-0805-8R45-1%-0.125W	7171871
RS-0805-8R66-1%-0.125W	7171875
RS-0805-8R87-1%-0.125W	7171884
RS-0805-9R09-1%-0.125W	7171887
RS-0805-9R31-1%-0.125W	7171881
RS-0805-9R76-1%-0.125W	7171893
RS-0805-10R2-1%-0.125W	7171897
RS-0805-10R5-1%-0.125W	7171907
RS-0805-10R7-1%-0.125W	7171900
RS-0805-11R3-1%-0.125W	7171904
RS-0805-11R5-1%-0.125W	7171913
RS-0805-11R8-1%-0.125W	7171916
RS-0805-12R1-1%-0.125W	7171910
RS-0805-12R4-1%-0.125W	7171929
RS-0805-12R7-1%-0.125W	7171922
RS-0805-13R3-1%-0.125W	7171926
RS-0805-13R7-1%-0.125W	7171935
RS-0805-14R-1%-0.125W	7171938
RS-0805-14R3-1%-0.125W	7171932
RS-0805-14R7-1%-0.125W	7171941
RS-0805-15R4-1%-0.125W	7171944
RS-0805-15R8-1%-0.125W	7171948
RS-0805-16R2-1%-0.125W	7171957
RS-0805-16R5-1%-0.125W	7171950
RS-0805-16R9-1%-0.125W	7171954
RS-0805-17R4-1%-0.125W	7171963
RS-0805-17R8-1%-0.125W	7171966
RS-0805-18R2-1%-0.125W	7171960
RS-0805-18R7-1%-0.125W	7171979
RS-0805-19R1-1%-0.125W	7171972
RS-0805-19R6-1%-0.125W	7171976
RS-0805-20R5-1%-0.125W	7171985
RS-0805-21R-1%-0.125W	7171988
RS-0805-22R1-1%-0.125W	7171991
RS-0805-23R6-1%-0.125W	7171994
RS-0805-23R2-1%-0.125W	7171998
RS-0805-23R7-1%-0.125W	7172001
RS-0805-24R3-1%-0.125W	7172004
RS-0805-24R9-1%-0.125W	7172008
RS-0805-25R5-1%-0.125W	7172017
RS-0805-26R1-1%-0.125W	7172010
RS-0805-26R7-1%-0.125W	7172014
RS-0805-27R4-1%-0.125W	7172023
RS-0805-28R-1%-0.125W	7172026
RS-0805-28R7-1%-0.125W	7172020
RS-0805-29R4-1%-0.125W	7172039
RS-0805-30R1-1%-0.125W	7172032
RS-0805-30R9-1%-0.125W	7172036
RS-0805-31R6-1%-0.125W	7172045
RS-0805-32R4-1%-0.125W	7172048
RS-0805-33R2-1%-0.125W	7172042
RS-0805-34R-1%-0.125W	7172051
RS-0805-34R8-1%-0.125W	7172054



**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-35R7-1%-0.125W	7172058
RS-0805-36R5-1%-0.125W	7172067
RS-0805-37R4-1%-0.125W	7172060
RS-0805-38R3-1%-0.125W	7172064
RS-0805-39R2-1%-0.125W	7172073
RS-0805-40R2-1%-0.125W	7172076
RS-0805-41R2-1%-0.125W	7172070
RS-0805-42R2-1%-0.125W	7172089
RS-0805-43R2-1%-0.125W	7172082
RS-0805-44R2-1%-0.125W	7172086
RS-0805-45R3-1%-0.125W	7172095
RS-0805-46R4-1%-0.125W	7172098
RS-0805-47R5-1%-0.125W	7172092
RS-0805-48R7-1%-0.125W	7172102
RS-0805-51R1-1%-0.125W	7172109
RS-0805-52R3-1%-0.125W	7172118
RS-0805-53R6-1%-0.125W	7172111
RS-0805-54R9-1%-0.125W	7172115
RS-0805-56R2-1%-0.125W	7172124
RS-0805-57R6-1%-0.125W	7172127
RS-0805-59R-1%-0.125W	7172121
RS-0805-60R4-1%-0.125W	7172130
RS-0805-61R9-1%-0.125W	7172133
RS-0805-63R4-1%-0.125W	7172137
RS-0805-64R9-1%-0.125W	7172146
RS-0805-66R5-1%-0.125W	7172149
RS-0805-68R1-1%-0.125W	7172143
RS-0805-69R8-1%-0.125W	7172152
RS-0805-71R5-1%-0.125W	7172155
RS-0805-73R2-1%-0.125W	7172159
RS-0805-76R8-1%-0.125W	7172168
RS-0805-78R7-1%-0.125W	7172161
RS-0805-80R6-1%-0.125W	7172165
RS-0805-82R5-1%-0.125W	7172174
RS-0805-84R5-1%-0.125W	7172177
RS-0805-86R6-1%-0.125W	7172171
RS-0805-88R7-1%-0.125W	7172180
RS-0805-90R9-1%-0.125W	7172183
RS-0805-93R1-1%-0.125W	7172187
RS-0805-97R6-1%-0.125W	7172199
RS-0805-102R-1%-0.125W	7172193
RS-0805-105R-1%-0.125W	7172203
RS-0805-107R-1%-0.125W	7172206
RS-0805-113R-1%-0.125W	7172200
RS-0805-115R-1%-0.125W	7172219
RS-0805-118R-1%-0.125W	7172212
RS-0805-121R-1%-0.125W	7172216
RS-0805-124R-1%-0.125W	7172225
RS-0805-127R-1%-0.125W	7172228
RS-0805-133R-1%-0.125W	7172222
RS-0805-137R-1%-0.125W	7172231
RS-0805-140R-1%-0.125W	7172234
RS-0805-143R-1%-0.125W	7172238
RS-0805-147R-1%-0.125W	7172247

**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-154R-1%-0.125W	7172240
RS-0805-158R-1%-0.125W	7172244
RS-0805-162R-1%-0.125W	7172253
RS-0805-165R-1%-0.125W	7172256
RS-0805-169R-1%-0.125W	7172250
RS-0805-174R-1%-0.125W	7172269
RS-0805-178R-1%-0.125W	7172262
RS-0805-182R-1%-0.125W	7172266
RS-0805-187R-1%-0.125W	7172275
RS-0805-191R-1%-0.125W	7172278
RS-0805-196R-1%-0.125W	7172272
RS-0805-205R-1%-0.125W	7172281
RS-0805-210R-1%-0.125W	7172284
RS-0805-221R-1%-0.125W	7172297
RS-0805-232R-1%-0.125W	7172294
RS-0805-237R-1%-0.125W	7172304
RS-0805-243R-1%-0.125W	7172307
RS-0805-249R-1%-0.125W	7172301
RS-0805-255R-1%-0.125W	7172310
RS-0805-261R-1%-0.125W	7172313
RS-0805-267R-1%-0.125W	7172317
RS-0805-274R-1%-0.125W	7172326
RS-0805-280R-1%-0.125W	7172329
RS-0805-287R-1%-0.125W	7172323
RS-0805-294R-1%-0.125W	7172332
RS-0805-301R-1%-0.125W	7172335
RS-0805-309R-1%-0.125W	7172339
RS-0805-316R-1%-0.125W	7172348
RS-0805-324R-1%-0.125W	7172341
RS-0805-332R-1%-0.125W	7172345
RS-0805-340R-1%-0.125W	7172354
RS-0805-348R-1%-0.125W	7172357
RS-0805-357R-1%-0.125W	7172351
RS-0805-365R-1%-0.125W	7172360
RS-0805-374R-1%-0.125W	7172363
RS-0805-383R-1%-0.125W	7172367
RS-0805-392R-1%-0.125W	7172376
RS-0805-402R-1%-0.125W	7172379
RS-0805-412R-1%-0.125W	7172373
RS-0805-422R-1%-0.125W	7172382
RS-0805-432R-1%-0.125W	7172385
RS-0805-442R-1%-0.125W	7172389
RS-0805-453R-1%-0.125W	7172398
RS-0805-464R-1%-0.125W	7172391
RS-0805-475R-1%-0.125W	7172395
RS-0805-487R-1%-0.125W	7172405
RS-0805-511R-1%-0.125W	7172402
RS-0805-523R-1%-0.125W	7172411
RS-0805-536R-1%-0.125W	7172414
RS-0805-549R-1%-0.125W	7172418
RS-0805-562R-1%-0.125W	7172427
RS-0805-576R-1%-0.125W	7172420
RS-0805-590R-1%-0.125W	7172424
RS-0805-604R-1%-0.125W	7172433

**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-619R-1%-0.125W	7172436
RS-0805-634R-1%-0.125W	7172430
RS-0805-649R-1%-0.125W	7172449
RS-0805-665R-1%-0.125W	7172442
RS-0805-681R-1%-0.125W	7172446
RS-0805-698R-1%-0.125W	7172455
RS-0805-715R-1%-0.125W	7172458
RS-0805-732R-1%-0.125W	7172452
RS-0805-768R-1%-0.125W	7172461
RS-0805-787R-1%-0.125W	7172464
RS-0805-806R-1%-0.125W	7172468
RS-0805-825R-1%-0.125W	7172477
RS-0805-845R-1%-0.125W	7172470
RS-0805-866R-1%-0.125W	7172474
RS-0805-887R-1%-0.125W	7172483
RS-0805-909R-1%-0.125W	7172486
RS-0805-931R-1%-0.125W	7172480
RS-0805-976R-1%-0.125W	7172492
RS-0805-1k02-1%-0.125W	7172496
RS-0805-1k05-1%-0.125W	7172506
RS-0805-1k07-1%-0.125W	7172509
RS-0805-1k13-1%-0.125W	7172503
RS-0805-1k15-1%-0.125W	7172512
RS-0805-1k18-1%-0.125W	7172515
RS-0805-1k21-1%-0.125W	7172519
RS-0805-1k24-1%-0.125W	7172528
RS-0805-1k27-1%-0.125W	7172521
RS-0805-1k30-1%-0.125W	7172525
RS-0805-1k33-1%-0.125W	7172534
RS-0805-1k37-1%-0.125W	7172537
RS-0805-1k40-1%-0.125W	7172531
RS-0805-1k43-1%-0.125W	7172540
RS-0805-1k47-1%-0.125W	7172543
RS-0805-1k54-1%-0.125W	7172547
RS-0805-1k58-1%-0.125W	7172556
RS-0805-1k62-1%-0.125W	7172559
RS-0805-1k65-1%-0.125W	7172553
RS-0805-1k69-1%-0.125W	7172562
RS-0805-1k74-1%-0.125W	7172565
RS-0805-1k78-1%-0.125W	7172569
RS-0805-1k82-1%-0.125W	7172578
RS-0805-1k87-1%-0.125W	7172571
RS-0805-1k91-1%-0.125W	7172575
RS-0805-1k96-1%-0.125W	7172584
RS-0805-2k05-1%-0.125W	7172587
RS-0805-2k10-1%-0.125W	7172581
RS-0805-2k16-1%-0.125W	7172590
RS-0805-2k21-1%-0.125W	7172593
RS-0805-2k36-1%-0.125W	7172597
RS-0805-2k32-1%-0.125W	7172607
RS-0805-2k37-1%-0.125W	7172600
RS-0805-2k43-1%-0.125W	7172604
RS-0805-2k49-1%-0.125W	7172613
RS-0805-2k55-1%-0.125W	7172616

**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-2k61-1%-0.125W	7172610
RS-0805-2k67-1%-0.125W	7172629
RS-0805-2k74-1%-0.125W	7172622
RS-0805-2k80-1%-0.125W	7172626
RS-0805-2k87-1%-0.125W	7172635
RS-0805-2k94-1%-0.125W	7172638
RS-0805-3k01-1%-0.125W	7172632
RS-0805-3k09-1%-0.125W	7172641
RS-0805-3k16-1%-0.125W	7172644
RS-0805-3k24-1%-0.125W	7172648
RS-0805-3k32-1%-0.125W	7172657
RS-0805-3k40-1%-0.125W	7172650
RS-0805-3k48-1%-0.125W	7172654
RS-0805-3k57-1%-0.125W	7172663
RS-0805-3k65-1%-0.125W	7172666
RS-0805-3k74-1%-0.125W	7172660
RS-0805-3k83-1%-0.125W	7172679
RS-0805-3k92-1%-0.125W	7172672
RS-0805-4k02-1%-0.125W	7172676
RS-0805-4k12-1%-0.125W	7172685
RS-0805-4k22-1%-0.125W	7172688
RS-0805-4k32-1%-0.125W	7172682
RS-0805-4k42-1%-0.125W	7172691
RS-0805-4k53-1%-0.125W	7172694
RS-0805-4k64-1%-0.125W	7172698
RS-0805-4k75-1%-0.125W	7172708
RS-0805-4k87-1%-0.125W	7172701
RS-0805-4k91-1%-0.125W	7172705
RS-0805-5k11-1%-0.125W	7172714
RS-0805-5k23-1%-0.125W	7172717
RS-0805-5k36-1%-0.125W	7172711
RS-0805-5k49-1%-0.125W	7172720
RS-0805-5k62-1%-0.125W	7172723
RS-0805-5k76-1%-0.125W	7172727
RS-0805-5k90-1%-0.125W	7172736
RS-0805-6k04-1%-0.125W	7172739
RS-0805-6k19-1%-0.125W	7172733
RS-0805-6k34-1%-0.125W	7172742
RS-0805-6k49-1%-0.125W	7172745
RS-0805-6k65-1%-0.125W	7172749
RS-0805-6k81-1%-0.125W	7172758
RS-0805-6k98-1%-0.125W	7172751
RS-0805-7k15-1%-0.125W	7172755
RS-0805-7k32-1%-0.125W	7172764
RS-0805-7k68-1%-0.125W	7172767
RS-0805-7k87-1%-0.125W	7172761
RS-0805-8k06-1%-0.125W	7172770
RS-0805-8k25-1%-0.125W	7172773
RS-0805-8k45-1%-0.125W	7172777
RS-0805-8k66-1%-0.125W	7172786
RS-0805-8k87-1%-0.125W	7172789
RS-0805-9k09-1%-0.125W	7172783
RS-0805-9k31-1%-0.125W	7172792
RS-0805-9k59-1%-0.125W	7172795

**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-9k76-1%-0.125W	7172799
RS-0805-10k2-1%-0.125W	7172809
RS-0805-10k5-1%-0.125W	7172802
RS-0805-10k7-1%-0.125W	7172806
RS-0805-11k3-1%-0.125W	7172815
RS-0805-11k5-1%-0.125W	7172818
RS-0805-11k8-1%-0.125W	7172812
RS-0805-12k1-1%-0.125W	7172821
RS-0805-12k4-1%-0.125W	7172824
RS-0805-12k7-1%-0.125W	7172828
RS-0805-13k3-1%-0.125W	7172837
RS-0805-13k7-1%-0.125W	7172830
RS-0805-14K-1%-0.125W	7172834
RS-0805-14k3-1%-0.125W	7172843
RS-0805-14k7-1%-0.125W	7172846
RS-0805-15k4-1%-0.125W	7172840
RS-0805-15k8-1%-0.125W	7172859
RS-0805-16k2-1%-0.125W	7172852
RS-0805-16k5-1%-0.125W	7172856
RS-0805-16k9-1%-0.125W	7172865
RS-0805-17k4-1%-0.125W	7172868
RS-0805-17k8-1%-0.125W	7172862
RS-0805-18k2-1%-0.125W	7172871
RS-0805-18k7-1%-0.125W	7172874
RS-0805-19k1-1%-0.125W	7172878
RS-0805-19k6-1%-0.125W	7172887
RS-0805-20k5-1%-0.125W	7172880
RS-0805-21K-1%-0.125W	7172884
RS-0805-21k6-1%-0.125W	7172893
RS-0805-22k1-1%-0.125W	7172896
RS-0805-23k6-1%-0.125W	7172890
RS-0805-23k2-1%-0.125W	7172900
RS-0805-23k7-1%-0.125W	7172903
RS-0805-24k3-1%-0.125W	7172907
RS-0805-24k9-1%-0.125W	7172916
RS-0805-25k5-1%-0.125W	7172919
RS-0805-26k1-1%-0.125W	7172913
RS-0805-26k7-1%-0.125W	7172922
RS-0805-27k4-1%-0.125W	7172925
RS-0805-28K-1%-0.125W	7172929
RS-0805-28k7-1%-0.125W	7172938
RS-0805-29k4-1%-0.125W	7172931
RS-0805-30k1-1%-0.125W	7172935
RS-0805-30k9-1%-0.125W	7172944
RS-0805-31k6-1%-0.125W	7172947
RS-0805-32k4-1%-0.125W	7172941
RS-0805-33k2-1%-0.125W	7172950
RS-0805-34K-1%-0.125W	7172953
RS-0805-34k8-1%-0.125W	7172957
RS-0805-35k7-1%-0.125W	7172966
RS-0805-36k5-1%-0.125W	7172969
RS-0805-37k4-1%-0.125W	7172963
RS-0805-38k3-1%-0.125W	7172972
RS-0805-39k2-1%-0.125W	7172975



**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-40k2-1%-0.125W	7172979
RS-0805-41k2-1%-0.125W	7172988
RS-0805-42k2-1%-0.125W	7172981
RS-0805-43k2-1%-0.125W	7172985
RS-0805-44k2-1%-0.125W	7172994
RS-0805-45k3-1%-0.125W	7172997
RS-0805-46k4-1%-0.125W	7172991
RS-0805-47k5-1%-0.125W	7173004
RS-0805-48k7-1%-0.125W	7173007
RS-0805-49k1-1%-0.125W	7173001
RS-0805-51k1-1%-0.125W	7173010
RS-0805-52k3-1%-0.125W	7173013
RS-0805-53k6-1%-0.125W	7173017
RS-0805-54k9-1%-0.125W	7173026
RS-0805-56k2-1%-0.125W	7173029
RS-0805-57k6-1%-0.125W	7173023
RS-0805-59K-1%-0.125W	7173032
RS-0805-60k4-1%-0.125W	7173035
RS-0805-61k9-1%-0.125W	7173039
RS-0805-63k4-1%-0.125W	7173048
RS-0805-64k9-1%-0.125W	7173041
RS-0805-66k5-1%-0.125W	7173045
RS-0805-68k1-1%-0.125W	7173054
RS-0805-69k8-1%-0.125W	7173057
RS-0805-71k5-1%-0.125W	7173051
RS-0805-73k2-1%-0.125W	7173060
RS-0805-76k8-1%-0.125W	7173063
RS-0805-78k7-1%-0.125W	7173067
RS-0805-80k6-1%-0.125W	7173076
RS-0805-82k5-1%-0.125W	7173079
RS-0805-84k5-1%-0.125W	7173073
RS-0805-86k6-1%-0.125W	7173082
RS-0805-88k7-1%-0.125W	7173085
RS-0805-90k9-1%-0.125W	7173089
RS-0805-93k1-1%-0.125W	7173098
RS-0805-95k9-1%-0.125W	7173091
RS-0805-97K6-1%-0.125W	7173095
RS-0805-102K-1%-0.125W	7173105
RS-0805-105K-1%-0.125W	7173108
RS-0805-107K-1%-0.125W	7173102
RS-0805-113K-1%-0.125W	7173111
RS-0805-115K-1%-0.125W	7173114
RS-0805-118K-1%-0.125W	7173118
RS-0805-121K-1%-0.125W	7173127
RS-0805-124K-1%-0.125W	7173120
RS-0805-127K-1%-0.125W	7173124
RS-0805-133K-1%-0.125W	7173133
RS-0805-137K-1%-0.125W	7173136
RS-0805-140K-1%-0.125W	7173130
RS-0805-143K-1%-0.125W	7173149
RS-0805-147K-1%-0.125W	7173142
RS-0805-154K-1%-0.125W	7173146
RS-0805-158K-1%-0.125W	7173155
RS-0805-162K-1%-0.125W	7173158

**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-165K-1%-0.125W	7173152
RS-0805-169K-1%-0.125W	7173161
RS-0805-174K-1%-0.125W	7173164
RS-0805-178K-1%-0.125W	7173168
RS-0805-182K-1%-0.125W	7173177
RS-0805-187K-1%-0.125W	7173170
RS-0805-191K-1%-0.125W	7173174
RS-0805-196K-1%-0.125W	7173183
RS-0805-205K-1%-0.125W	7173186
RS-0805-210K-1%-0.125W	7173180
RS-0805-216K-1%-0.125W	7173199
RS-0805-221K-1%-0.125W	7173192
RS-0805-236K-1%-0.125W	7173196
RS-0805-232K-1%-0.125W	7173206
RS-0805-237K-1%-0.125W	7173209
RS-0805-243K-1%-0.125W	7173203
RS-0805-249K-1%-0.125W	7173212
RS-0805-255K-1%-0.125W	7173215
RS-0805-261K-1%-0.125W	7173219
RS-0805-267K-1%-0.125W	7173228
RS-0805-274K-1%-0.125W	7173221
RS-0805-280K-1%-0.125W	7173225
RS-0805-287K-1%-0.125W	7173234
RS-0805-294K-1%-0.125W	7173237
RS-0805-301K-1%-0.125W	7173231
RS-0805-309K-1%-0.125W	7173240
RS-0805-316K-1%-0.125W	7173243
RS-0805-324K-1%-0.125W	7173247
RS-0805-332K-1%-0.125W	7173256
RS-0805-340K-1%-0.125W	7173259
RS-0805-348K-1%-0.125W	7173253
RS-0805-357K-1%-0.125W	7173262
RS-0805-365K-1%-0.125W	7173265
RS-0805-374K-1%-0.125W	7173269
RS-0805-383K-1%-0.125W	7173278
RS-0805-392K-1%-0.125W	7173271
RS-0805-402K-1%-0.125W	7173275
RS-0805-412K-1%-0.125W	7173284
RS-0805-422K-1%-0.125W	7173287
RS-0805-432K-1%-0.125W	7173281
RS-0805-442K-1%-0.125W	7173290
RS-0805-453K-1%-0.125W	7173293
RS-0805-464K-1%-0.125W	7173297
RS-0805-475K-1%-0.125W	7173307
RS-0805-487K-1%-0.125W	7173300
RS-0805-491K-1%-0.125W	7173304
RS-0805-511K-1%-0.125W	7173313
RS-0805-523K-1%-0.125W	7173316
RS-0805-536K-1%-0.125W	7173310
RS-0805-549K-1%-0.125W	7173329
RS-0805-562K-1%-0.125W	7173322
RS-0805-576K-1%-0.125W	7173326
RS-0805-590K-1%-0.125W	7173335
RS-0805-604K-1%-0.125W	7173338

**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-619K-1%-0.125W	7173332
RS-0805-634K-1%-0.125W	7173341
RS-0805-649K-1%-0.125W	7173344
RS-0805-665K-1%-0.125W	7173348
RS-0805-681K-1%-0.125W	7173357
RS-0805-698K-1%-0.125W	7173350
RS-0805-715K-1%-0.125W	7173354
RS-0805-732K-1%-0.125W	7173363
RS-0805-768K-1%-0.125W	7173366
RS-0805-787K-1%-0.125W	7173360
RS-0805-806K-1%-0.125W	7173379
RS-0805-825K-1%-0.125W	7173372
RS-0805-845K-1%-0.125W	7173376
RS-0805-866K-1%-0.125W	7173385
RS-0805-887K-1%-0.125W	7173388
RS-0805-909K-1%-0.125W	7173382
RS-0805-931K-1%-0.125W	7173391
RS-0805-959K-1%-0.125W	7173394
RS-0805-976K-1%-0.125W	7173398
RS-0805-10R-1%-0.125W	697-9918
RS-0805-11R-1%-0.125W	697-9911
RS-0805-12R-1%-0.125W	697-9915
RS-0805-13R-1%-0.125W	697-9924
RS-0805-15R-1%-0.125W	697-9927
RS-0805-16R-1%-0.125W	697-9921
RS-0805-18R-1%-0.125W	697-9930
RS-0805-20R-1%-0.125W	697-9933
RS-0805-22R-1%-0.125W	697-9937
RS-0805-24R-1%-0.125W	697-9946
RS-0805-27R-1%-0.125W	697-9949
RS-0805-30R-1%-0.125W	697-9943
RS-0805-33R-1%-0.125W	697-9952
RS-0805-36R-1%-0.125W	697-9955
RS-0805-39R-1%-0.125W	697-9959
RS-0805-43R-1%-0.125W	697-9968
RS-0805-47R-1%-0.125W	697-9961
RS-0805-51R-1%-0.125W	697-9965
RS-0805-56R-1%-0.125W	697-9974
RS-0805-62R-1%-0.125W	697-9977
RS-0805-68R-1%-0.125W	697-9971
RS-0805-75R-1%-0.125W	697-9980
RS-0805-82R-1%-0.125W	697-9983
RS-0805-91R-1%-0.125W	697-9987
RS-0805-100R-1%-0.125W	697-9996
RS-0805-110R-1%-0.125W	697-9999
RS-0805-120R-1%-0.125W	697-9993
RS-0805-130R-1%-0.125W	6980003
RS-0805-150R-1%-0.125W	6980006
RS-0805-160R-1%-0.125W	6980000
RS-0805-180R-1%-0.125W	6980019
RS-0805-200R-1%-0.125W	6980012
RS-0805-220R-1%-0.125W	6980016
RS-0805-240R-1%-0.125W	6980025
RS-0805-270R-1%-0.125W	6980028

**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-300R-1%-0.125W	6980022
RS-0805-330R-1%-0.125W	6980031
RS-0805-360R-1%-0.125W	6980034
RS-0805-390R-1%-0.125W	6980038
RS-0805-430R-1%-0.125W	6980047
RS-0805-470R-1%-0.125W	6980040
RS-0805-510R-1%-0.125W	6980044
RS-0805-560R-1%-0.125W	6980053
RS-0805-620R-1%-0.125W	6980056
RS-0805-680R-1%-0.125W	6980050
RS-0805-750R-1%-0.125W	6980069
RS-0805-820R-1%-0.125W	6980062
RS-0805-910R-1%-0.125W	6980066
RS-0805-1k-1%-0.125W	6980075
RS-0805-1k1-1%-0.125W	6980078
RS-0805-1k2-1%-0.125W	6980072
RS-0805-1k3-1%-0.125W	6980081
RS-0805-1k5-1%-0.125W	6980084
RS-0805-1k6-1%-0.125W	6980088
RS-0805-1k8-1%-0.125W	6980097
RS-0805-2k-1%-0.125W	6980090
RS-0805-2k2-1%-0.125W	6980094
RS-0805-2k4-1%-0.125W	6980104
RS-0805-2k7-1%-0.125W	6980107
RS-0805-3k-1%-0.125W	6980101
RS-0805-3k3-1%-0.125W	6980110
RS-0805-3k6-1%-0.125W	6980113
RS-0805-3k9-1%-0.125W	6980117
RS-0805-4k3-1%-0.125W	6980126
RS-0805-4k7-1%-0.125W	6980129
RS-0805-5k1-1%-0.125W	6980123
RS-0805-5k6-1%-0.125W	6980132
RS-0805-6k2-1%-0.125W	6980135
RS-0805-6k8-1%-0.125W	6980139
RS-0805-7k5-1%-0.125W	6980148
RS-0805-8k2-1%-0.125W	69-80141
RS-0805-9k1-1%-0.125W	6980145
RS-0805-10k-1%-0.125W	6980154
RS-0805-11k-1%-0.125W	6980157
RS-0805-12k-1%-0.125W	6980151
RS-0805-13k-1%-0.125W	6980160
RS-0805-15k-1%-0.125W	6980163
RS-0805-16k-1%-0.125W	6980167
RS-0805-18k-1%-0.125W	6980176
RS-0805-20k-1%-0.125W	6980179
RS-0805-22k-1%-0.125W	6980173
RS-0805-24k-1%-0.125W	6980182
RS-0805-27k-1%-0.125W	6980185
RS-0805-30k-1%-0.125W	6980189
RS-0805-33k-1%-0.125W	6980198
RS-0805-36k-1%-0.125W	6980191
RS-0805-39k-1%-0.125W	6980195
RS-0805-43k-1%-0.125W	6980205
RS-0805-47k-1%-0.125W	6980208

**RS 0805 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-0805-51k-1%-0.125W	6980202
RS-0805-56k-1%-0.125W	6980211
RS-0805-62k-1%-0.125W	6980214
RS-0805-68k-1%-0.125W	6980218
RS-0805-75k-1%-0.125W	6980227
RS-0805-82k-1%-0.125W	6980220
RS-0805-91k-1%-0.125W	6980224
RS-0805-100k-1%-0.125W	6980233
RS-0805-110k-1%-0.125W	6980236
RS-0805-120k-1%-0.125W	6980230
RS-0805-130k-1%-0.125W	6980249
RS-0805-150k-1%-0.125W	6980242
RS-0805-160k-1%-0.125W	6980246
RS-0805-180k-1%-0.125W	6980255
RS-0805-200k-1%-0.125W	6980258
RS-0805-220k-1%-0.125W	6980252
RS-0805-240k-1%-0.125W	6980261
RS-0805-270k-1%-0.125W	6980264
RS-0805-300k-1%-0.125W	6980268
RS-0805-330k-1%-0.125W	6980277
RS-0805-360k-1%-0.125W	6980270
RS-0805-390k-1%-0.125W	6980274
RS-0805-430k-1%-0.125W	6980283
RS-0805-470k-1%-0.125W	6980286
RS-0805-510k-1%-0.125W	6980280
RS-0805-560k-1%-0.125W	6980299
RS-0805-620k-1%-0.125W	6980292
RS-0805-680k-1%-0.125W	6980296
RS-0805-750k-1%-0.125W	6980306
RS-0805-820k-1%-0.125W	6980309
RS-0805-910k-1%-0.125W	6980303

**RS 1206 Series**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-1R-1%-0.25W	7174707
RS-1206-1R02-1%-0.25W	7174701
RS-1206-1R05-1%-0.25W	7174710
RS-1206-1R07-1%-0.25W	7174713
RS-1206-1R1-1%-0.25W	7174717
RS-1206-1R13-1%-0.25W	7174726
RS-1206-1R15-1%-0.25W	7174729
RS-1206-1R18-1%-0.25W	7174723
RS-1206-1R21-1%-0.25W	7174732
RS-1206-1R24-1%-0.25W	7174735
RS-1206-1R27-1%-0.25W	7174739
RS-1206-1R3-1%-0.25W	7174748
RS-1206-1R33-1%-0.25W	7174741
RS-1206-1R37-1%-0.25W	7174745
RS-1206-1R4-1%-0.25W	7174754
RS-1206-1R43-1%-0.25W	7174757
RS-1206-1R47-1%-0.25W	7174751

**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-1R5-1%-0.25W	7174760
RS-1206-1R54-1%-0.25W	7174763
RS-1206-1R58-1%-0.25W	7174767
RS-1206-1R62-1%-0.25W	7174776
RS-1206-1R65-1%-0.25W	7174779
RS-1206-1R69-1%-0.25W	7174773
RS-1206-1R74-1%-0.25W	7174782
RS-1206-1R78-1%-0.25W	7174785
RS-1206-1R82-1%-0.25W	7174789
RS-1206-1R87-1%-0.25W	7174798
RS-1206-1R91-1%-0.25W	7174791
RS-1206-1R96-1%-0.25W	7174795
RS-1206-2R-1%-0.25W	7174805
RS-1206-2R05-1%-0.25W	7174808
RS-1206-2R1-1%-0.25W	7174802
RS-1206-2R16-1%-0.25W	7174811
RS-1206-2R21-1%-0.25W	7174814
RS-1206-2R36-1%-0.25W	7174818
RS-1206-2R32-1%-0.25W	7174827
RS-1206-2R37-1%-0.25W	7174820
RS-1206-2R43-1%-0.25W	7174824
RS-1206-2R49-1%-0.25W	7174833
RS-1206-2R55-1%-0.25W	7174836
RS-1206-2R61-1%-0.25W	7174830
RS-1206-2R67-1%-0.25W	7174849
RS-1206-2R74-1%-0.25W	7174842
RS-1206-2R8-1%-0.25W	7174846
RS-1206-2R87-1%-0.25W	7174855
RS-1206-2R94-1%-0.25W	7174858
RS-1206-3R01-1%-0.25W	7174852
RS-1206-3R09-1%-0.25W	7174861
RS-1206-3R16-1%-0.25W	7174864
RS-1206-3R24-1%-0.25W	7174868
RS-1206-3R32-1%-0.25W	7174877
RS-1206-3R4-1%-0.25W	7174870
RS-1206-3R48-1%-0.25W	7174874
RS-1206-3R57-1%-0.25W	7174883
RS-1206-3R65-1%-0.25W	7174886
RS-1206-3R74-1%-0.25W	7174880
RS-1206-3R83-1%-0.25W	7174899
RS-1206-3R92-1%-0.25W	7174892
RS-1206-4R02-1%-0.25W	7174896
RS-1206-4R12-1%-0.25W	7174906
RS-1206-4R22-1%-0.25W	7174909
RS-1206-4R32-1%-0.25W	7174903
RS-1206-4R42-1%-0.25W	7174912
RS-1206-4R53-1%-0.25W	7174915
RS-1206-4R64-1%-0.25W	7174919
RS-1206-4R75-1%-0.25W	7174928
RS-1206-4R87-1%-0.25W	7174921
RS-1206-4R91-1%-0.25W	7174925
RS-1206-5R11-1%-0.25W	7174934
RS-1206-5R23-1%-0.25W	7174937
RS-1206-5R36-1%-0.25W	7174931

**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-5R49-1%-0.25W	7174940
RS-1206-5R62-1%-0.25W	7174943
RS-1206-5R76-1%-0.25W	7174947
RS-1206-5R9-1%-0.25W	7174956
RS-1206-6R04-1%-0.25W	7174959
RS-1206-6R19-1%-0.25W	7174953
RS-1206-6R34-1%-0.25W	7174962
RS-1206-6R49-1%-0.25W	7174965
RS-1206-6R65-1%-0.25W	7174969
RS-1206-6R81-1%-0.25W	7174978
RS-1206-6R98-1%-0.25W	7174971
RS-1206-7R15-1%-0.25W	7174975
RS-1206-7R32-1%-0.25W	7174984
RS-1206-7R5-1%-0.25W	7174987
RS-1206-7R68-1%-0.25W	7174981
RS-1206-7R87-1%-0.25W	7174990
RS-1206-8R06-1%-0.25W	7174993
RS-1206-8R25-1%-0.25W	7174997
RS-1206-8R45-1%-0.25W	7175000
RS-1206-8R66-1%-0.25W	7175003
RS-1206-8R87-1%-0.25W	7175007
RS-1206-9R09-1%-0.25W	7175016
RS-1206-9R31-1%-0.25W	7175019
RS-1206-9R59-1%-0.25W	7175013
RS-1206-9R76-1%-0.25W	7175022
RS-1206-10R2-1%-0.25W	7175025
RS-1206-10R5-1%-0.25W	7175029
RS-1206-10R7-1%-0.25W	7175038
RS-1206-11R3-1%-0.25W	7175031
RS-1206-11R5-1%-0.25W	7175035
RS-1206-11R8-1%-0.25W	7175044
RS-1206-12R1-1%-0.25W	7175047
RS-1206-12R4-1%-0.25W	7175041
RS-1206-12R7-1%-0.25W	7175050
RS-1206-13R3-1%-0.25W	7175053
RS-1206-13R7-1%-0.25W	7175057
RS-1206-14R-1%-0.25W	7175066
RS-1206-14R3-1%-0.25W	7175069
RS-1206-14R7-1%-0.25W	7175063
RS-1206-15R4-1%-0.25W	7175072
RS-1206-15R8-1%-0.25W	7175075
RS-1206-16R2-1%-0.25W	7175079
RS-1206-16R5-1%-0.25W	7175088
RS-1206-16R9-1%-0.25W	7175081
RS-1206-17R4-1%-0.25W	7175085
RS-1206-17R8-1%-0.25W	7175094
RS-1206-18R2-1%-0.25W	7175097
RS-1206-18R7-1%-0.25W	7175091
RS-1206-19R1-1%-0.25W	7175101
RS-1206-19R6-1%-0.25W	7175104
RS-1206-20R5-1%-0.25W	7175108
RS-1206-21R-1%-0.25W	7175117
RS-1206-21R6-1%-0.25W	7175110
RS-1206-22R1-1%-0.25W	7175114

**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-23R6-1%-0.25W	7175123
RS-1206-23R2-1%-0.25W	7175126
RS-1206-23R7-1%-0.25W	7175120
RS-1206-24R3-1%-0.25W	7175139
RS-1206-24R9-1%-0.25W	7175132
RS-1206-25R5-1%-0.25W	7175136
RS-1206-26R1-1%-0.25W	7175145
RS-1206-26R7-1%-0.25W	7175148
RS-1206-27R4-1%-0.25W	7175142
RS-1206-28R-1%-0.25W	7175151
RS-1206-28R7-1%-0.25W	7175154
RS-1206-29R4-1%-0.25W	7175158
RS-1206-30R1-1%-0.25W	7175167
RS-1206-30R9-1%-0.25W	7175160
RS-1206-31R6-1%-0.25W	7175164
RS-1206-32R4-1%-0.25W	7175173
RS-1206-33R2-1%-0.25W	7175176
RS-1206-34R-1%-0.25W	7175170
RS-1206-34R8-1%-0.25W	7175189
RS-1206-35R7-1%-0.25W	7175182
RS-1206-36R5-1%-0.25W	7175186
RS-1206-37R4-1%-0.25W	7175195
RS-1206-38R3-1%-0.25W	7175198
RS-1206-39R2-1%-0.25W	7175192
RS-1206-40R2-1%-0.25W	7175202
RS-1206-41R2-1%-0.25W	7175205
RS-1206-42R2-1%-0.25W	7175209
RS-1206-43R2-1%-0.25W	7175218
RS-1206-44R2-1%-0.25W	7175211
RS-1206-45R3-1%-0.25W	7175215
RS-1206-46R4-1%-0.25W	7175224
RS-1206-47R5-1%-0.25W	7175227
RS-1206-48R7-1%-0.25W	7175221
RS-1206-49R1-1%-0.25W	7175230
RS-1206-51R1-1%-0.25W	7175233
RS-1206-52R3-1%-0.25W	7175237
RS-1206-53R6-1%-0.25W	7175246
RS-1206-54R9-1%-0.25W	7175249
RS-1206-56R2-1%-0.25W	7175243
RS-1206-57R6-1%-0.25W	7175252
RS-1206-59R-1%-0.25W	7175255
RS-1206-60R4-1%-0.25W	7175259
RS-1206-61R9-1%-0.25W	7175268
RS-1206-63R4-1%-0.25W	7175261
RS-1206-64R9-1%-0.25W	7175265
RS-1206-66R5-1%-0.25W	7175274
RS-1206-68R1-1%-0.25W	7175277
RS-1206-69R8-1%-0.25W	7175271
RS-1206-71R5-1%-0.25W	7175280
RS-1206-73R2-1%-0.25W	7175283
RS-1206-76R8-1%-0.25W	7175287
RS-1206-78R7-1%-0.25W	7175296
RS-1206-80R6-1%-0.25W	7175299
RS-1206-82R5-1%-0.25W	7175293



**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-84R5-1%-0.25W	7175303
RS-1206-86R6-1%-0.25W	7175306
RS-1206-88R7-1%-0.25W	7175300
RS-1206-90R9-1%-0.25W	7175319
RS-1206-93R1-1%-0.25W	7175312
RS-1206-95R9-1%-0.25W	7175316
RS-1206-97R6-1%-0.25W	7175325
RS-1206-102R-1%-0.25W	7175328
RS-1206-105R-1%-0.25W	7175322
RS-1206-107R-1%-0.25W	7175331
RS-1206-113R-1%-0.25W	7175334
RS-1206-115R-1%-0.25W	7175338
RS-1206-118R-1%-0.25W	7175347
RS-1206-121R-1%-0.25W	7175340
RS-1206-124R-1%-0.25W	7175344
RS-1206-127R-1%-0.25W	7175353
RS-1206-133R-1%-0.25W	7175356
RS-1206-137R-1%-0.25W	7175350
RS-1206-140R-1%-0.25W	7175369
RS-1206-143R-1%-0.25W	7175362
RS-1206-147R-1%-0.25W	7175366
RS-1206-154R-1%-0.25W	7175375
RS-1206-158R-1%-0.25W	7175378
RS-1206-162R-1%-0.25W	7175372
RS-1206-165R-1%-0.25W	7175381
RS-1206-169R-1%-0.25W	7175384
RS-1206-174R-1%-0.25W	7175388
RS-1206-178R-1%-0.25W	7175397
RS-1206-182R-1%-0.25W	7175390
RS-1206-187R-1%-0.25W	7175394
RS-1206-191R-1%-0.25W	7175404
RS-1206-196R-1%-0.25W	7175407
RS-1206-205R-1%-0.25W	7175401
RS-1206-210R-1%-0.25W	7175410
RS-1206-216R-1%-0.25W	7175413
RS-1206-221R-1%-0.25W	7175417
RS-1206-236R-1%-0.25W	7175426
RS-1206-232R-1%-0.25W	7175429
RS-1206-237R-1%-0.25W	7175423
RS-1206-243R-1%-0.25W	7175432
RS-1206-249R-1%-0.25W	7175435
RS-1206-255R-1%-0.25W	7175439
RS-1206-261R-1%-0.25W	7175448
RS-1206-267R-1%-0.25W	7175441
RS-1206-274R-1%-0.25W	7175445
RS-1206-280R-1%-0.25W	7175454
RS-1206-287R-1%-0.25W	7175457
RS-1206-294R-1%-0.25W	7175451
RS-1206-301R-1%-0.25W	7175460
RS-1206-309R-1%-0.25W	7175463
RS-1206-316R-1%-0.25W	7175467
RS-1206-324R-1%-0.25W	7175476
RS-1206-332R-1%-0.25W	7175479
RS-1206-340R-1%-0.25W	7175473

**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-348R-1%-0.25W	7175482
RS-1206-357R-1%-0.25W	7175485
RS-1206-365R-1%-0.25W	7175489
RS-1206-374R-1%-0.25W	7175498
RS-1206-383R-1%-0.25W	7175491
RS-1206-392R-1%-0.25W	7175495
RS-1206-402R-1%-0.25W	7175505
RS-1206-412R-1%-0.25W	7175508
RS-1206-422R-1%-0.25W	7175502
RS-1206-432R-1%-0.25W	7175511
RS-1206-442R-1%-0.25W	7175514
RS-1206-453R-1%-0.25W	7175518
RS-1206-464R-1%-0.25W	7175527
RS-1206-475R-1%-0.25W	7175520
RS-1206-487R-1%-0.25W	7175524
RS-1206-491R-1%-0.25W	7175533
RS-1206-511R-1%-0.25W	7175536
RS-1206-523R-1%-0.25W	7175530
RS-1206-536R-1%-0.25W	7175549
RS-1206-549R-1%-0.25W	7175542
RS-1206-562R-1%-0.25W	7175546
RS-1206-576R-1%-0.25W	7175555
RS-1206-590R-1%-0.25W	7175558
RS-1206-604R-1%-0.25W	7175552
RS-1206-619R-1%-0.25W	7175561
RS-1206-634R-1%-0.25W	7175564
RS-1206-649R-1%-0.25W	7175568
RS-1206-665R-1%-0.25W	7175577
RS-1206-681R-1%-0.25W	7175570
RS-1206-698R-1%-0.25W	7175574
RS-1206-715R-1%-0.25W	7175583
RS-1206-732R-1%-0.25W	7175586
RS-1206-768R-1%-0.25W	7175580
RS-1206-787R-1%-0.25W	7175599
RS-1206-806R-1%-0.25W	7175592
RS-1206-825R-1%-0.25W	7175596
RS-1206-845R-1%-0.25W	7175606
RS-1206-866R-1%-0.25W	7175609
RS-1206-887R-1%-0.25W	7175603
RS-1206-909R-1%-0.25W	7175612
RS-1206-931R-1%-0.25W	7175615
RS-1206-959R-1%-0.25W	7175619
RS-1206-976R-1%-0.25W	7175628
RS-1206-1k02-1%-0.25W	7175621
RS-1206-1k05-1%-0.25W	7175625
RS-1206-1k07-1%-0.25W	7175634
RS-1206-1k13-1%-0.25W	7175637
RS-1206-1k15-1%-0.25W	7175631
RS-1206-1k18-1%-0.25W	7175640
RS-1206-1k21-1%-0.25W	7175643
RS-1206-1k24-1%-0.25W	7175647
RS-1206-1k27-1%-0.25W	7175656
RS-1206-1k30-1%-0.25W	7175659
RS-1206-1k33-1%-0.25W	7175653

**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-1k37-1%-0.25W	7175662
RS-1206-1k40-1%-0.25W	7175665
RS-1206-1k43-1%-0.25W	7175669
RS-1206-1k47-1%-0.25W	7175678
RS-1206-1k54-1%-0.25W	7175671
RS-1206-1k58-1%-0.25W	7175675
RS-1206-1k62-1%-0.25W	7175684
RS-1206-1k65-1%-0.25W	7175687
RS-1206-1k69-1%-0.25W	7175681
RS-1206-1k74-1%-0.25W	7175690
RS-1206-1k78-1%-0.25W	7175693
RS-1206-1k82-1%-0.25W	7175697
RS-1206-1k87-1%-0.25W	7175707
RS-1206-1k91-1%-0.25W	7175700
RS-1206-1k96-1%-0.25W	7175704
RS-1206-2k05-1%-0.25W	7175713
RS-1206-2k10-1%-0.25W	7175716
RS-1206-2k16-1%-0.25W	7175710
RS-1206-2k21-1%-0.25W	7175729
RS-1206-2k36-1%-0.25W	7175722
RS-1206-2k32-1%-0.25W	7175726
RS-1206-2k37-1%-0.25W	7175735
RS-1206-2k43-1%-0.25W	7175738
RS-1206-2k49-1%-0.25W	7175732
RS-1206-2k55-1%-0.25W	7175741
RS-1206-2k61-1%-0.25W	7175744
RS-1206-2k67-1%-0.25W	7175748
RS-1206-2k74-1%-0.25W	7175757
RS-1206-2k80-1%-0.25W	7175750
RS-1206-2k87-1%-0.25W	7175754
RS-1206-2k94-1%-0.25W	7175763
RS-1206-3k01-1%-0.25W	7175766
RS-1206-3k09-1%-0.25W	7175760
RS-1206-3k16-1%-0.25W	7175779
RS-1206-3k24-1%-0.25W	7175772
RS-1206-3k32-1%-0.25W	7175776
RS-1206-3k40-1%-0.25W	7175785
RS-1206-3k48-1%-0.25W	7175788
RS-1206-3k57-1%-0.25W	7175782
RS-1206-3k65-1%-0.25W	7175791
RS-1206-3k74-1%-0.25W	7175794
RS-1206-3k83-1%-0.25W	7175798
RS-1206-3k92-1%-0.25W	7175808
RS-1206-4k02-1%-0.25W	7175801
RS-1206-4k12-1%-0.25W	7175805
RS-1206-4k22-1%-0.25W	7175814
RS-1206-4k32-1%-0.25W	7175817
RS-1206-4k42-1%-0.25W	7175811
RS-1206-4k53-1%-0.25W	7175820
RS-1206-4k64-1%-0.25W	7175823
RS-1206-4k75-1%-0.25W	7175827
RS-1206-4k87-1%-0.25W	7175836
RS-1206-4k91-1%-0.25W	7175839
RS-1206-5k11-1%-0.25W	7175833

**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-5k23-1%-0.25W	7175842
RS-1206-5k36-1%-0.25W	7175845
RS-1206-5k49-1%-0.25W	7175849
RS-1206-5k62-1%-0.25W	7175858
RS-1206-5k76-1%-0.25W	7175851
RS-1206-5k90-1%-0.25W	7175855
RS-1206-6k04-1%-0.25W	7175864
RS-1206-6k19-1%-0.25W	7175867
RS-1206-6k34-1%-0.25W	7175861
RS-1206-6k49-1%-0.25W	7175870
RS-1206-6k65-1%-0.25W	7175873
RS-1206-6k81-1%-0.25W	7175877
RS-1206-6k98-1%-0.25W	7175886
RS-1206-7k15-1%-0.25W	7175889
RS-1206-7k32-1%-0.25W	7175883
RS-1206-7k68-1%-0.25W	7175892
RS-1206-7k87-1%-0.25W	7175895
RS-1206-8k06-1%-0.25W	7175899
RS-1206-8k25-1%-0.25W	7175909
RS-1206-8k45-1%-0.25W	7175902
RS-1206-8k66-1%-0.25W	7175906
RS-1206-8k87-1%-0.25W	7175915
RS-1206-9k09-1%-0.25W	7175918
RS-1206-9k31-1%-0.25W	7175912
RS-1206-9k59-1%-0.25W	7175921
RS-1206-9k76-1%-0.25W	7175924
RS-1206-10k2-1%-0.25W	7175928
RS-1206-10k5-1%-0.25W	7175937
RS-1206-10k7-1%-0.25W	7175930
RS-1206-11k3-1%-0.25W	7175934
RS-1206-11k5-1%-0.25W	7175943
RS-1206-11k8-1%-0.25W	7175946
RS-1206-12k1-1%-0.25W	7175940
RS-1206-12k4-1%-0.25W	7175959
RS-1206-12k7-1%-0.25W	7175952
RS-1206-13k3-1%-0.25W	7175956
RS-1206-13k7-1%-0.25W	7175965
RS-1206-14K-1%-0.25W	7175968
RS-1206-14k3-1%-0.25W	7175962
RS-1206-14k7-1%-0.25W	7175971
RS-1206-15k4-1%-0.25W	7175974
RS-1206-15k8-1%-0.25W	7175978
RS-1206-16k2-1%-0.25W	7175987
RS-1206-16k5-1%-0.25W	7175980
RS-1206-16k9-1%-0.25W	7175984
RS-1206-17k4-1%-0.25W	7175993
RS-1206-17k8-1%-0.25W	7175996
RS-1206-18k2-1%-0.25W	7175990
RS-1206-18k7-1%-0.25W	7176003
RS-1206-19k1-1%-0.25W	7176006
RS-1206-19k6-1%-0.25W	7176000
RS-1206-20k5-1%-0.25W	7176019
RS-1206-21K-1%-0.25W	7176012
RS-1206-21k6-1%-0.25W	7176016

**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-22k1-1%-0.25W	7176025
RS-1206-23k6-1%-0.25W	7176028
RS-1206-23k2-1%-0.25W	7176022
RS-1206-23k7-1%-0.25W	7176031
RS-1206-24k3-1%-0.25W	7176034
RS-1206-24k9-1%-0.25W	7176038
RS-1206-25k5-1%-0.25W	7176047
RS-1206-26k1-1%-0.25W	7176040
RS-1206-26k7-1%-0.25W	7176044
RS-1206-27k4-1%-0.25W	7176053
RS-1206-28K-1%-0.25W	7176056
RS-1206-28k7-1%-0.25W	7176050
RS-1206-29k4-1%-0.25W	7176069
RS-1206-30k1-1%-0.25W	7176062
RS-1206-30k9-1%-0.25W	7176066
RS-1206-31k6-1%-0.25W	7176075
RS-1206-32k4-1%-0.25W	7176078
RS-1206-33k2-1%-0.25W	7176072
RS-1206-34K-1%-0.25W	7176081
RS-1206-34k8-1%-0.25W	7176084
RS-1206-35k7-1%-0.25W	7176088
RS-1206-36k5-1%-0.25W	7176097
RS-1206-37k4-1%-0.25W	7176090
RS-1206-38k3-1%-0.25W	7176094
RS-1206-39k2-1%-0.25W	7176104
RS-1206-40k2-1%-0.25W	7176107
RS-1206-41k2-1%-0.25W	7176101
RS-1206-42k2-1%-0.25W	7176110
RS-1206-43k2-1%-0.25W	7176113
RS-1206-44k2-1%-0.25W	7176117
RS-1206-45k3-1%-0.25W	7176126
RS-1206-46k4-1%-0.25W	7176129
RS-1206-47k5-1%-0.25W	7176123
RS-1206-48k7-1%-0.25W	7176132
RS-1206-49k1-1%-0.25W	7176135
RS-1206-51k1-1%-0.25W	7176139
RS-1206-52k3-1%-0.25W	7176148
RS-1206-53k6-1%-0.25W	7176141
RS-1206-54k9-1%-0.25W	7176145
RS-1206-56k2-1%-0.25W	7176154
RS-1206-57k6-1%-0.25W	7176157
RS-1206-59K-1%-0.25W	7176151
RS-1206-60k4-1%-0.25W	7176160
RS-1206-61k9-1%-0.25W	7176163
RS-1206-63k4-1%-0.25W	7176167
RS-1206-64k9-1%-0.25W	7176176
RS-1206-66k5-1%-0.25W	7176179
RS-1206-68k1-1%-0.25W	7176173
RS-1206-69k8-1%-0.25W	7176182
RS-1206-71k5-1%-0.25W	7176185
RS-1206-73k2-1%-0.25W	7176189
RS-1206-76k8-1%-0.25W	7176198
RS-1206-78k7-1%-0.25W	7176191
RS-1206-80k6-1%-0.25W	7176195

**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-82k5-1%-0.25W	7176205
RS-1206-84k5-1%-0.25W	7176208
RS-1206-86k6-1%-0.25W	7176202
RS-1206-88k7-1%-0.25W	7176211
RS-1206-90k9-1%-0.25W	7176214
RS-1206-93k1-1%-0.25W	7176218
RS-1206-95k9-1%-0.25W	7176227
RS-1206-97K6-1%-0.25W	7176220
RS-1206-102K-1%-0.25W	7176224
RS-1206-105K-1%-0.25W	7176233
RS-1206-107K-1%-0.25W	7176236
RS-1206-113K-1%-0.25W	7176230
RS-1206-115K-1%-0.25W	7176249
RS-1206-118K-1%-0.25W	7176242
RS-1206-121K-1%-0.25W	7176246
RS-1206-124K-1%-0.25W	7176255
RS-1206-127K-1%-0.25W	7176258
RS-1206-133K-1%-0.25W	7176252
RS-1206-137K-1%-0.25W	7176261
RS-1206-140K-1%-0.25W	7176264
RS-1206-143K-1%-0.25W	7176268
RS-1206-147K-1%-0.25W	7176277
RS-1206-154K-1%-0.25W	7176270
RS-1206-158K-1%-0.25W	7176274
RS-1206-162K-1%-0.25W	7176283
RS-1206-165K-1%-0.25W	7176286
RS-1206-169K-1%-0.25W	7176280
RS-1206-174K-1%-0.25W	7176299
RS-1206-178K-1%-0.25W	7176292
RS-1206-182K-1%-0.25W	7176296
RS-1206-187K-1%-0.25W	7176306
RS-1206-191K-1%-0.25W	7176309
RS-1206-196K-1%-0.25W	7176303
RS-1206-205K-1%-0.25W	7176312
RS-1206-210K-1%-0.25W	7176315
RS-1206-216K-1%-0.25W	7176319
RS-1206-221K-1%-0.25W	7176328
RS-1206-236K-1%-0.25W	7176321
RS-1206-232K-1%-0.25W	7176325
RS-1206-237K-1%-0.25W	7176334
RS-1206-243K-1%-0.25W	7176337
RS-1206-249K-1%-0.25W	7176331
RS-1206-255K-1%-0.25W	7176340
RS-1206-261K-1%-0.25W	7176343
RS-1206-267K-1%-0.25W	7176347
RS-1206-274K-1%-0.25W	7176356
RS-1206-280K-1%-0.25W	7176359
RS-1206-287K-1%-0.25W	7176353
RS-1206-294K-1%-0.25W	7176362
RS-1206-301K-1%-0.25W	7176365
RS-1206-309K-1%-0.25W	7176369
RS-1206-316K-1%-0.25W	7176378
RS-1206-324K-1%-0.25W	7176371
RS-1206-332K-1%-0.25W	7176375

**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-340K-1%-0.25W	7176384
RS-1206-348K-1%-0.25W	7176387
RS-1206-357K-1%-0.25W	7176381
RS-1206-365K-1%-0.25W	7176390
RS-1206-374K-1%-0.25W	7176393
RS-1206-383K-1%-0.25W	7176397
RS-1206-392K-1%-0.25W	7176407
RS-1206-402K-1%-0.25W	7176400
RS-1206-412K-1%-0.25W	7176404
RS-1206-422K-1%-0.25W	7176413
RS-1206-432K-1%-0.25W	7176416
RS-1206-442K-1%-0.25W	7176410
RS-1206-453K-1%-0.25W	7176429
RS-1206-464K-1%-0.25W	7176422
RS-1206-475K-1%-0.25W	7176426
RS-1206-487K-1%-0.25W	7176435
RS-1206-491K-1%-0.25W	7176438
RS-1206-511K-1%-0.25W	7176432
RS-1206-523K-1%-0.25W	7176441
RS-1206-536K-1%-0.25W	7176444
RS-1206-549K-1%-0.25W	7176448
RS-1206-562K-1%-0.25W	7176457
RS-1206-576K-1%-0.25W	7176450
RS-1206-590K-1%-0.25W	7176454
RS-1206-604K-1%-0.25W	7176463
RS-1206-619K-1%-0.25W	7176466
RS-1206-634K-1%-0.25W	7176460
RS-1206-649K-1%-0.25W	7176479
RS-1206-665K-1%-0.25W	7176472
RS-1206-681K-1%-0.25W	7176476
RS-1206-698K-1%-0.25W	7176485
RS-1206-715K-1%-0.25W	7176488
RS-1206-732K-1%-0.25W	7176482
RS-1206-768K-1%-0.25W	7176491
RS-1206-787K-1%-0.25W	7176494
RS-1206-806K-1%-0.25W	7176498
RS-1206-825K-1%-0.25W	7176508
RS-1206-845K-1%-0.25W	7176501
RS-1206-866K-1%-0.25W	7176505
RS-1206-887K-1%-0.25W	7176514
RS-1206-909K-1%-0.25W	7176517
RS-1206-931K-1%-0.25W	7176511
RS-1206-959K-1%-0.25W	7176520
RS-1206-976K-1%-0.25W	7176523
RS-1206-10R-1%-0.25W	697-9390
RS-1206-11R-1%-0.25W	697-9407
RS-1206-12R-1%-0.25W	697-9400
RS-1206-13R-1%-0.25W	697-9413
RS-1206-15R-1%-0.25W	697-9410
RS-1206-16R-1%-0.25W	697-9422
RS-1206-18R-1%-0.25W	697-9435
RS-1206-20R-1%-0.25W	697-9441
RS-1206-22R-1%-0.25W	697-9448
RS-1206-24R-1%-0.25W	697-9463

**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-27R-1%-0.25W	697-9460
RS-1206-30R-1%-0.25W	697-9479
RS-1206-33R-1%-0.25W	697-9482
RS-1206-36R-1%-0.25W	697-9491
RS-1206-39R-1%-0.25W	697-9498
RS-1206-43R-1%-0.25W	697-9501
RS-1206-47R-1%-0.25W	697-9514
RS-1206-51R-1%-0.25W	697-9523
RS-1206-56R-1%-0.25W	697-9536
RS-1206-62R-1%-0.25W	697-9533
RS-1206-68R-1%-0.25W	697-9545
RS-1206-75R-1%-0.25W	697-9558
RS-1206-82R-1%-0.25W	697-9555
RS-1206-91R-1%-0.25W	697-9567
RS-1206-100R-1%-0.25W	697-9570
RS-1206-110R-1%-0.25W	697-9577
RS-1206-120R-1%-0.25W	697-9589
RS-1206-130R-1%-0.25W	697-9592
RS-1206-150R-1%-0.25W	697-9599
RS-1206-160R-1%-0.25W	697-9602
RS-1206-180R-1%-0.25W	697-9615
RS-1206-200R-1%-0.25W	697-9618
RS-1206-220R-1%-0.25W	697-9612
RS-1206-240R-1%-0.25W	697-9621
RS-1206-270R-1%-0.25W	697-9624
RS-1206-300R-1%-0.25W	697-9628
RS-1206-330R-1%-0.25W	697-9637
RS-1206-360R-1%-0.25W	697-9630
RS-1206-390R-1%-0.25W	697-9634
RS-1206-430R-1%-0.25W	697-9643
RS-1206-470R-1%-0.25W	697-9646
RS-1206-510R-1%-0.25W	697-9640
RS-1206-560R-1%-0.25W	697-9659
RS-1206-620R-1%-0.25W	697-9652
RS-1206-680R-1%-0.25W	697-9656
RS-1206-750R-1%-0.25W	697-9665
RS-1206-820R-1%-0.25W	697-9668
RS-1206-910R-1%-0.25W	697-9662
RS-1206-1k-1%-0.25W	697-9671
RS-1206-1k1-1%-0.25W	697-9674
RS-1206-1k2-1%-0.25W	697-9678
RS-1206-1k3-1%-0.25W	697-9687
RS-1206-1k5-1%-0.25W	697-9680
RS-1206-1k6-1%-0.25W	697-9684
RS-1206-1k8-1%-0.25W	697-9693
RS-1206-2k-1%-0.25W	697-9696
RS-1206-2k2-1%-0.25W	697-9690
RS-1206-2k4-1%-0.25W	697-9700
RS-1206-2k7-1%-0.25W	697-9703
RS-1206-3k-1%-0.25W	697-9707
RS-1206-3k3-1%-0.25W	697-9716
RS-1206-3k6-1%-0.25W	697-9719
RS-1206-3k9-1%-0.25W	697-9713
RS-1206-4k3-1%-0.25W	697-9722



**RS 1206 Series continued**

<b>Part Number</b>	<b>RS Stock Number</b>
RS-1206-4k7-1%-0.25W	697-9725
RS-1206-5k1-1%-0.25W	697-9729
RS-1206-5k6-1%-0.25W	697-9738
RS-1206-6k2-1%-0.25W	697-9731
RS-1206-6k8-1%-0.25W	697-9735
RS-1206-7k5-1%-0.25W	697-9744
RS-1206-8k2-1%-0.25W	697-9747
RS-1206-9k1-1%-0.25W	697-9741
RS-1206-10k-1%-0.25W	697-9750
RS-1206-11k-1%-0.25W	697-9753
RS-1206-12k-1%-0.25W	697-9757
RS-1206-13k-1%-0.25W	697-9766
RS-1206-15k-1%-0.25W	697-9769
RS-1206-16k-1%-0.25W	697-9763
RS-1206-18k-1%-0.25W	697-9772
RS-1206-20k-1%-0.25W	697-9775
RS-1206-22k-1%-0.25W	697-9779
RS-1206-24k-1%-0.25W	697-9788
RS-1206-27k-1%-0.25W	697-9781
RS-1206-30k-1%-0.25W	697-9785
RS-1206-33k-1%-0.25W	697-9794
RS-1206-36k-1%-0.25W	697-9797
RS-1206-39k-1%-0.25W	697-9791
RS-1206-43k-1%-0.25W	697-9801
RS-1206-47k-1%-0.25W	697-9804
RS-1206-51k-1%-0.25W	697-9808
RS-1206-56k-1%-0.25W	697-9817
RS-1206-62k-1%-0.25W	697-9810
RS-1206-68k-1%-0.25W	697-9814
RS-1206-75k-1%-0.25W	697-9823
RS-1206-82k-1%-0.25W	697-9826
RS-1206-91k-1%-0.25W	697-9820
RS-1206-100k-1%-0.25W	697-9839
RS-1206-110k-1%-0.25W	697-9832
RS-1206-120k-1%-0.25W	697-9836
RS-1206-130k-1%-0.25W	697-9845
RS-1206-150k-1%-0.25W	697-9848
RS-1206-160k-1%-0.25W	697-9842
RS-1206-180k-1%-0.25W	697-9851
RS-1206-200k-1%-0.25W	697-9854
RS-1206-220k-1%-0.25W	697-9858
RS-1206-240k-1%-0.25W	697-9867
RS-1206-270k-1%-0.25W	697-9860
RS-1206-300k-1%-0.25W	697-9864
RS-1206-330k-1%-0.25W	697-9873
RS-1206-360k-1%-0.25W	697-9876
RS-1206-390k-1%-0.25W	697-9870
RS-1206-430k-1%-0.25W	697-9889
RS-1206-470k-1%-0.25W	697-9882
RS-1206-510k-1%-0.25W	697-9886
RS-1206-560k-1%-0.25W	697-9895
RS-1206-620k-1%-0.25W	697-9898
RS-1206-680k-1%-0.25W	697-9892
RS-1206-750k-1%-0.25W	697-9902



**RS 1206 Series continued**

**Part Number**

RS-1206-820k-1%-0.25W

RS-1206-910k-1%-0.25W

**RS Stock Number**

697-9905

697-9909