
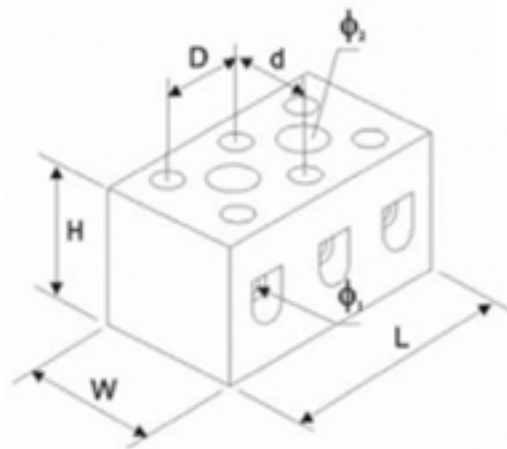


RS Porcelain Terminal Blocks

SPECIFICATIONS

INSERTS:	NICKEL PLATED BRASS
HOUSING:	PORCELAIN (GLAZED OPTION)
TEMP.:	800°C (HOUSING); 350°C (INSERTS)
SCREWS:	GALVANISED STEEL
STANDARDS:	CE (BS EN 60998)
COLOUR:	WHITE
FEATURES:	HARD AND SOLID VERY HIGH TEMPERATURE NON-FLAMMABLE RESISTANT TO CHEMICALS

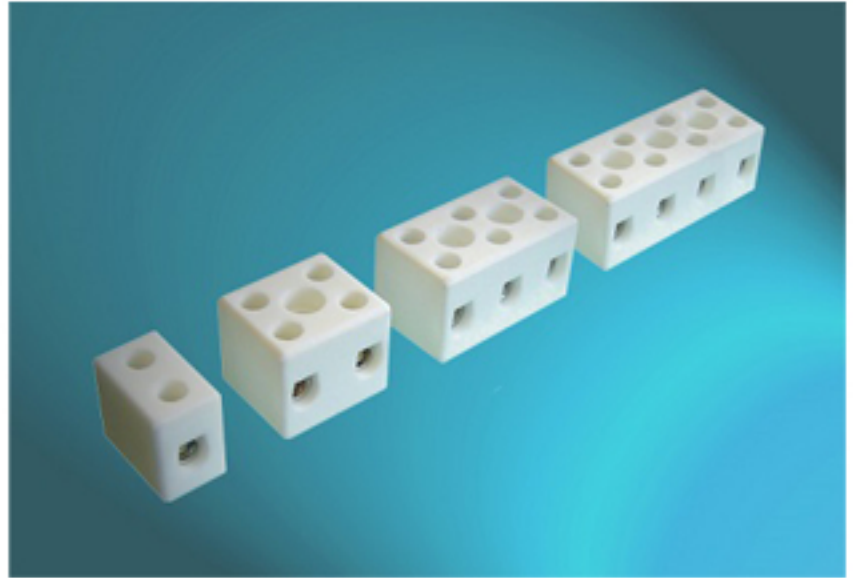

RS Stock No.	CROSS SECTION	CURRENT RANGE	RATED VOLTAGE	DIMENSIONS (mm)						
				W	L	$\phi 1$	$\phi 2$	D	d	H
813-3098	4 mm ²	5 - 32 A	450 V	17.8	45.2	3.2	4.8	12	8	16
813-3108	10 mm ²	15 - 57 A	450 V	20.7	48.6	4.3	4.9	13	10	20
813-3101	16 mm ²	30 - 76 A	450 V	26.6	64.3	6.1	4.9	17	12.5	21
813-3114	4 mm ²	5 - 32 A	450 V	13	12	3.2	-	-	8	16
813-3117	10 mm ²	15 - 57 A	450 V	21	13	4.3	-	-	10	20
813-3111	16 mm ²	30 - 76 A	450 V	21	15	6.1	-	-	12	22

Cross-section rated for rigid wire and cables (if for flexible wire, it should be reduced one-step, i.e., 6mm² is 4mm²)

$\phi 1$ = wire entry hole diameter

$\phi 2$ = fixing hole diameter

