


CCTV Euro PSU 12Vdc 1Amp Wall Mounting

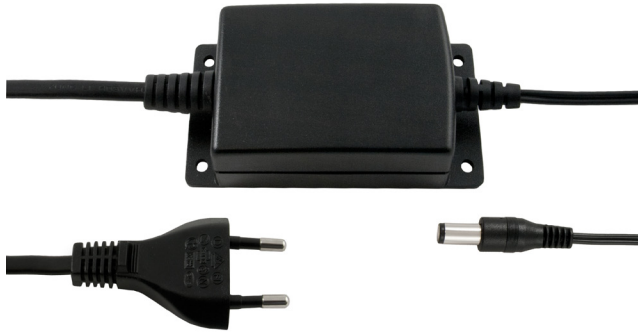

Features

- Universal AC Input
- Fixed Euro AC Mains Lead
- Small & Compact Design
- Built-in wall mounting tabs
- Over Voltage, Short Circuit & Over Temp. Protections
- ErP Level V
- RoHS Compliant
- MTBF >50,000 hours

RS Stock Number	Manufacturers P/N	Output Voltage	Output Current (Min)	Output Current (Max)	Power (Watts)	Line Regulation	Voltage Tolerance	Ripple & Noise (mV- p-p)
8280046	T3299EG	12Vdc	0A	1A	12W	+/-5%	+/-5%	150mV

Input

- Rated Input 100-240Vac
- Rated Input Frequency 50-60Hz
- Input Current 300mA
- Inrush Current 60A at 230Vac
- Leakage Current <0.25mA
- Efficiency >77.7%
- 1.8M EU Mains Lead with Plug

Output

- 1.8M Cable
- Straight 2.1C+ve Connector

Environmental

- Operating Temperature 0°C to 40°C
- Storage Temperature -10°C to 70°C
- Operating Humidity 20% to 80%
- Storage Humidity 10% to 90%

Casing

- Dimensions 75mm x 47.5mm x 26.5mm
- Weight 220g (approx.)

