

Dual USB DC/DC Adapter

12Vdc in 5Vdc out 2x1A



Features

- 12Vdc Input
- Car Charger Style Design
- Small & Compact
- 2 x 1A USB Output
- Over Load & Short Circuit Protections
- ErP Level V
- RoHS Compliant
- MTBF >50,000 hours


RS Stock Number	Manufacturers P/N	Output Voltage	Output Current (Min)	Output Current (Max)	Power (Watts)
8280226	T5297ST	+/- 5Vdc	0A	2A (1A Each Port)	10W

Input

- Rated Input 12Vdc
- Input Current <30mA
- Cigarette Lighter Style Inlet

Output

- Dual Port USB Outlet

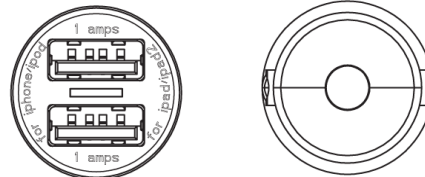

Environmental

- Operating Temperature 0°C to 25°C
- Storage Temperature -20°C to 60°C
- Operating Humidity 20% to 90%
- Storage Humidity 0% to 100%

Casing

- Dimensions 23mm x 45.3mm

