




**Professionally approved products.**

## Product Datasheet

75mm Bolt Hole Braked Swivel Castor with Grey Rubber Tyred Wheel, 70kg load capacity

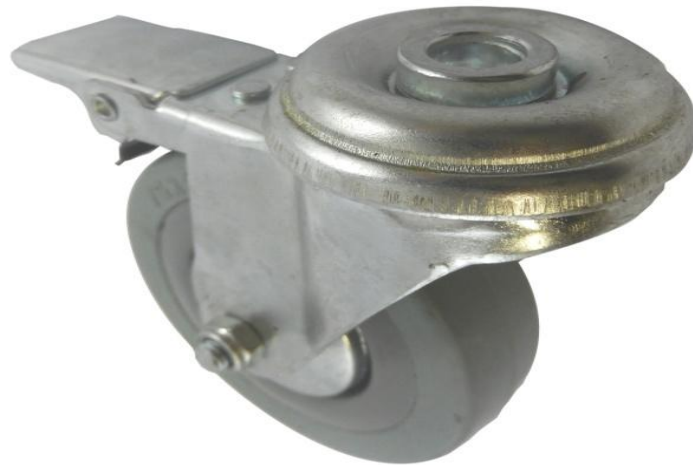

Specification	
Application	General Purpose / Industrial
Features	Ball Bearing Swivel Head
Fixing Centres	Single Bolt Hole
Fixing Hole Size	10mm
Hub Bearing Type	Plain
Hub Material	Polypropylene
Load Capacity	70kg
Number of Fixing Holes	1
Overall Height	100mm
Rotation	Swivel & Brake
Tyre Material	Grey Rubber Tyre
Weight Class	Light Duty
Wheel Diameter	75mm
Wheel Width	21mm

*RS, Professionally Approved Products, gives you professional quality parts across all products categories. Our range has been testified by engineers as giving comparable quality to that of the leading brands without paying a premium price.*

