


Professionally approved products.

## Datasheet

# NewRS Maximum of 30 V Pk-Pk Panel Mount Piezo Buzzer, Maximum of 9500 Hz

RS Stock 837-7844

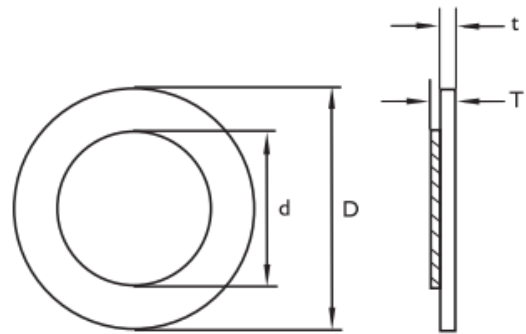

Dimensions: (mm)

### Specifications

### ABT-456-RC

Rated max voltage (Vp-p square wave)	30Vp-p
Capacitance	8000pF±30%
Resonant frequency	9500±1000Hz
Resonant impedance	≥1000Ω
Operating temperature	-20~+60°C
Storage temperature	-30~+70°C
Dimensions D±0.1	12mm
d±0.3	9mm
t±0.02	0.1mm
T±0.1	0.22mm

### Features

- ROHS compliant
- Low power consumption
- Reliable and lightweight

All data at 25°C unless otherwise specified