

Professionally approved products.


Datasheet

NewRS Maximum of 30 V Pk-Pk Panel Mount Piezo Buzzer, Maximum of 2800 Hz

RS Stock 837-7853



Dimensions: (mm)

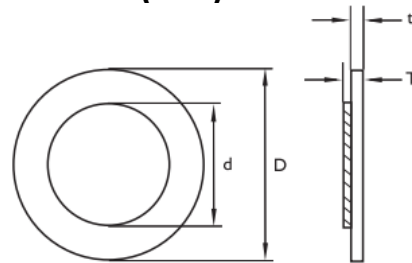

Specifications

ABT-457-RC

Rated max voltage (Vp-p square wave)	30Vp-p
Capacitance	37000pF±30%
Resonant frequency	2800±300Hz
Resonant impedance	≥600Ω
Operating temperature	-20~+60°C
Storage temperature	-30~+70°C
Dimensions D±0.1	35mm
d±0.3	25mm
t±0.02	0.25mm
T±0.1	0.51mm

Features

- ROHS compliant
- Low power consumption
- Reliable and lightweight

All data at 25°C unless otherwise specified