


Professionally approved products.

Datasheet

Prototyping board

RS Stock number 100-4334

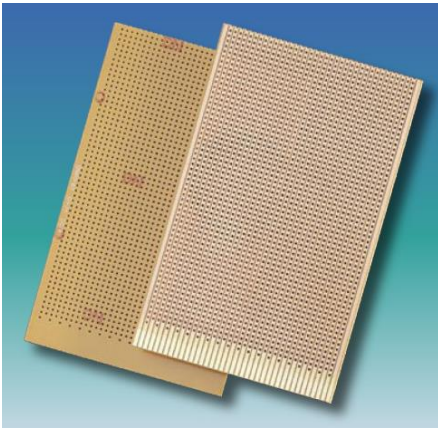

Description

This board combines the unique Veroboard pattern with the 37 way 2,54mm pitch direct edge connector. Intended primarily for hard wiring of discrete components it is equally useful where a number of common bus or signal lines are required.

Features

Ideal for hard wired applications
37 way 2,54mm pitch gold plated tongue

Board Specifications

Board type Epoxy glass
Base material SRBP
Single sided copper BS4584 part 16
Max. working temp. 155oC
Nom. board thickness (inc. copper) 1,6mm
Copper thickness 35µm or 1oz/ft2 or 305g/m2

| Dimensions | Tracks | Holes per track | Base material |
|------------|--------|-----------------|---------------|
| 100 x 160 | 37 | 57 | SRBP |

Note: hole grid 2,54 x 2,54mm Hole dia. 1,02mm Contact pitch 2,54mm