



Data Specification Sheet

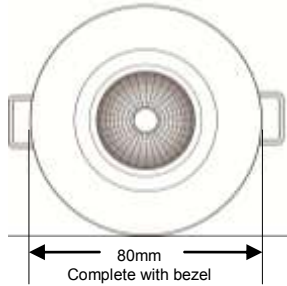

Shown with Bezel (not included)

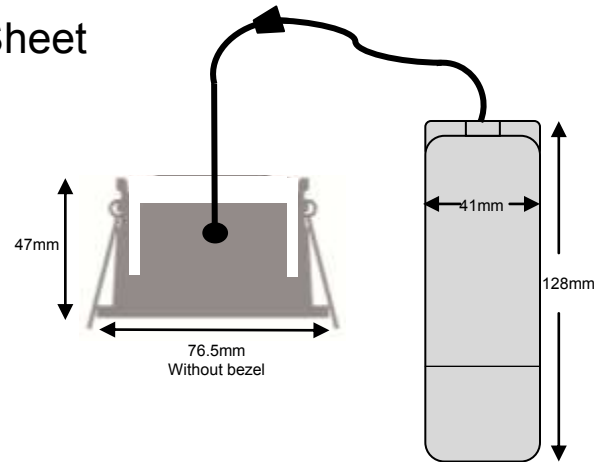

IP65 LED Fire Rated Downlight c/w Dimmable Driver

| | | | |
|--|---|------------------------|--|
| Description | IP65 LED Fire Rated Downlight c/w Dimmable Driver | | |
| Code | 851-2968 Warm White IP65 LED Fire Rated Downlight 851-2980 Cool White IP65 LED Fire Rated Downlight | | |
| Code – Bezel Only | 858-0958 – Matt White Bezel | 858-0942 – Brass Bezel | 858-0949 – Chrome Bezel 858-0945 – Brushed Chrome Bezel |
| Bezel Diameter | 80mm | | |
| Rim Diameter | 76.5mm | | |
| Cut Out | 64mm | | |
| Minimum Depth (Void) | 75mm | | |
| Total length of driver lead | 300mm | | |
| Weight | 0.29Kg | | |
| Recommended product location | Indoor Outdoor | | |
| Finishes available (Bezels sold separately) | Matt White, Brass, Chrome, Brushed Chrome | | |
| Control Gear Type | 8W 180mA SELV LED Dimmable Driver supplied pre-wired to downlight | | |
| Lamp Supplied | Fixed non-replaceable 8W COB LED | | |
| Class | Class II. Must not be Earthed | | |
| IP | IP65 | | |
| Photometric Testing | Yes | | |
| Lumen Output | 460lm Warm White – 530lm Cool White | | |
| Beam Angle | 38° | | |
| Dimmable | Yes | | |
| Instruction sheet | Yes | | |
| Origin of manufacture | China | | |
| Main materials: | | | |
| • Chassis | Pressed Steel | | |
| • Body | Die cast | | |
| • Bezel | Die cast | | |
| Method of fix | Twin fixed spring | | |
| Electrical Connections | Loop in 10Amp L.N. + Earth Park Nylon Connector, Push-in Terminals | | |
| CE mark | Yes | | |
| Batch coding details on product | Yes | | |
| Certificate of Conformity (Held on File) | Yes | | |
| Manufactured in accordance | EN60598-1 General requirements EN60598-2-1 Fixed general purpose luminaires EN60598-2-2 Recessed luminaires BS5250 (Energy efficiency, Useful heat loss and passage of condensation), BS ISO 10140 : Acoustics : Building Elements Part P (Installation requirements) BS476 – Part 21 & Part 23 Fire rating | | |

