 



 
 

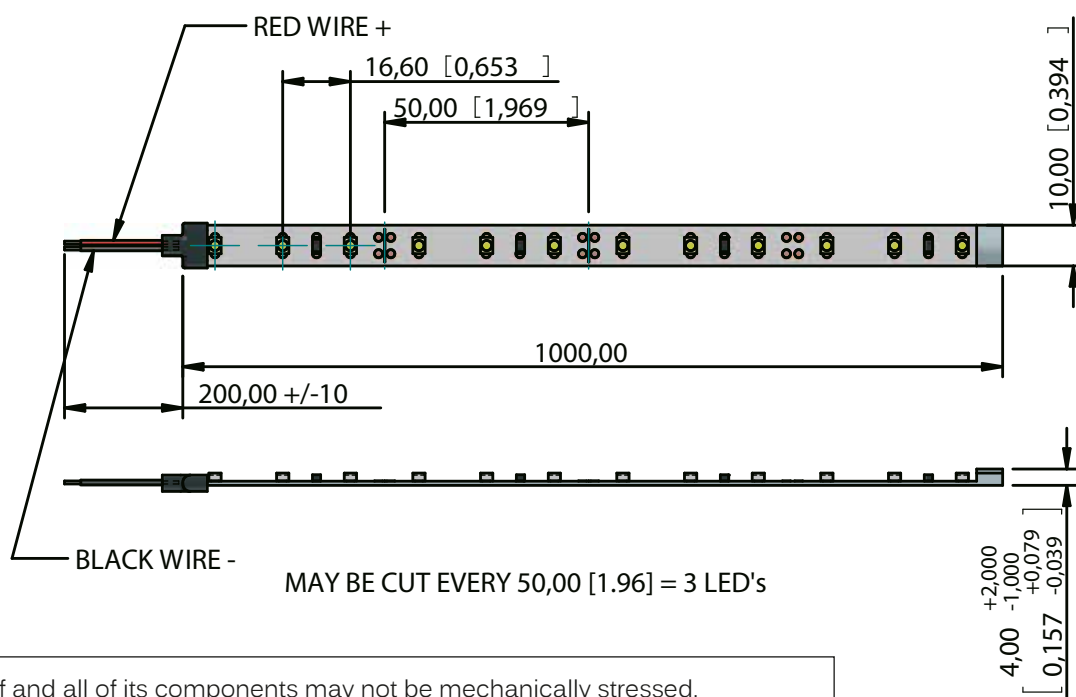




FLEXIBLE LED LIGHTING STRIPS

Technical Information	Colour		Light Output Lumens/m	Part Number
<ul style="list-style-type: none">• LED: SMD3528 60LED/M• Voltage: 12VDC• Current: 400mA• Max consumption: (W/m) power 4.8• Dimensions: 10mm x 1000mm (1 Metre)• Beam angle: 120°• Sealed up to IP65 Crystal Resin		Cool White	550	LSCW6121MIP65RS
		White	450	LSNW6121MIP65RS
		Warm White	400	LSWW6121MIP65RS
		Red	240	LSR6121MIP65RS
		Green	350	LSG6121MIP65RS
		Blue	40	LSB6121MIP65RS
		Yellow	150	LSY6121MIP65RS



The strip itself and all of its components may not be mechanically stressed.
Assembly must not damage or destroy conducting paths on the circuit board.
Correct electrical polarity needs to be observed, wrong polarity may destroy the strip.
When mounting on a metallic or otherwise conductive surfaces, there needs to be electrical isolation points between strip and the mounting surface.
Caution needs to be taken after cutting the strip that exposed ends are insulated.