



Professionally approved products. Datasheet

New 5.0mm Screwless 10A 8 Way

RS Stock 874-5486

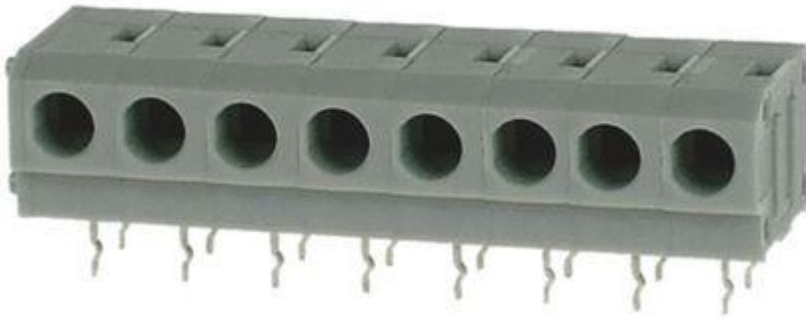

Dimensions: (mm)

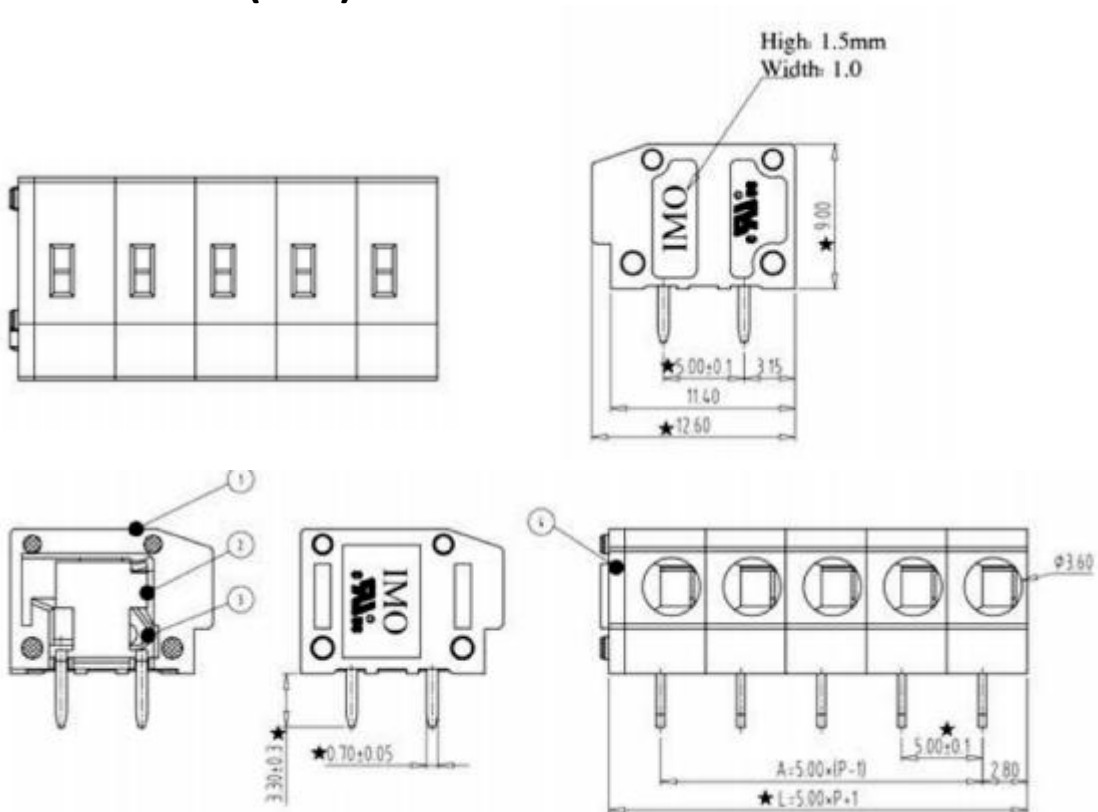

Professionally approved products. Datasheet

Specifications

- Rated Voltage: 300V 10A (UL)
- Insulation Resistance: $\geq 500\Omega\text{M}$ or more at DC500V
- Withstanding Voltage: AC 1600V/1 min
- Temperature Range: $-40^{\circ}\text{C} \sim +105^{\circ}\text{C}$
- Suitable Electric Wire: 14-20AWG
- Insulation Stripping Length: 8mm

Materials

- Housing: PA66 / UL94V-0
- Spring Coil: Stainless Steel
- Solder pin: Brass / Tin Plated
- End Cover: PA66 (VO)