


BKS-S111-RT13
BCC02HC

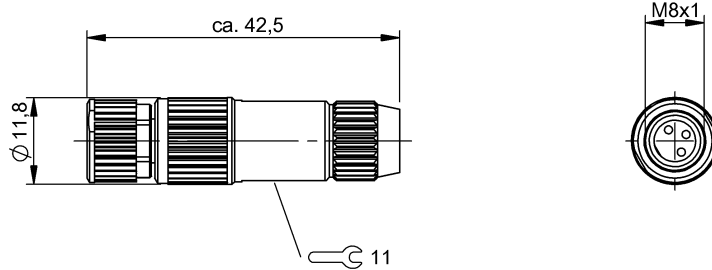

Display/Operation

Power indicator no

Electrical connection

Cable diameter D 2.5...5.1 mm
Number of pins 3
System Can be fabricated

Electrical data

Rated current (40 °C) 4.0 A

Environmental conditions

Ambient temperature -40...85 °C
Protection type IEC 60529 IP67

General data

Approval/Conformity cURus

Material

Conductor insulation material PVC
PP
TPE
Housing material PA
Zinc, Die casting
Material contact carrier PA
Material contacts Copper alloy
Material cover nut Brassnickel plates
Material grip Plastic

Mechanical data

Conductor diameter min. 1 mm
Connection cross-section 0.14...0.34 mm²
Connection cycles min. 100
Core diameter max. 1.60 mm
Lead diameter min. 0.1 mm
Tightening torque pigtail 0.4 Nm

Remarks

max. connection frequency with same cable cross-section 10

Connector view

