


BIS L-503-PU1-05
BCC00R2

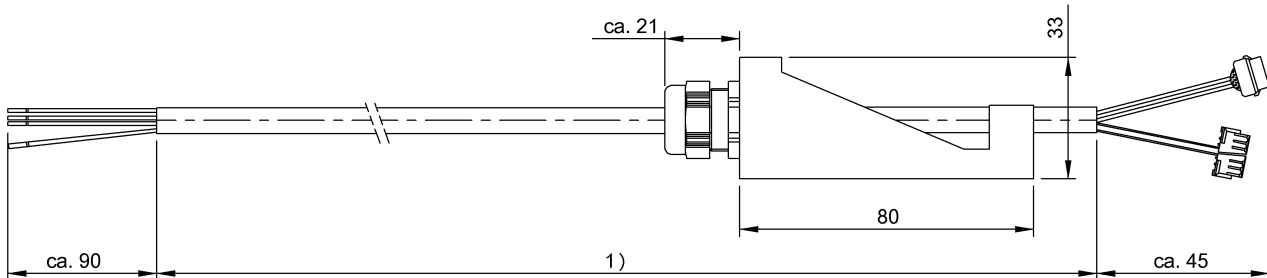

1) Cable length see text



Electrical connection

Bending radius min., flexible cable	12.5 x D
Cable diameter D	7.50 mm
Cable length	5 m, Drag chain compatible
Connection type	5.00 m, PU

Environmental conditions

Cable temperature, drag chain	-30...90 °C
Cable temperature, fixed routing	-50...90 °C
Cable temperature, flexible routing	-30...90 °C
Protection type IEC 60529	IP65 installed

General data

Approval/Conformity	CE
---------------------	----

Material

Material jacket	PU
-----------------	----

Remarks

Connector unit: for connecting BIS L-405-xx-MU drag chain compatible
Mounting base made of PBT with open cable end.