


BDN C-F01-AN-NAN-01
BCC07A9

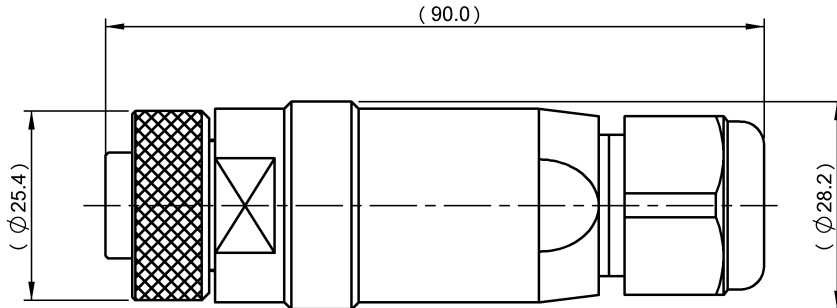

L



Electrical connection

Cable diameter D	5...12 mm
Number of pins	5
System	Can be fabricated

Electrical data

Operating voltage U_b	600 VDC
Rated current (40 °C)	8.0 A

Environmental conditions

Ambient temperature	-40...80 °C
Protection type IEC 60529	IP68

General data

Application	DeviceNet
-------------	-----------

Approval/Conformity

cCSAus

Material

Material contact carrier	PUR
Material contacts	Bronze
Material cover nut	Brassnickel plates
Material grip	PA


Mechanical data

Connection cross-section	0.205...1.65 mm ²
Type of wire mounting	Screw terminals

Remarks


Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

Connector view

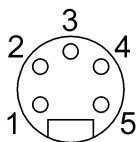

BDN C-F01-AN-NAN-01
BCC07A9

Wiring Diagram

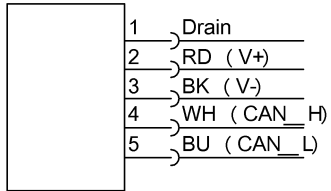

L