


BIS C-521-SA1-PVC-02
BCC06Y7

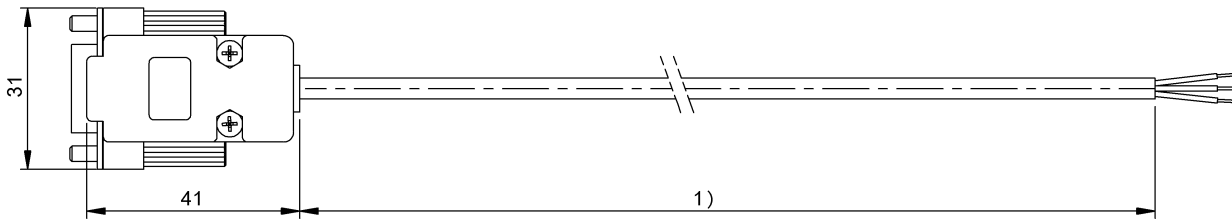

1) Cable length see text



Electrical connection

Cable	PVC Shielded gray, 2.00 m
Cable diameter D	5.80 mm
Conductor cross-section	0.25 mm ²
Number of conductors	4

Environmental conditions

Cable temperature, fixed routing	-30...80 °C
Cable temperature, flexible routing	-5...80 °C
Protection type IEC 60529	IP40 installed

General data

Application	RFID
Approval/Conformity	CE

Remarks

Connection cable: for internal service port RS 232 (on terminal strip) for connecting to PC.
1x MIN D female 9-pin threaded on with 3-conductor cable end incl. end ferrules
Cable were labeled