

SIGNALLING COLUMN MULTI-FUNCTION SIREN  
ELEMENT DIFFERENT SOUNDS SETTABLE 115V AC



Figure similar

General technical data:		
product brand name		SIRIUS
Product designation		Siren element
Type of voltage of the operating voltage		AC
Operating voltage		
• 1 at AC at 50 Hz Rated value	V	115
• 1 at AC at 60 Hz Rated value	V	115
Type of acoustic signal		continuous tone
Loudness level	dB	100
Equipment marking acc. to DIN EN 61346-2		P

Mechanical data:		
Outer diameter of the signal column element	mm	70

Ambient conditions:		
Ambient temperature during operation	°C	-20 ... +50
Protection class IP		IP65
Product function adjustable acoustic signal		Yes
Height	mm	72
Width	mm	70

Certificates/ approvals:

General Product Approval	EMC	Declaration of Conformity	Shipping Approval
--------------------------	-----	---------------------------	-------------------



Further information

**Information- and Downloadcenter (Catalogs, Brochures,...)**

<http://www.siemens.com/industrial-controls/catalogs>

**Industry Mall (Online ordering system)**

<http://www.siemens.com/industrymall>

**Cax online generator**



<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD44400EA2>

**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**

<https://support.industry.siemens.com/cs/ww/en/ps/8WD44400EA2>

**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)**

[http://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=8WD44400EA2&lang=en](http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD44400EA2&lang=en)

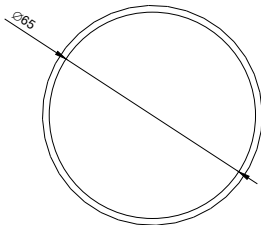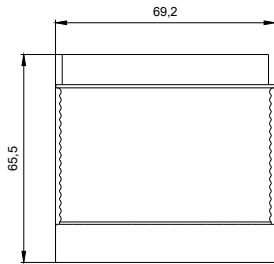

WB:8331: 8WD44...\_ALL



last modified:

16.10.2015