
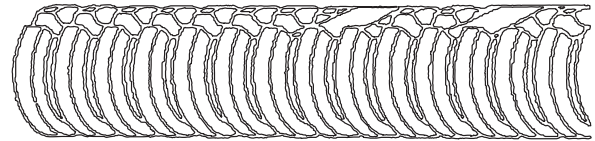


Colored Split Loom

Features

- Designed to Hold and Protect Cables, Harnesses, and Hoses
- Quick and Easy to Install. Slit Automatically Closes after Installation
- Polyethylene Construction
- Temperature Rating:
 Brittleness Temperature (ASTM D746): -50°C (-58°F)
 Vicat Softening Temperature (ASTM D1525): +87°C (+188°F)

SL-01

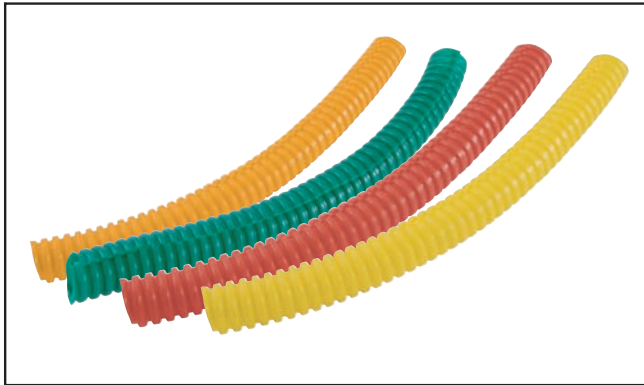

Colored Split Loom (Note 1)

NTE Type No.	Length (feet)	Inner Diameter (in. / mm)	Outer Diameter (in. / mm)	Max. Wall Thickness (in. / mm)	Diag No.
04-SL.250-X	100	.266 / 6.75	.395 / 9.92	.010 / .254	SL-01
04-SL.250-X-5	5	.266 / 6.75	.395 / 9.92	.010 / .254	SL-01
04-SL.250-X-10	10	.266 / 6.75	.395 / 9.92	.010 / .254	SL-01
04-SL.375-X	100	.419 / 10.64	.535 / 13.59	.008 / .203	SL-01
04-SL.375-X-5	5	.419 / 10.64	.535 / 13.59	.008 / .203	SL-01
04-SL.375-X-10	10	.419 / 10.64	.535 / 13.59	.008 / .203	SL-01
04-SL.500-X	100	.505 / 12.83	.670 / 17.02	.010 / .254	SL-01
04-SL.500-X-5	5	.505 / 12.83	.670 / 17.02	.010 / .254	SL-01
04-SL.500-X-10	10	.505 / 12.83	.670 / 17.02	.010 / .254	SL-01
04-SL.625-X	100	.650 / 16.51	.825 / 20.96	.008 / .203	SL-01
04-SL.625-X-5	5	.650 / 16.51	.825 / 20.96	.008 / .203	SL-01
04-SL.625-X-10	10	.650 / 16.51	.825 / 20.96	.008 / .203	SL-01
04-SL.750-X	100	.761 / 19.33	.927 / 23.55	.008 / .203	SL-01
04-SL.750-X-5	5	.761 / 19.33	.927 / 23.55	.008 / .203	SL-01
04-SL.750-X-10	10	.761 / 19.33	.927 / 23.55	.008 / .203	SL-01
04-SL1.00-X	100	.909 / 23.09	1.033 / 26.24	.010 / .254	SL-01
04-SL1.00-X-5	5	.909 / 23.09	1.033 / 26.24	.010 / .254	SL-01
04-SL1.00-X-10	10	.909 / 23.09	1.033 / 26.24	.010 / .254	SL-01

Note 1. Replace "X" in device number with O = Orange, G = Green, R = Red, Y = Yellow.