


ATM Equivalent – Low Voltage Miniature Automotive, Fast Acting

Features

- Miniature Blade Type
- RoHS Compliant



F-05

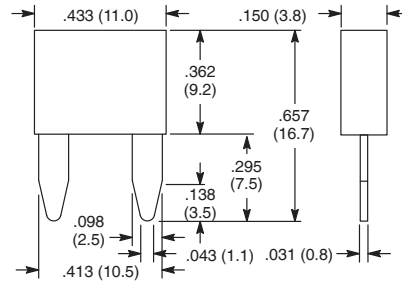

Specifications

Rated Voltage: 32V

Time Current Characteristics:

% of Ampere Rating	Opening Time
110%	4 hours min.
135%	0.75 – 1800 seconds
200%	0.15 – 5 seconds
300%	0.08 seconds max.

Accessories:


Description	NTE Type No.
In-Line Fuse Holder, up to 15A	74-IFHMA15
In-Line Fuse Holder, up to 30A	74-IFHMA30
In-Line Fuse Holder w/LED Light, up to 15A	74-IFHMAL15
In-Line Fuse Holder w/LED Light, up to 30A	74-IFHMAL30

NTE Type No.	Rated Current	Color Code	Diag No.
NEW 74-MAF2A	2A	Gray	F-05
NEW 74-MAF3A	3A	Violet	F-05
NEW 74-MAF4A	4A	Pink	F-05
74-MAF5A	5A	Tan	F-05
74-MAF7.5A	7.5A	Brown	F-05
74-MAF10A	10A	Red	F-05
74-MAF15A	15A	Blue	F-05
74-MAF20A	20A	Yellow	F-05
74-MAF25A	25A	Natural	F-05
74-MAF30A	30A	Green	F-05


ATC Equivalent - Low Voltage Automotive, Fast Acting

Features

- Fast Acting
- RoHS Compliant

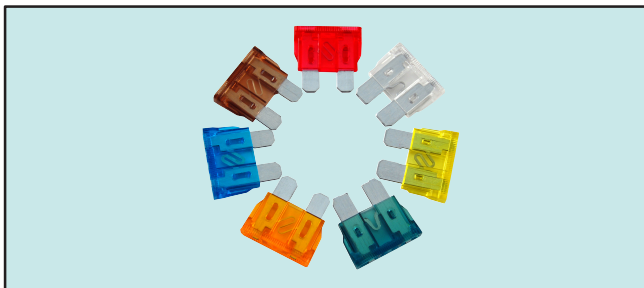

F-06

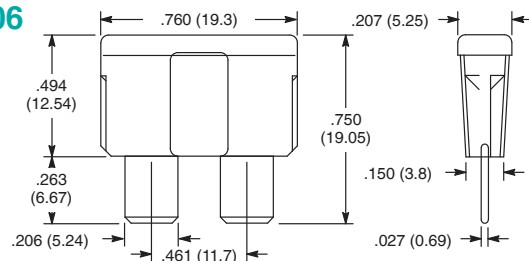

Specifications

Rated Voltage: 32V

Time Current Characteristics:

% of Ampere Rating	Opening Time
110%	100 hours min.
135%	1800 seconds max.
200%	5 seconds max.
300%	0.08 seconds max.

Accessories:

Description	NTE Type No.
In-Line Fuse Holder, up to 15A	74-IFHA15
In-Line Fuse Holder, up to 30A	74-IFHA30
In-Line Fuse Holder w/LED Light, up to 15A	74-IFHAL15
In-Line Fuse Holder w/LED Light, up to 30A	74-IFHAL30

NTE Type No.	Rated Current	Color Code	Diag No.
NEW 74-AF1A	1A	Black	F-06
NEW 74-AF2A	2A	Gray	F-06
NEW 74-AF3A	3A	Violet	F-06
NEW 74-AF4A	4A	Pink	F-06
74-AF5A	5A	Tan	F-06
74-AF7.5A	7.5A	Brown	F-06
74-AF10A	10A	Red	F-06
74-AF15A	15A	Blue	F-06
74-AF20A	20A	Yellow	F-06
74-AF25A	25A	Natural	F-06
74-AF30A	30A	Green	F-06