


6GK1901-1BB10-2AE0 IE FC RJ45 PLUG 180 2X2

Technical Data

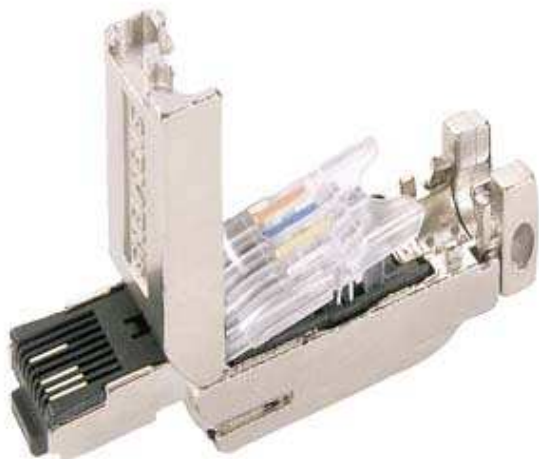

IE FC RJ45 PLUG 180 2X2, RJ45 PLUG CONNECTOR (10/100MBIT/S) WITH RUGGED METAL HOUSING AND FC CONNECTING METHOD, FOR IE FC CABLE 2X2 180 DGR CABLE OUTLET 1 PACK = 50 PCS

Transfer rate

- 1 / for Industrial Ethernet 10 Mbit/s
- 2 / for Industrial Ethernet 100 Mbit/s

Interfaces

Number of electrical connections

- for Industrial Ethernet FC TP cables 4
- for network components and terminal equipment 1

Design of the electrical connection / FastConnect Yes

Mechanical data

material / of the housing metal

Design, dimensions and weight

Width 13.7 mm

Height 16 mm

Depth 55 mm

Net weight 35 g

Permitted ambient conditions

Ambient temperature

- during operating -40...+70 °C
- during storage -40...+80 °C
- during transport -40...+80 °C

Relative humidity

- at 25 °C / without condensation / during operating / maximum 95 %

Protection class IP	IP20
Product properties, functions, components / general	
Product feature / [not supplied - silicon-free]	Yes
Composant produit	
• décharge de traction	Yes
Standards, specifications, approvals	
Verification of suitability	
• RoHS conformity	Yes
• UL-registration	Yes
letzte Änderung:	May 14, 2012