

PLUG-IN RELAY COMPACT UNIT AC 24V, 2 CO  
CONTACT LED MODULE RED SOCKET W. LOGIC  
ISOLATION SCREW TERMINAL



Figure similar

General technical data:

Supply voltage frequency for auxiliary and control current circuit Rated value		
• minimum	Hz	50
• maximum	Hz	60
<b>Type of voltage</b>		AC
<b>Control supply voltage</b>		
• at AC		
— at 50 Hz Rated value		
— minimum	V	24
— maximum	V	24
— at 60 Hz Rated value		
— minimum	V	24
— maximum	V	24
Number of NC contacts for auxiliary contacts		0
Number of NO contacts for auxiliary contacts		0
Number of CO contacts for auxiliary contacts		2
Operating current of the auxiliary contacts		
• at AC-15		

— at 230 V	A	2.5
Design of the switching function positively driven		No
Switching behavior		monostable

#### Mechanical data:

Type of electrical connection		screw-type terminals
Design of the relay operating mechanism		poled
Product component Plug-in socket		Yes
Width	mm	15.5
Height	mm	71
Depth	mm	77

#### Certificates/ approvals:

General Product Approval	Declaration of Conformity
--------------------------	---------------------------



EG-Konf.

#### Further information

##### Industry Mall (Online ordering system)

<http://www.siemens.com/industrymall>

##### Cax online generator

<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=LZS:RT4B4R24>

##### Information- and Downloadcenter (Catalogs, Brochures,...)



<http://www.siemens.com/industrial-controls/catalogs>

##### Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/LZS:RT4B4R24>

##### Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

[http://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=LZS:RT4B4R24&lang=en](http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=LZS:RT4B4R24&lang=en)

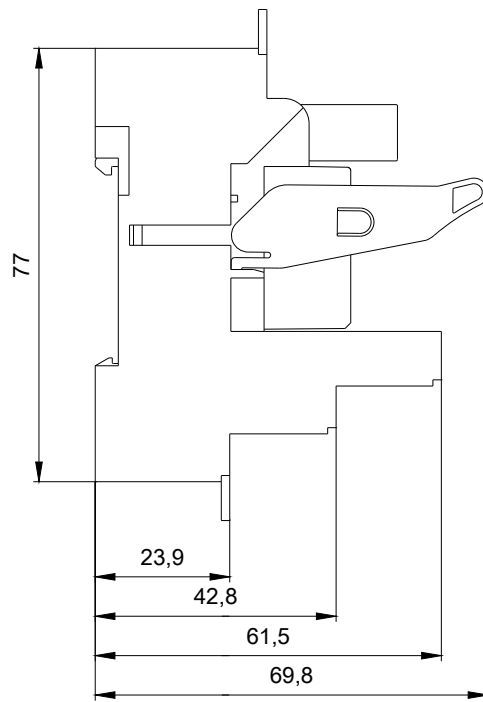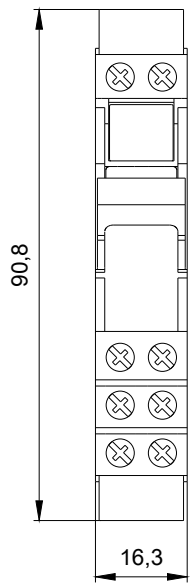

last modified:

18.07.2015