


# Steel Alligator Clip w/Barrel, Screw & Handle, 10 Amp

## Features

- Nickel Plated Clip with Insulated Handle
- Banana Plug or Screw Connection
- Overall Length: 1.950" (49.5mm)
- Jaw Opening: .310" (7.87mm)

NTE Type No.	Description
72-152-0	Steel Alligator Clip with Barrel, Screw and Black Insulated Handle
72-152-2	Steel Alligator Clip with Barrel, Screw and Red Insulated Handle
72-152-KIT	2 Each of 72-152-0 (Black) & 72-152-2 (Red)

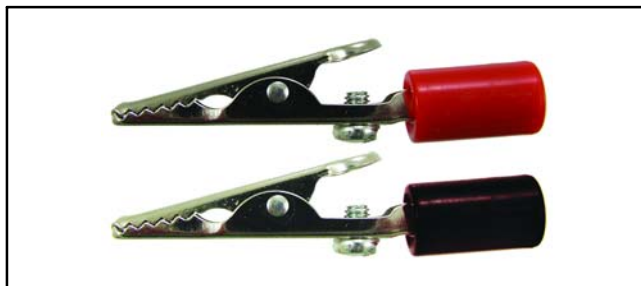

# Solid Copper Alligator Clip w/Barrel, Screw & Handle, 10 Amp

## Features

- Solid Copper Clip with Insulated Handle
- Banana Plug or Screw Connection
- Overall Length: 2.344" (59.53mm)
- Jaw Opening: .310" (7.87mm)

NTE Type No.	Description
72-150-0	Solid Copper Alligator Clip with Barrel, Screw and Black Insulated Handle
72-150-2	Solid Copper Alligator Clip with Barrel, Screw and Red Insulated Handle
72-150-4	Solid Copper Alligator Clip with Barrel, Screw and Yellow Insulated Handle
72-150-5	Solid Copper Alligator Clip with Barrel, Screw and Green Insulated Handle
72-150-6	Solid Copper Alligator Clip with Barrel, Screw and Blue Insulated Handle
72-150-9	Solid Copper Alligator Clip with Barrel, Screw and White Insulated Handle
72-150-KIT	2 Each of 72-150-0 (Black) & 72-150-2 (Red)



# Steel Alligator Clip, Insulated, 10 Amp

## Features

- Nickel Plated Clip
- Includes Skin Tight Insulation
- Banana Plug or Screw Connection
- Overall Length: 2.125" (53.9mm)
- Jaw Opening: .310" (7.87mm)

NTE Type No.	Description
72-158-0	Steel Alligator Clip w/Skin Tight Insulation, Black
72-158-2	Steel Alligator Clip w/Skin Tight Insulation, Red
72-158-KIT	2 Each of 72-158-0 (Black) & 72-158-2 (Red)

