

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0006023042](#)
Status: **Active**
Description: Flat Blade Appliance Defrost Timer Crimp Housing, 4 Circuit, 4 Circuits

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family Crimp Housings
 Series [42400](#)
 Application Power
 Product Name Flat Blade
 UPC 800754942676

Physical

Circuits (maximum) 4
 Color - Resin Natural
 Flammability 94V-2
 Gender Receptacle
 Glow-Wire Capable No
 Keying to Mating Part Yes
 Lock to Mating Part None
 Material - Resin Nylon
 Net Weight 4.408/g
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 5.56mm, 9.63mm
 Pitch - Termination Interface 5.56mm, 9.63mm
 Stackable No
 Temperature Range - Operating -40° to +75°C

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number 42400-0001

Reference - Drawing Numbers

Sales Drawing SD-42400-001

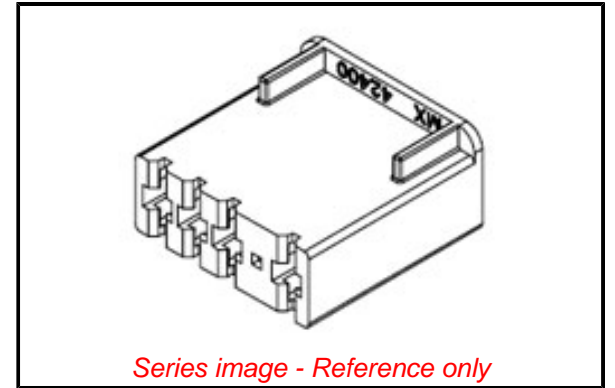

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[42400 Series](#)

Mates With

Appliance Timer

Use With

[41422](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION