


T-2¼ BA9s BASE

XENON GAS FILLED LAMP

12V 10W

WAMCO PART NO.	ENVELOPE SIZE	BASE TYPE	RATING	FILAMENT SHAPE			
WL-998502-4	T-2¼	BA9s	12V 10W	C-8Z			
TEST VOLTS	CURRENT (A)			LIGHT OUTPUT (MSCP)			LIFE HRS
	MIN	NOM	MAX	MIN	NOM	MAX	
12V	.791	.833	.875	6.7	8.6	10.5	10,000

DIMENSIONAL CHARACTERISTICS

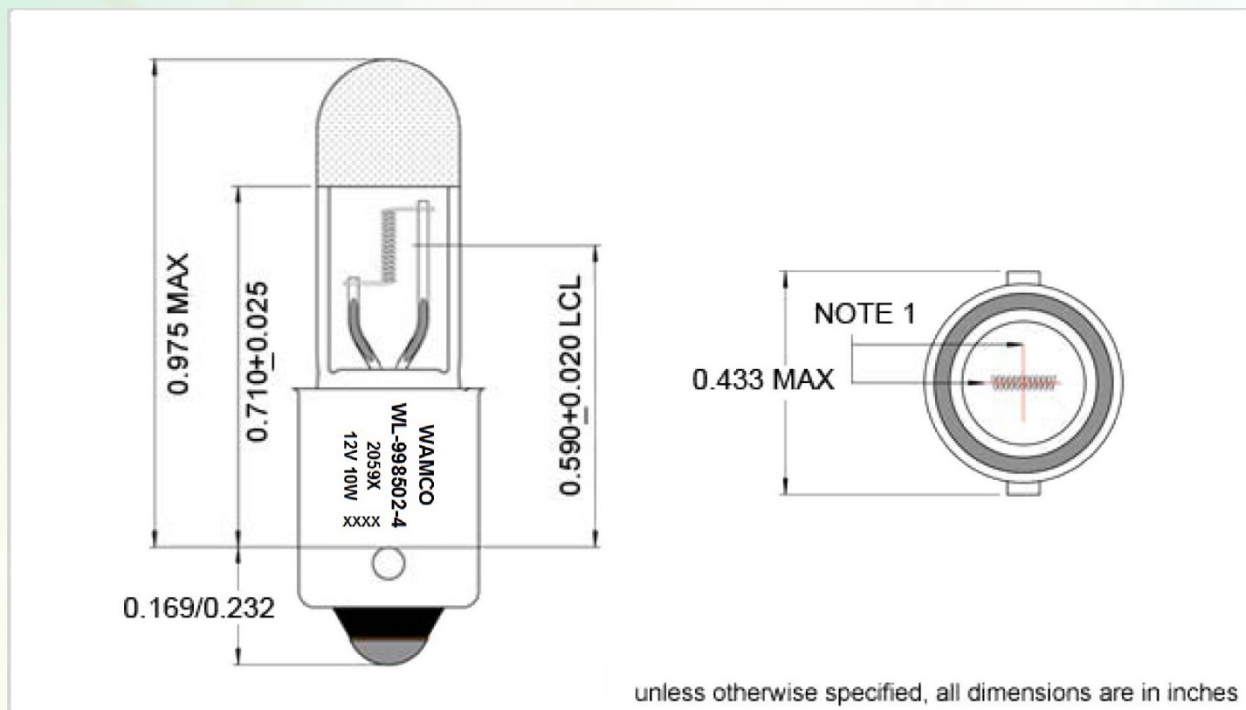

NOTES

1. Filament centered within $\pm .040''$ each axis, filament orientation to pins not specified
2. Center contact and internal ground connection solder consists of 95% tin & 5% silver, softening point 430°F, melting point 473°F
3. Part mark WAMCO WL-998502-4, 2059X, 12V, 10W, and lot code, marking orientation to pins not specified
4. RoHS compliant
5. ANSI trade number 2059 X

