


Professionally approved products.

Datasheet

SPDT Rocker Switch, ON-(ON)

RS Stock number 734-6889

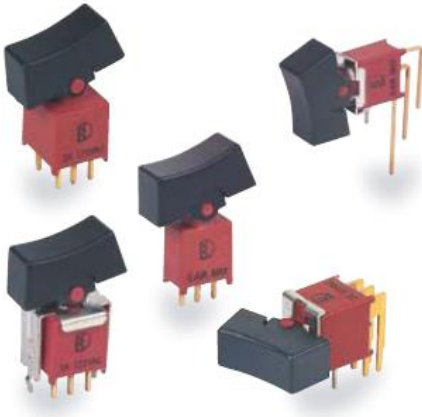

Specifications:

MECHANICAL LIFE:	30,000 make-and-break cycles.
CONTACT RESISTANCE:	20mΩmax. initial @ 2-4VDC 100mA for both silver and gold plated contacts.
100mA for	
INSULATION RESISTANCE:	1,000 MΩmin.
DIELECTRIC STRENGTH:	1,000Vrms min. @ sea level.
OPERATING TEMPERATURE:	-30°C to 85°C.
MATERIALS	
CASE & BUSHING :	Glass filled nylon 6/6, flame retardant, heat stabilized (UL94V-0).
ACTUATOR:	Nylon, black standard. Internal O-ring seal standard with all actuators.
SWITCH SUPPORT:	Brass or steel, tin plated.
TERMINAL/CONTACT:	Silver or gold plated copper alloy.

