

Datasheet

SPDT Rocker Switch, ON-(ON)

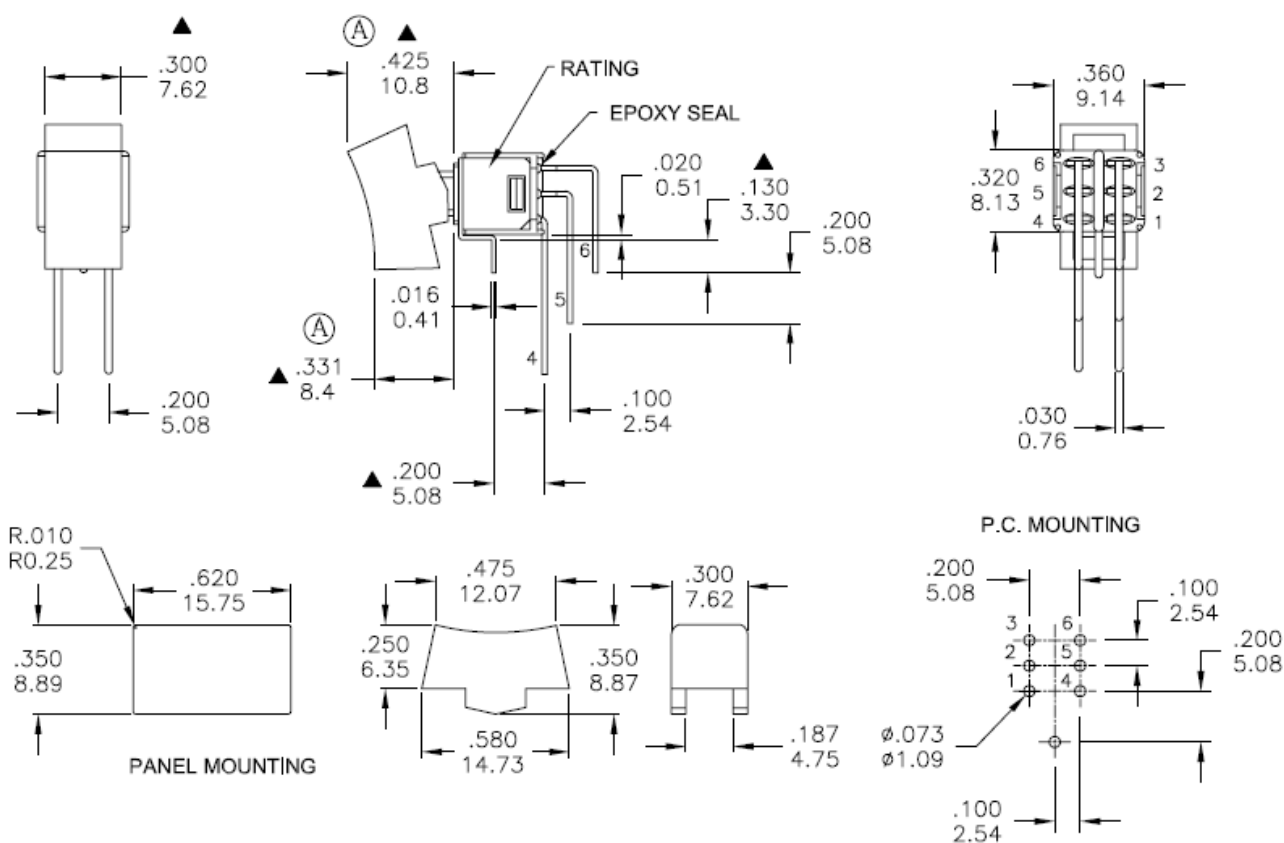
RS Stock number 734-6912

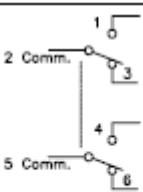
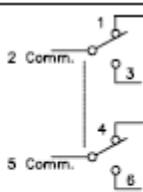


Specifications:

MECHANICAL LIFE:	30,000 make-and-break cycles.
CONTACT RESISTANCE:	20mΩmax. initial @ 2-4VDC 100mA for both silver and gold plated contacts.
INSULATION RESISTANCE:	1,000 MΩmin.
DIELECTRIC STRENGTH:	1,000Vrms min. @ sea level.
OPERATING TEMPERATURE:	-30°C to 85°C.
MATERIALS	
CASE:	Diallyl phthalate (DAP) (UL94V-0)
ACTUATOR:	Nylon, black standard.
SWITCH SUPPORT:	Brass, tin plated.
TERMINAL/CONTACT:	Brass, with silver or gold plated.
RoHS:	2002/95/EC

Dimensions – inch mm



Model No.	POS.1	POS.2	POS.3
4MD1	ON	NONE	ON
Term. Comm.	2-3,5-6	N/A	2-1,5-4
SCHEMATIC			

SWITCH FUNCTION