


Datasheet

Slide Switch


RS Stock number 734-7286

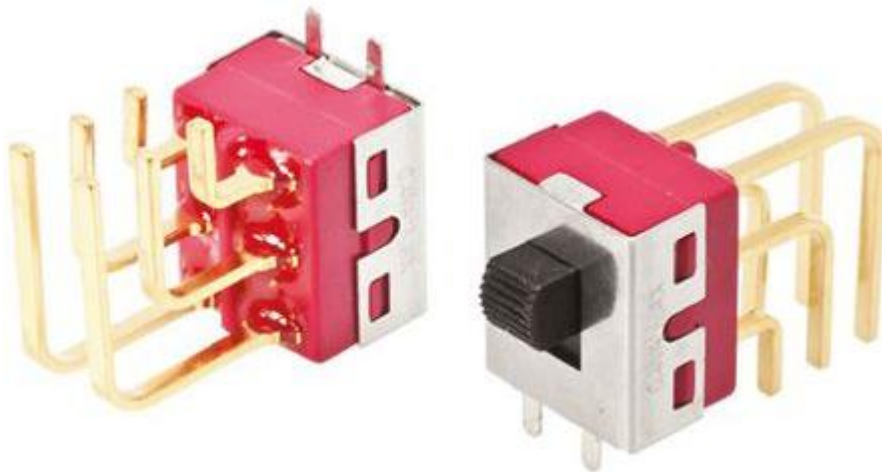

Specifications:

MECHANICAL LIFE:	30,000 make-and-break cycles at full load
CONTACT RESISTANCE:	10m Ω max. initial @ 2-4VDC 100mA for both silver and gold plated contacts
INSULATION RESISTANCE:	1000M Ω min.
DIELECTRIC STRENGTH:	1000Vrms min. @ sea level.
OPERATING TEMPERATURE:	-30°C to 85°C.
CASE:	Dially phthalate (DAP) (UL94v-0)
ACTUATOR:	Nylon, black
HOUSING:	Stainless steel
CONTACT:	Silver or gold plated
TERMINAL SEAL:	Epoxy
RoHS:	2002/95/EC

**Dimensions – inch
mm**

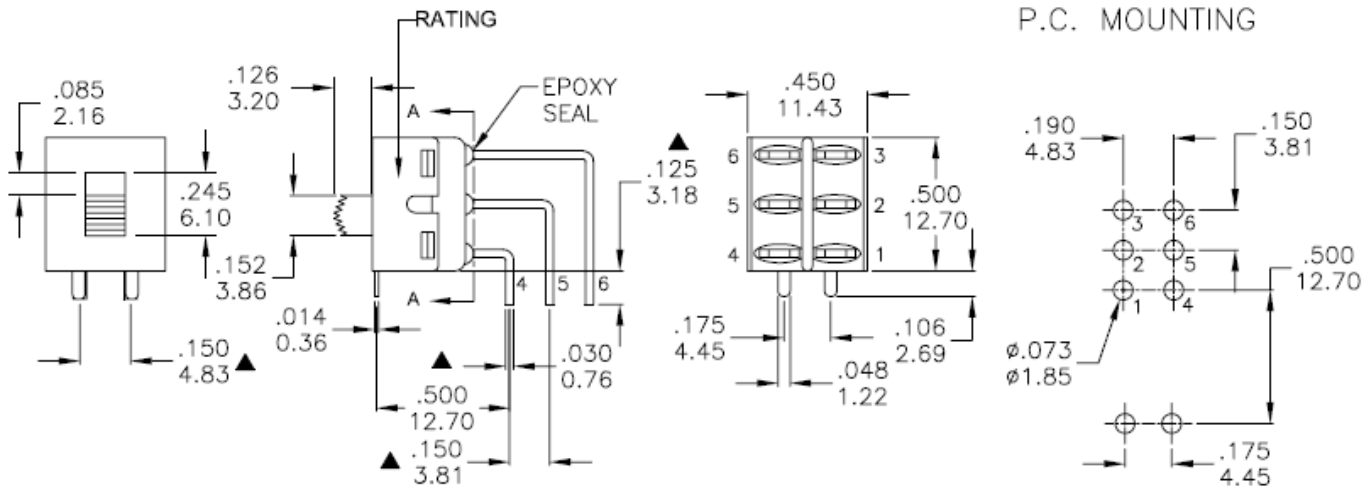

Model No.	POS.1	POS.2	POS.3
5MD1	ON	NONE	ON
Term. Comm.	2-1,5-4		2-3,5-6
SCHEMATIC		OPEN	

SWITCH FUNCTION