


BCC A417-0000-10-086-VX47W8-050
BCC0A3F

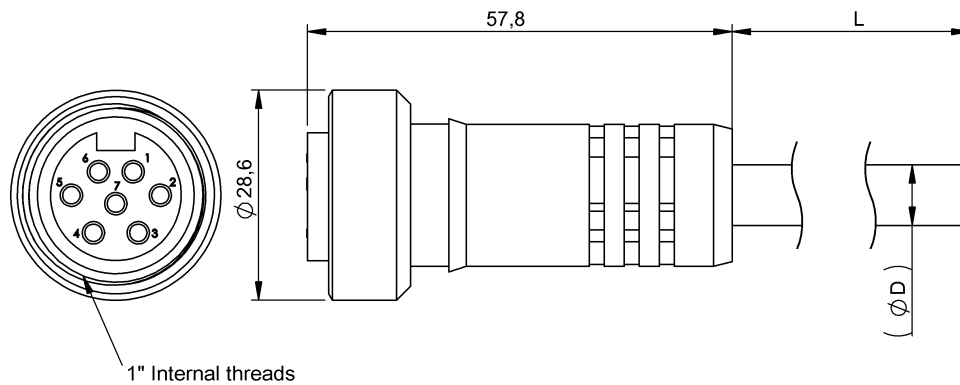

Electrical connection

Cable	PVC yellow, 5.00 m
Cable diameter D	8.25 mm ±0.13 mm
Conductor cross-section	AWG 18
Number of conductors	7
Number of pins	7
System	Molded

Electrical data

Rated current (40 °C)	5.0 A
-----------------------	-------

Environmental conditions

Cable temperature, fixed routing	-40...105 °C
Protection type IEC 60529	IP67

General data

Application	Operating voltage
Approval/Conformity	cULus LISTED


Material

Material contact carrier	PUR
Material contacts	Brass
Material cover nut	Aluminumanodized
Material grip	PVC

Remarks

Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.
Bulk cable: Oil resistant PVC jacket rated to 300 V, 105 °C, no wicking, non-hygroscopic, UL Style 2661 or 2517

Connector view

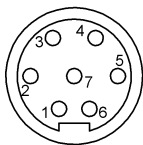

PIN 1: white/black PIN 2: black PIN 3: white PIN 4: red
PIN 5: orange PIN 6: blue PIN 7: green/yellow

BCC A417-0000-10-086-VX47W8-050
BCC0A3F

Wiring Diagram

