


BCC A51C-A51C-70-362-VX4CW8-050  
BCC0A5P

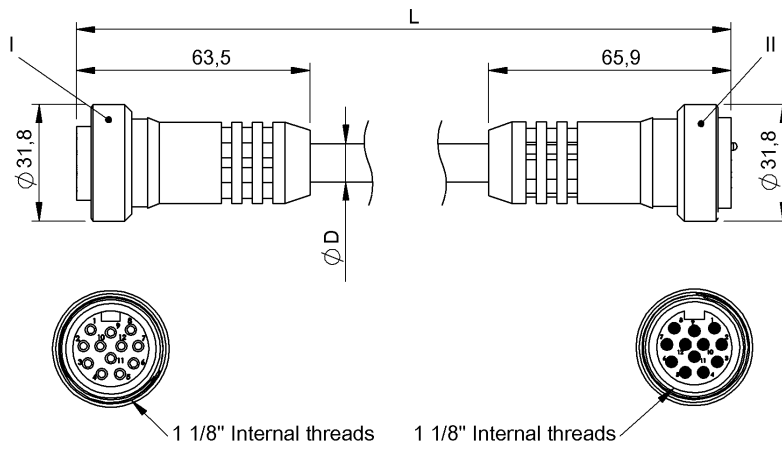

## Electrical connection

Cable	PVC yellow, 5.00 m
Conductor cross-section	AWG 18
Number of conductors	12
Number of pins	12/12
System	Molded/Molded

## Electrical data

Rated current (40 °C)	4.0 A
-----------------------	-------

## Environmental conditions

Cable temperature, fixed routing	-40...105 °C
Protection type IEC 60529	IP67 /IP67

## General data

Application	Operating voltage
Approval/Conformity	cULus LISTED

## Material

Material contacts	Brass/Brass
Material cover nut	Aluminum anodized/Aluminum anodized
Material grip	PVC

## Remarks

Bulk cable: Oil resistant yellow PVC jacket, rated at 300 V, 105 °C, no wicking, not hygroscopic

## Connector view



BCC A51C-A51C-70-362-VX4CW8-050  
BCC0A5P

## Wiring Diagram

