


C04 T8M-23
BPI0017

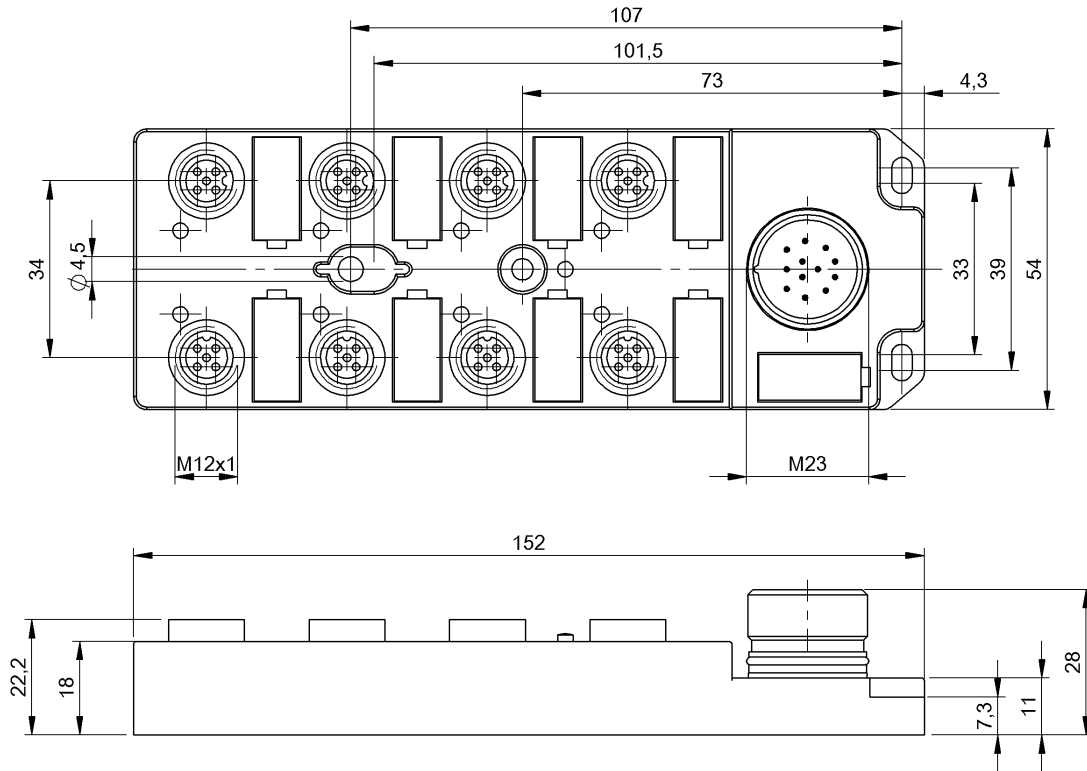

Display/Operation

Power indicator	LED green
Switching function display	8x LED yellow

Electrical data

Operating voltage U_b	10...30 VDC
Output current max.	4 A
Total current max.	12 A

Environmental conditions

Ambient temperature	-25...90 °C
Protection type IEC 60529	IP68

Material

Housing material	PBT, GF
------------------	---------

Mechanical data

Casting	yes
Dimension	152 x 54 x 28 mm
Fastening detail	M4 (4x)
Tightening torque	1.2 Nm \pm 0.2 (M4)
Tightening torque pigtail	0.6 Nm + 0.1 Nm (M12 connector)

Output/Interface

Switching output	PNP
------------------	-----

