


C04 T8S-23  
BPI001Y

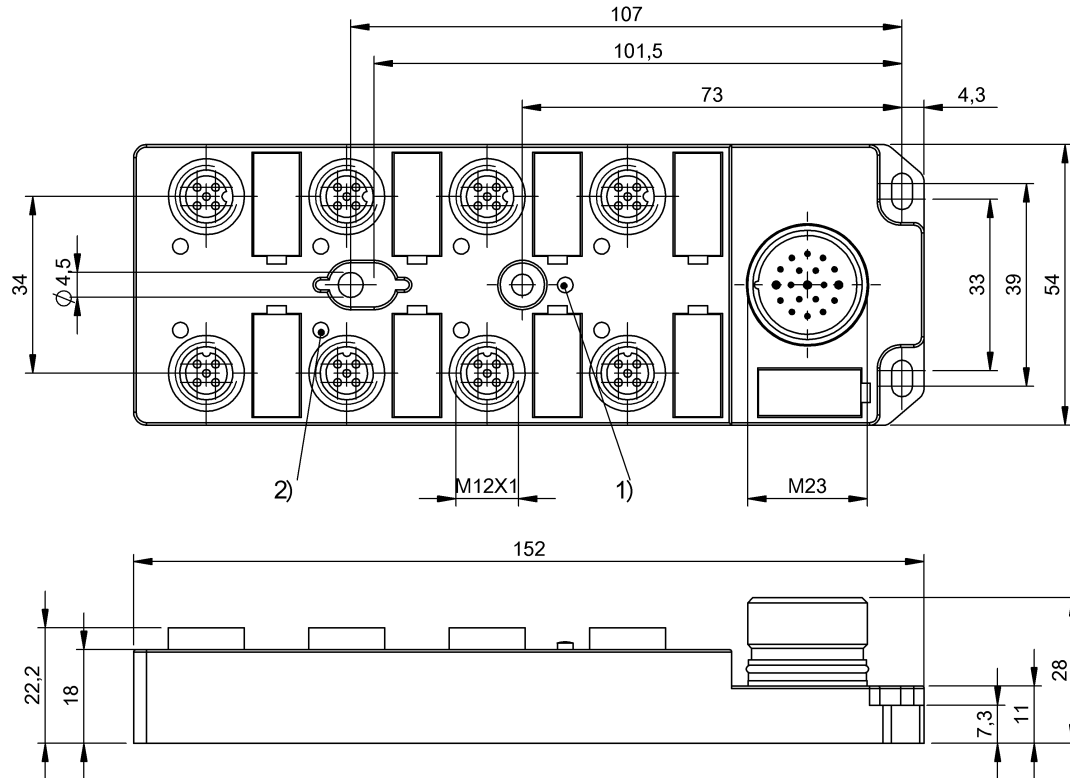

1) Power ind. green potential 2) LED yellow for Signal 1 (NO/NC)

## Display/Operation

Power indicator	LED green
Switching function display	8x LED yellow

## Electrical data

Operating voltage $U_b$	10...30 VDC
Output current max.	2 A
Total current max.	12 A

## Environmental conditions

Ambient temperature	-25...90 °C
Protection type IEC 60529	IP67 when threaded in

## Material

Housing material	PBT, GF
------------------	---------

## Mechanical data

 

Casting	yes
Dimension	152 x 54 x 28 mm
Fastening detail	M4 (4x)
Tightening torque	1.2 Nm $\pm$ 0.2 (M4)
Tightening torque pigtail	0.6 Nm + 0.1 Nm (M12 connector)

## Output/Interface

Switching output	NPN Normally open/Normally closed (NO/NC)
------------------	---


## C04 T8S-23 BPI001Y

### Connector view

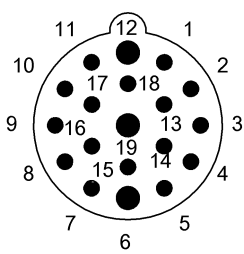

I/O ports PIN 1: +24V PIN 2: Normally closed PIN  
3: 0V PIN 4: Normally open PIN 5: PE

### Wiring Diagram

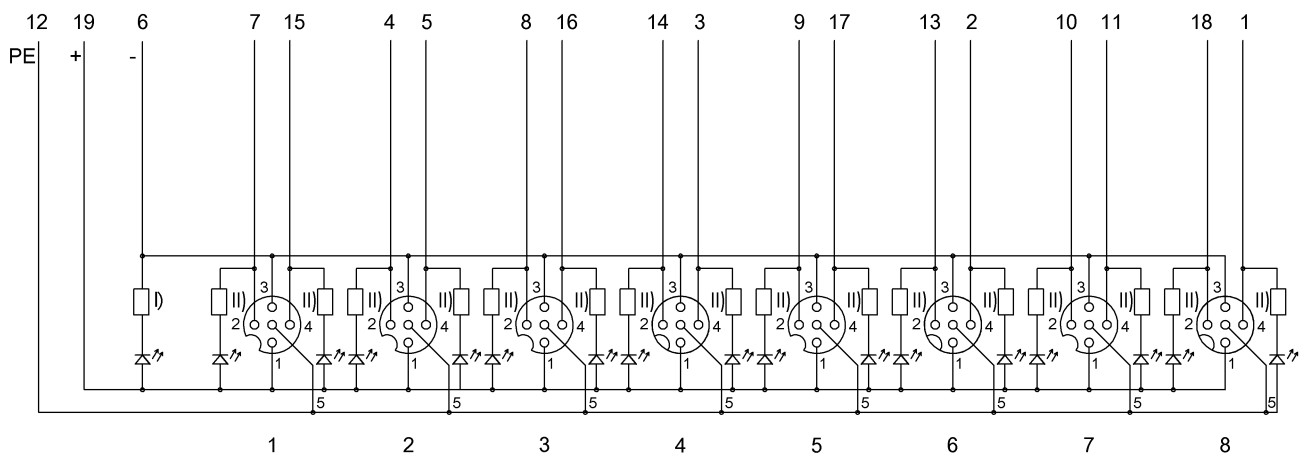

I) LED green II) LED yellow