


BCC M333-0000-20-000-31X350-000-C027
BCC0E7N

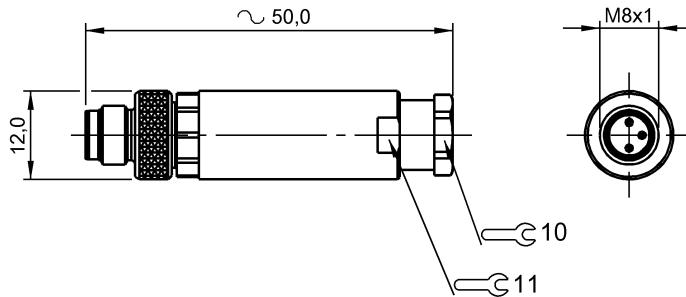

Display/Operation

Power indicator no

Electrical connection

Cable diameter D 2.2...3.5 mm
Number of pins 3
System Can be fabricated

Electrical data

Rated current (40 °C) 4.0 A

Environmental conditions

Ambient temperature -25...85 °C
Protection type IEC 60529 IP67

General data

Base type deviation C027: For cable diameter 2.2 to 3.5 mm use gray compression screw. For cable diameter 3.5 to 5.0 mm use black compression screw.

Material

Material contact carrier PA
Material contacts Brass
Material cover nut Brass
Material grip PBT

Mechanical data

 
Cable diameter (2nd sleeve) 3.5...5 mm
Connection cross-section 0.14...0.5 mm²
Tightening torque pigtail 0.4 Nm
Type of wire mounting Screw terminals

Remarks

Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

BCC M333-0000-20-000-31X350-000-C027
BCC0E7N

Connector view



PIN 1-3 usable