

LED Landscape Replacement Lamps



G4

G9

- 2.5 watts
- 25,000 hours*
- G4/G9 base
- 200° beam spread

features

- Direct replacement for halogen Incandescent G4 and G9 base lamps
- Consumes 75% less energy and lasts 25x longer than incandescent bulbs
- 25,000 hour rated life for ENERGY STAR® Approved lamps*
- 50,000 hour design life**
- Choice of 3000K, 4000K, and 5000K color temperatures
- 200° multi-directional beam angle
- Integrated driver
- Contains no mercury; RoHS compliant
- Emits virtually no UV or IR radiation



performance

- G4 12V 2.5W 200 LM replaces 10W halogen Incandescent
- G9 120V 2.5W 200 LM replaces 10W halogen Incandescent
- 80+ CRI
- Non-dimmable
- Not for use in totally enclosed luminaires
- Operating Temperature: -40°F to 104°F (-40°C to 40°C)

applications

- Landscape lighting
- Deck and patio
- Accent lighting
- Under cabinet lighting
- Pendant and downlighting
- Signs and display lighting
- Steps / Pathway


* Early initial qualification for ENERGY STAR allows for directional lamp life claims of 25,000 hours (L70) with 3,000 hour actual test data, LM80 data and in-situ temperature measurements. As the lamps pass ENERGY STAR requirements, manufacturers may increase the lifetime of a product as dictated by ENERGY STAR guidelines. See http://www.energystar.gov/index.cfm?fuseaction=products_for_partners.showLightbulbs for further details.

** Design life is based on engineering testing and probability analysis



LED Landscape Replacement Lamps

dimensions

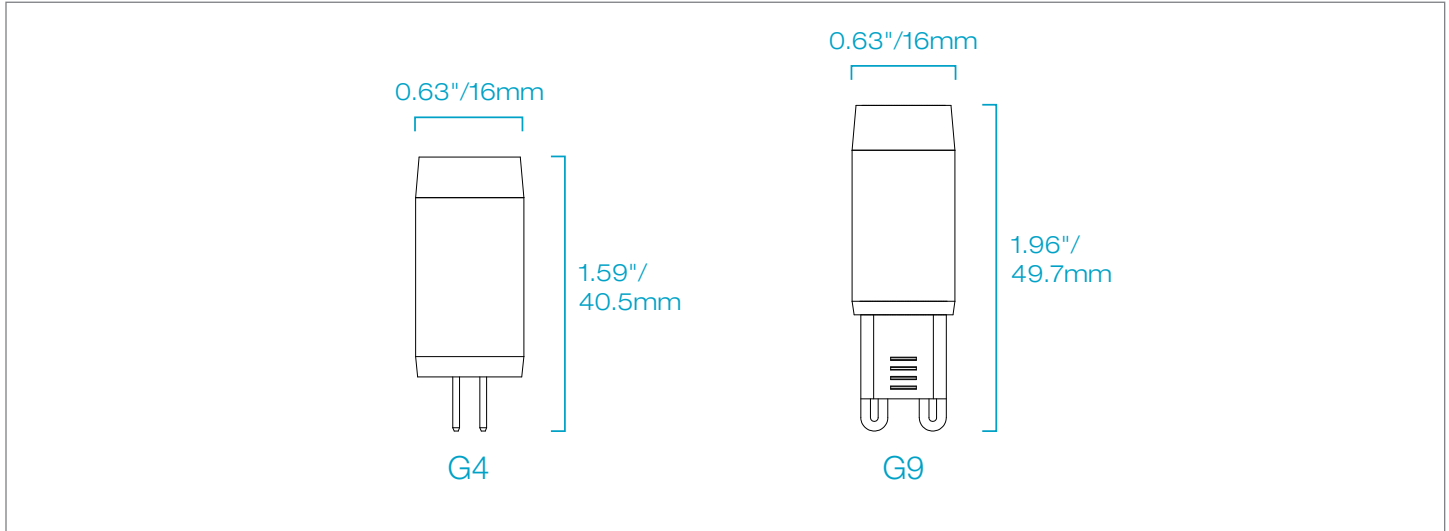

ordering information

Order Code	Litespan Part #	Watts	Volts	Lumens	CCT	CRI	MOL	Life Hours*	Replaces Incandescent
G4 Landscape Replacement 12VAC									
08605	LED2WG4/830K-G4	3W	12V	200	3000K	80+	1.59"	25,000	10W G4
08606	LED2WG4/840K-G4	3W	12V	200	4000K	80+	1.59"	25,000	10W G4
08607	LED2WG4/850K-G4	3W	12V	200	5000K	80+	1.59"	25,000	10W G4
G9 Landscape Replacement 120V									
08608	LED2WG9/830K-G4	3W	120V	200	3000K	80+	1.96"	25,000	10W G9
08609	LED2WG9/840K-G4	3W	120V	200	4000K	80+	1.96"	25,000	10W G9
08610	LED2WG9/850K-G4	3W	120V	200	5000K	80+	1.96"	25,000	10W G9

* 25,000 hour ENERGY STAR® rated life. 50,000 hour design life. See note on obverse.

watch > like > follow



selection. solutions. simplicity. eiko.com

23220 W. 84th St, Shawnee, KS 66227 · (P) 1.800.852.2217 (F) 1.800.492.8975
Canada: 81 King St, Barrie, ON L4N 6B5 · (P) 1.888.410.8151 (F) 1.888.705.1335

