

6" Rotatable LED Downlight Kit



GU24 base E26 base
(included with kit)

11
watts

750
lumens

68
lpw

3000K/
4000K
CCT

features

- Ultra-efficient aimable LED downlight kit designed to retrofit into existing incandescent adjustable downlights.
- Integrated LEDs reduce energy consumption up to 80%
- Ideal for accent, display, and wall washing
- Fits many popular 6" recessed downlight fixtures
- Integrated white trim with both medium base (E26) and GU24 socket adapters (included) for direct replacement
- Lifetime exceeds 35,000 Hrs.
- Lasts up to 30X longer than traditional incandescent
- Choice of warm white or cool white color temperatures
- Instant-on, no warm-up time
- 30° aimable and 355° rotatable

 


performance

- 11W 750 lm equivalent to 65W BR incandescent
- Long life: 35,000+ hours
- 80 CRI
- 120V @ 60hz
- Dimmable 10-100%
- ENERGY STAR® Certified
- UL Damp Location Listed


applications

- Healthcare
- Hospitality
- Office
- Property Management
- Residential
- Retail




6" Rotatable LED Downlight Kit

dimensions

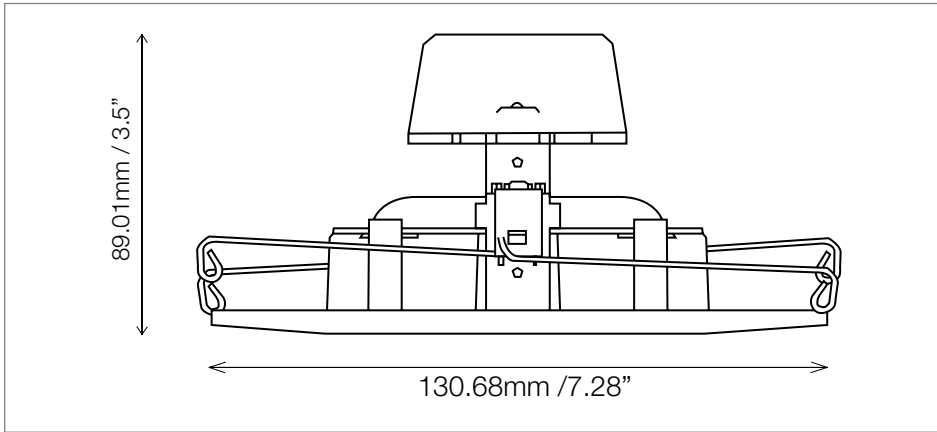

photometrics

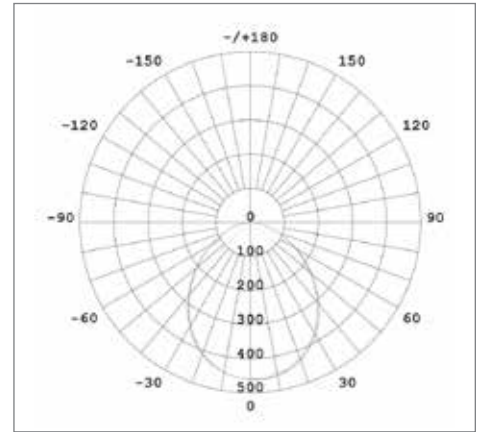

ordering information

Order Code	Litespan Part #	Description	Watts	Volts	Lumens	CRI	Life Hours	ES
09085	LED-DK6RT-11W830-DIM-G5	LED Downlight Kit Rotatable Eye 6", 3000K, dimmable, aimable	11	120	750	80	35,000	★
09086	LED-DK6RT-11W840-DIM-G5	LED Downlight Kit Rotatable Eye 6", 4000K, dimmable, aimable	11	120	750	80	35,000	★

★ENERGY STAR™ Approved

watch > like > follow



selection. solutions. simplicity. eiko.com

23220 W. 84th St, Shawnee, KS 66227 · (P) 1.800.852.2217 (F) 1.800.492.8975
 Canada: 81 King St, Barrie, ON L4N 6B5 · (P) 1.888.410.8151 (F) 1.888.705.1335

