

## Datasheet

### RS Pro BS 1363, 13A UK Plug, Cable Mount, 250 V ac

RS Stock No: **269-8722**



## Product Details


RS Pro UK male main plug connector in white colour, has a thermoplastic body construction with standard sleeved pin for easy assembling. This plug has BS1363 connector type that is current rated for 13 A and is voltage rated for 250 V ac. It is supplied with screwless cable clamp for quick and easy assembly.

## Features and Benefits

- Thermoplastic body construction
- Standard sleeved pin
- BS1363 connector type
- Current rated for 13 A
- Voltage rated for 250 V ac

**Specifications:**

Body Material	Thermoplastic
Colour	White
Connector Type	BS 1363
Country	UK
Current Rating	13 A
Gender	Male
Mounting Type	Cable Mount
Plug/Socket	Plug
Pole Format	2P+E
Voltage Rating	250 V ac
Dimensions	50.2 x 50 x 22 mm

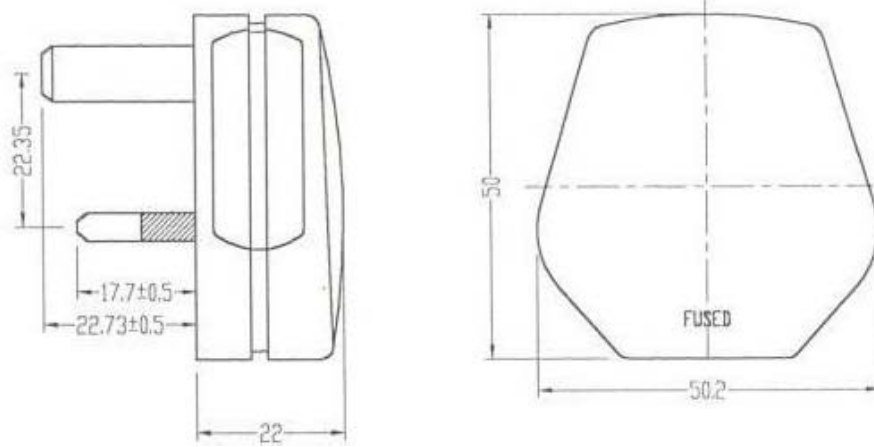

RS code: 2698744

REWIRABLE 13A U.K. PLUGTOP FITTED WITH 3A FUSE, WHITE COLOR, WITH PRESS-FIT CORDGRIP.  
(5PCS PER PACK)

RS code: 2698738

REWIRABLE 13A U.K. PLUGTOP FITTED WITH 13A FUSE, BLACK COLOR, WITH PRESS-FIT CORDGRIP.  
(5PCS PER PACK)

RS Code: 2698722

REWIRABLE 13A U.K. PLUGTOP FITTED WITH 13A FUSE, WHITE COLOR, WITH PRESS-FIT CORDGRIP.  
(5PCS PER PACK)