


# Data sheet

## AC/AC linear adaptors

### UK 5VA

RS Stock No. 458-890  
 RS Stock No. 458-894  
 RS Stock No. 458-973  
 RS Stock No. 458-963  
 RS Stock No. 7300170

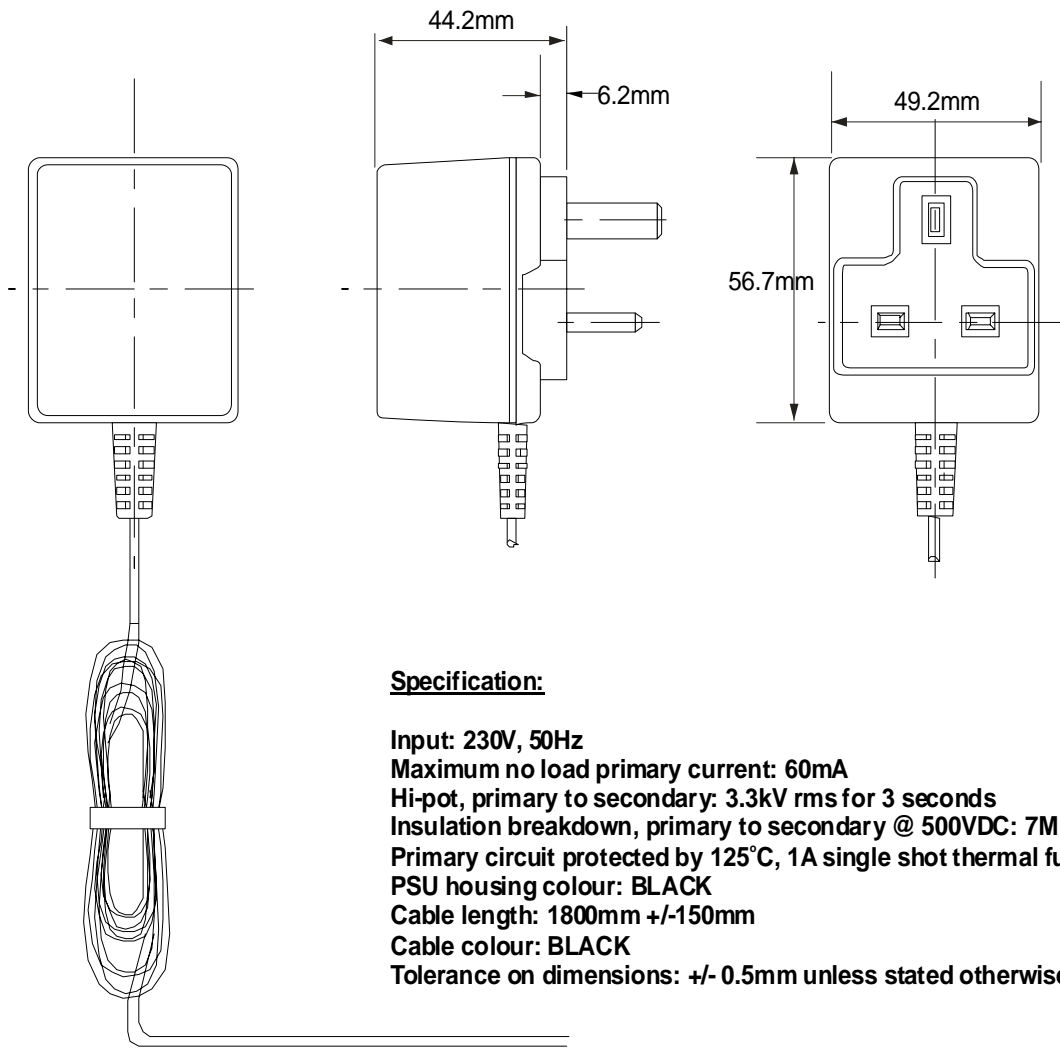

**Specification:**

Input: 230V, 50Hz  
 Maximum no load primary current: 60mA  
 Hi-pot, primary to secondary: 3.3kV rms for 3 seconds  
 Insulation breakdown, primary to secondary @ 500VDC: 7M ohms  
 Primary circuit protected by 125°C, 1A single shot thermal fuse  
 PSU housing colour: BLACK  
 Cable length: 1800mm +/-150mm  
 Cable colour: BLACK  
 Tolerance on dimensions: +/- 0.5mm unless stated otherwise

Part number	Open circuit voltage (VAC)	Full load voltage (VAC)	Current (mA)
AD3515-05-0600 UK	7.1	5	600
AD3515-09-0528 UK	13.4	9	528
AD3515-12-0400 UK	18.3	12	400
AD3515-18-0267UK	25.9	18	267
AD3515-24-0200UK	35.5	24	200