




Data sheet

AC/AC linear adaptors

European 5VA

RS Stock No. 459-948
RS Stock No. 459-853
RS Stock No. 459-843
RS Stock No. 459-847
RS Stock No. 730!0177

ENGLISH

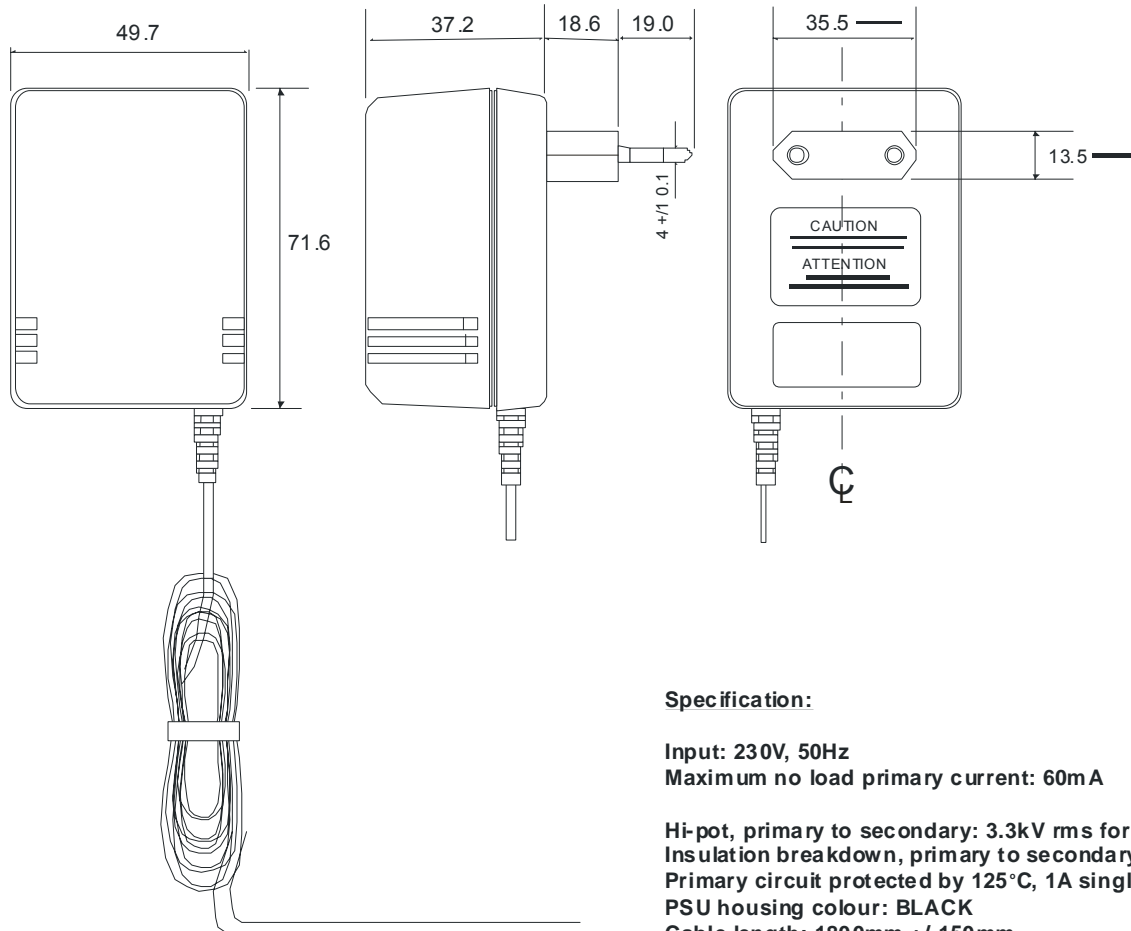

Specification:

Input: 230V, 50Hz
Maximum no load primary current: 60mA

Hi-pot, primary to secondary: 3.3kV rms for 3 seconds
Insulation breakdown, primary to secondary @ 500VDC: 7M ohms
Primary circuit protected by 125°C, 1A single shot thermal fuse
PSU housing colour: BLACK
Cable length: 1800mm +/-150mm
Cable colour: BLACK

Tolerance on dimensions: +/- 0.5mm unless stated otherwise

Part number	Open circuit voltage (VAC)	Full load voltage (VAC)	Current (mA)
459-948	7.1	5	600
459-853	13.4	9	528
459-843	18.3	12	400
459-847	25.9	18	267
730-0177	35.5	24	200