

Datasheet

705-1210

Electronic Outside Micrometer

Specification: 25-50mm/1-2"

Resolution: 0.001mm/0.00005"


Accuracy: $\pm 0.002\text{mm}$



Feature:

- Protection level **IP54**.
- Display data is origin data of absolute measurement after changing battery.
- Chrome-plated or painted frame. Carbide measuring faces.
- Criterion: DIN863/1, DIN40050/IEC529.
- Resolution: 0.001mm(Metric); 0.00005"(Inch).

Power ON/OFF	✓
Abs. and inc. conversion	✓
Metric/inch conversion	✓
Data output	✓
Origin data set	✓
Clock	✓
Battery	SR44
Auto power off	✓
Power consumption	<35 μA
RS232 output port	✓
Connecting cable (Optional)	P1103 or P1104

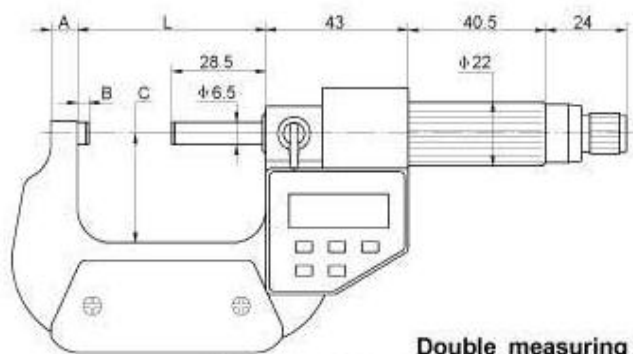

Double measuring forces
(Ratchet stop and Ratchet friction thimble)

Dimensions

Range		A	B	C	L
Metric	Inch				
0-25mm	0-1"	6mm	3.0mm	24mm	32mm
25-50mm	1-2"	8mm	3.0mm	32mm	57mm