


Data sheet

AC/AC linear adaptors

European 8VA

RS Stock No. 459-831
 RS Stock No. 7300174
 RS Stock No. 7300186
 RS Stock No. 7300199
 RS Stock No. 7300196

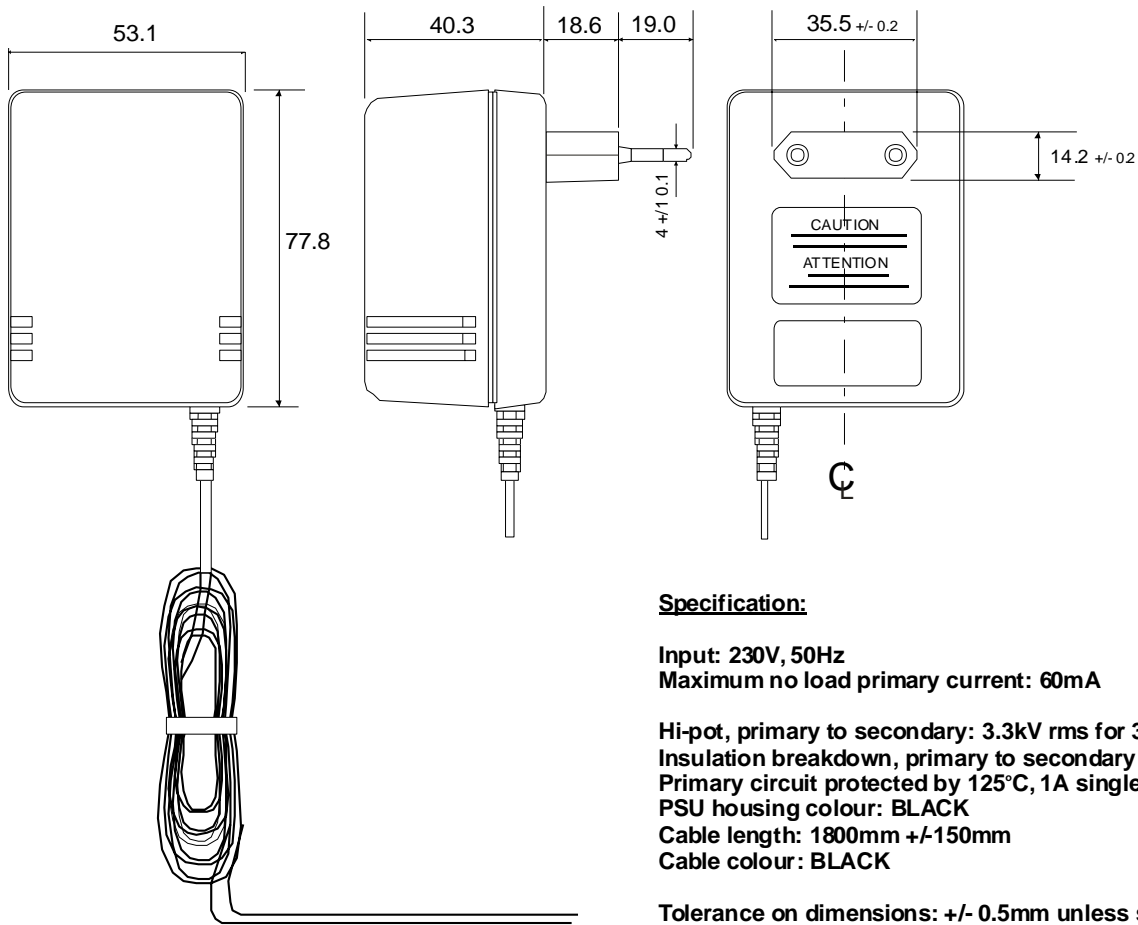

Specification:

Input: 230V, 50Hz
 Maximum no load primary current: 60mA

Hi-pot, primary to secondary: 3.3kV rms for 3 seconds
 Insulation breakdown, primary to secondary @ 500VDC: 7M ohms
 Primary circuit protected by 125°C, 1A single shot thermal fuse
 PSU housing colour: BLACK
 Cable length: 1800mm +/-150mm
 Cable colour: BLACK

Tolerance on dimensions: +/- 0.5mm unless stated otherwise

Part number	Open circuit voltage (VAC)	Full load voltage (VAC)	Current (mA)
AD4120-05-1000 EU	10	5	1000
AD4120-09-0950EU	12.6	9	950
AD4120-12-0700EU	16.1	12	700
AD4120-18-0460EU	24.2	18	460
AD4120-24-0350EU	31.8	24	350