


Data sheet

AC/DC linear adaptors

UK 6W

RS Stock No. 7300284
 RS Stock No. 7300281
 RS Stock No. 7300293
 RS Stock No. 7300307

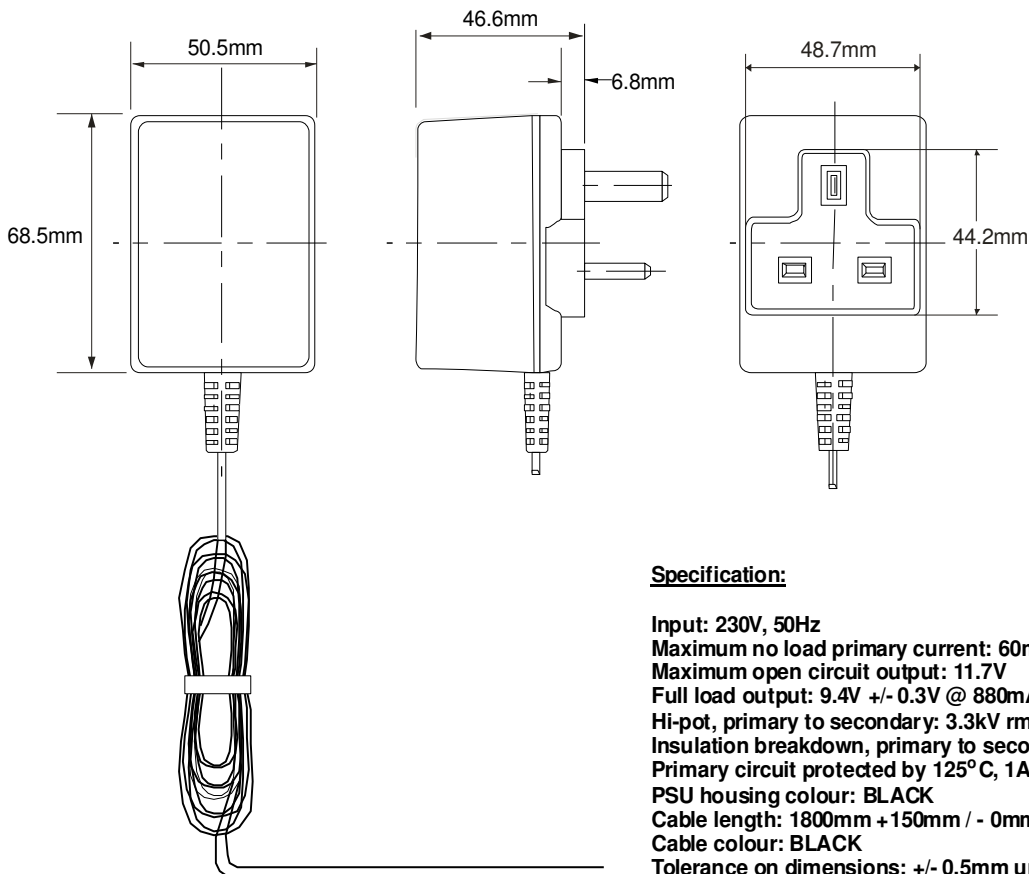

Specification:

Input: 230V, 50Hz
 Maximum no load primary current: 60mA
 Maximum open circuit output: 11.7V
 Full load output: 9.4V +/- 0.3V @ 880mA
 Hi-pot, primary to secondary: 3.3kV rms for 3 seconds
 Insulation breakdown, primary to secondary @ 500VDC: 7M ohms
 Primary circuit protected by 125°C, 1A single shot thermal fuse
 PSU housing colour: BLACK
 Cable length: 1800mm +150mm / - 0mm
 Cable colour: BLACK
 Tolerance on dimensions: +/- 0.5mm unless stated otherwise

Part number	Open circuit voltage (VDC)	Full load voltage (VDC)	Current (mA)
D41-05.0-0900UK	9.5	5	900
D41-09.0-0600UK	15	9	600
D41-12.0-0450UK	19	12	450
D41-18.0-0300UK	28.5	18	300