


Data sheet

AC/DC linear adaptors

European 6W

RS Stock No. 7300275
 RS Stock No. 7300287
 RS Stock No. 7300290
 RS Stock No. 7300297

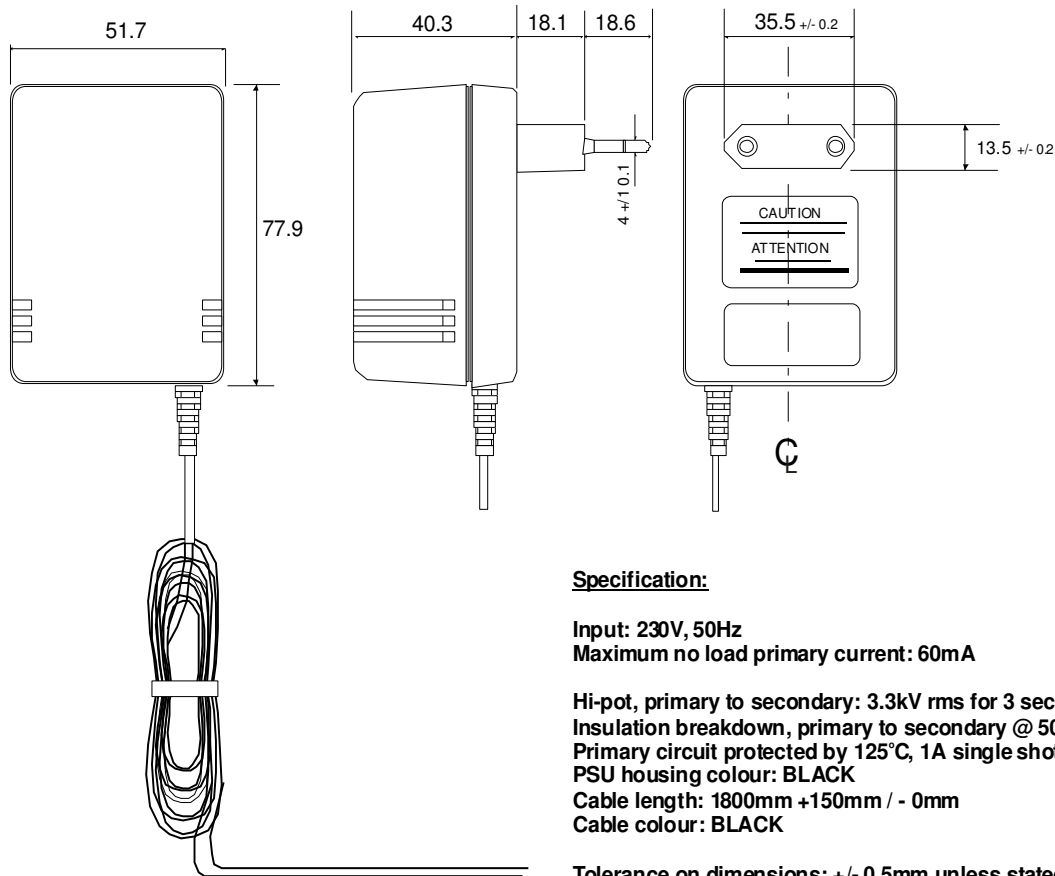

Specification:

Input: 230V, 50Hz
 Maximum no load primary current: 60mA

Hi-pot, primary to secondary: 3.3kV rms for 3 seconds
 Insulation breakdown, primary to secondary @ 500VDC: 7M ohms
 Primary circuit protected by 125°C, 1A single shot thermal fuse
 PSU housing colour: BLACK
 Cable length: 1800mm +150mm / - 0mm
 Cable colour: BLACK

Tolerance on dimensions: +/- 0.5mm unless stated otherwise

Part number	Open circuit voltage (VDC)	Full load voltage (VDC)	Current (mA)
D41-05.0-0900EU	9.5	5	900
D41-09.0-0600EU	15	9	600
D41-12.0-0450EU	19	12	450
D41-18.0-0300EU	28.5	18	300