




Datasheet

ENGLISH

20m Long Black Rubber Hose, Applications Steam, 25mm Inner Diam.

RS Stock number 486-546

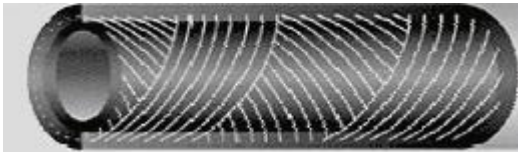

Type No. : 1161		
Standard Length :		
Working Temperature : -30°C to +170°C		
Std. Branding :		STEAM - 7 BAR WP. - 170°C
Reinforcement :		Polyester
Inside :	EPDM	Colour : Black
Outside :	EPDM	Colour : Black/white line
Standards :		-

Data					
Inside dia. mm	Outside dia. mm	Working Pressure BAR	Burst Pressure BAR	Bend Radius mm	Weight g/m
13.0	25.0	7	70	130	410
19.0	32.0	7	70	190	600
25.0	38.0	7	70	250	740