

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1201130002](#)  
**Status:** **Active**  
**Overview:** [Brad® Nano-Change® &#40;M8&#41; Products](#)  
**Description:** Nano-Change® Molded Junction Box, Side Mount with Molded Cable, 10 Ports, 5.0m Cable

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Passive Distribution Boxes
Series	120113
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	<a href="#">Brad® Nano-Change® &amp;#40;M8&amp;#41; Products</a>
Product Name	Nano-Change® (M8)
UPC	78678834074

**Physical**

Bus I/O	Nano-Change® (M8)
Cable Connector Orientation	Straight
Cable Length	5.0m
Home Run Cable Length	5.0m
Home Run Connector	N/A
Home Run Interface	Pigtail
Keyway	None
LED Indicator	Yes
Material - Cable Jacket	PUR
Material - Housing	PBT
Material - Metal	Copper Alloy
Material - Plating Mating	Gold over Nickel
Orientation	Top Mount
Poles	3
Poles (wired)	3
Ports	10
Temperature Range - Operating	-25°C to +90°C
Wiring Configuration	Single I/O per Port

**Electrical**


Current - Maximum per Contact	2.0A per port
Functional Wiring	PNP
Voltage - Maximum	10-30V DC

**Material Info**

Old Part Number	BEYA01P-FBP-05
-----------------	----------------

**Reference - Drawing Numbers**

Sales Drawing	SD-120113-004
---------------	---------------

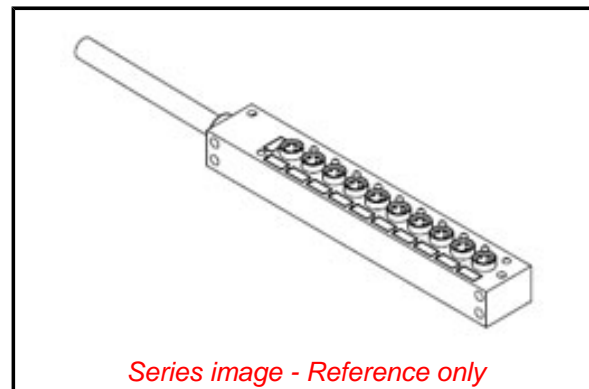

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Not Contained Per -ED/79/2015 (17 December 2015)

**Halogen-Free**

**Status**

**Not Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

50 Image

ELV

Not Relevant

**Search Parts in this Series**

[120113 Series](#)