

PANEL MOUNT INDICATOR, NON-RELAMPABLE

LED TECHNOLOGY

MOUNTING HOLE, Ø 0.500"

PART NO.	LENS COLOR	VOLTAGE	CURRENT [mA]	RATED LIFE HOURS
LED 115VAC SERIES				
WL-1091M1-125V	RED	105-125VAC	20mA	100,000
WL-1091M4-125V	WHITE	105-125VAC	20mA	100,000
WL-1091M5-125V	GREEN	105-125VAC	20mA	100,000
WL-1091M7-125V	YELLOW	105-125VAC	20mA	100,000
LED 230VAC SERIES				
WL-1091M1-250V	RED	208-250VAC	20mA	100,000
WL-1091M4-250V	WHITE	208-250VAC	20mA	100,000
WL-1091M5-250V	GREEN	208-250VAC	20mA	100,000
WL-1091M7-250V	YELLOW	208-250VAC	20mA	100,000

NOTES


1. Recommended panel thickness
0.030" to 0.090"
2. 6" leads with 1/2" strip are standard
3. Storage temperature
 T_{STG} : -25°C - +80°C
4. Ambient temperature
 T_A : -20°C - +60°C
5. Voltage tolerance
 V_{OP} : ±10%
6. Body material
Polycarbonate, white
7. Lens material
Polycarbonate
8. Bezel material
Stainless steel
9. Wire gauge
20 AWG
10. Wire strip
1/2"

CERTIFICATIONS

UL (E340667), RoHS



DIMENSIONAL CHARACTERISTICS

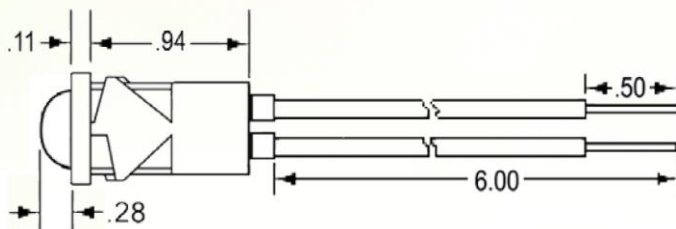

unless otherwise specified, all dimensions are in inches



OPTIONS

Additional options and lens styles available. Please contact Wamco for more information.

