


Datasheet

Filament Indicator Lamp

RS Stock number 104-840



Dimensions: (mm)

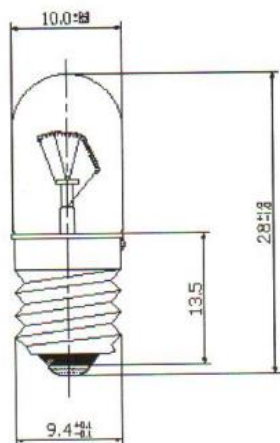

Specification

Structure		Design Characteristics	
Bulb Type	T3 ¼ Clear	Voltage	60V
Bulb Diameter	Ø10.0 Max	Amperage	50mA \pm 10%
Length	28.0 Max	Filament Type	Vacuum Type
Base Type	E10	Life Hours	3000 Hours
		Luminous Flux	10.5Lm \pm 20%