

Sealing cap - PROT-M12 MS-PA-CHAIN-EYE-DM14 - 1456200


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



M12 sealing cap with fixing band, for free M12 sockets with 14.5 mm fastening eye



Key Commercial Data

Packing unit	5 STK
Minimum order quantity	5 STK
GTIN	 4 046356 605724
GTIN	4046356605724

Technical data

Ambient conditions

Ambient temperature (operation)	-25 °C ... 85 °C
Degree of protection	IP67

General

Note	Not suitable for M12 sockets with K, L, or M coding
------	---

Material

Flammability rating according to UL 94	V0
Material	PA 66 GF
Sealing material	NBR
Additional material specifications	PUR (Holding band)

Standards and Regulations

Flammability rating according to UL 94	V0
--	----

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
------------	--

Sealing cap - PROT-M12 MS-PA-CHAIN-EYE-DM14 - 1456200


Technical data

Environmental Product Compliance

	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"
--	---

Drawings

Dimensional drawing

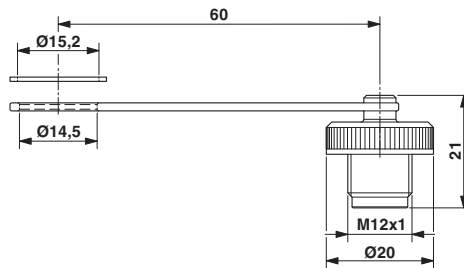

Dimensional drawing

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>