

LEADING CHANGEOVER SWITCH CHANGEOVER CONTACTS
TYPE HQ (7MM) ELECTRONIC ACCESSORY FOR 3VA4/5/6-
BREAKER



| Model | |
|--|---------|
| product brandname | SENTRON |
| General technical data | |
| Degree of pollution | 3 |
| Overtoltage category | III |
| Lead time / relating to main contacts | 20 ms |
| Voltage | |
| Tension assignée d'isolement Ui | 690 V |
| Tension assignée de tenue aux chocs | 4 kV |
| Operating voltage / at AC / acc. to CSA and UL | 24 V |
| Operating voltage / at DC / acc. to CSA and UL | 24 V |
| Rated operational voltage Ue at AC 50 Hz | 24 V |
| Rated operational voltage Ue with DC | 24 V |
| Electricity | |
| Thermal current | 0.3 A |
| Operating current | |
| • at AC-12 / at 12 V | 0.3 A |
| • at AC-12 / at 24 V | 0.3 A |



- at DC-12 / at 12 V
- at DC-12 / at 24 V
- at DC-13 / at 12 V
- at DC-13 / at 24 V
- at AC-15 / at 12 V
- at AC-15 / at 24 V

0.1 A
0.1 A
0.07 A
0.07 A
0.3 A
0.3 A

Mechanical Design

| | |
|----------------------------|---------------|
| Width / Note | 1 slot (7 mm) |
| Wire stripping length | 15 mm |
| Wire stripping length [in] | 0.6 in |

Certificates

| EMC | Declaration of Conformity | other |
|--|---|-------------------------|
|  RCM |  EG-Konf. | sonstig |

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/3VA9978-0AA23>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/3VA9978-0AA23/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9978-0AA23

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

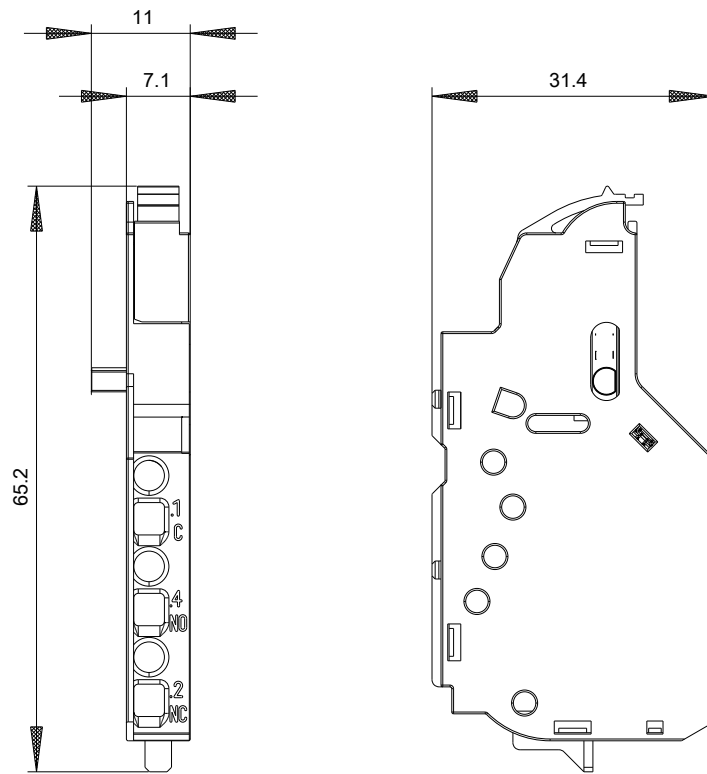

LCS

.2

.4

.1

last modified:

11/25/2016