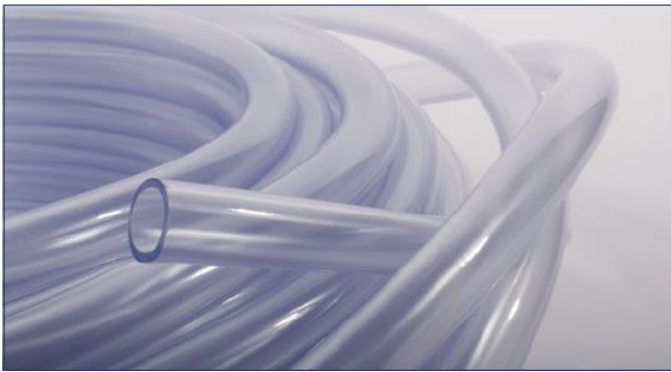


Datasheet

Stock No: 9145528**RS Pro Clear Unreinforced PVC Hose**

Nominal Size	6 x 9mm
Internal Diameter	6.0 ± 0.25mm
External Diameter	9.0 ± 0.25mm
Length Tolerance	BS EN ISO 1307 (± 1%)
Maximum Working Pressure	N/A
Minimum Burst Pressure	N/A
Bend Radius	81mm
Working Temperature	-15°C to +60°C
Material	Flexible PVC
Material Softness	BSS45 FDA Approved
Flammability	Self-Extinguishing
Weight Per Meter	0.044Kg
Coil Weight	1.32Kg