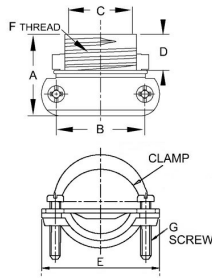


**NM CLAMP TYPE CONNECTORS**

Clamp Type Cable Connectors Die Cast Zinc

**B77**

Catalog #: 2711

**APPLICATIONS**

For use in dry locations to connect Nonmetallic Sheathed Cable (NMSC) to a box or enclosure

**PRODUCT FEATURES**Rugged metallic construction will last the lifetime of the installation  
N/A**UL LISTED**

Standard 514B, UL Listed E195972

**CSA**

C22.2 No. 18

**COMPLIANCES**MSDS  
[www.hubbell-rtb.com/certifications/Hubbell-RACO MSDS for WP Boxes and Fittings, January 2015.pdf](http://www.hubbell-rtb.com/certifications/Hubbell-RACO%20MSDS%20for%20WP%20Boxes%20and%20Fittings,%20January%202015.pdf)**GENERAL PRODUCT INFORMATION**Trade Size: 1/2 in.  
Cable Size: 2 #14, 2 #10, 3 #14, or 3 #12 with or without Ground**DRAWING DIMENSIONS**Dimension A: .75 in.  
Dimension B: .89 in.  
Dimension C: .65 in.  
Dimension D: .36 in.  
Dimension E: 1.17 in.  
Dimension F: 1/2 in. - 1/4 NPSM  
Dimension G: NO. 8-32 x 3/4 in.**PACKAGING**Package Type: Carton  
Std. Pkg.: 100  
Ship Carton Qty.: 1000  
Product UPC-A Labeled: No  
Weight (Lbs. Per/C): 4.70  
Ship Carton Length (in.): 18.89  
Ship Carton Width (in.): 10.59  
Ship Carton Height (in.): 6.81  
Ctn Weight (Lbs.): 44.90  
UPC Number: 050169027110  
I2of5: 50050169027115